

# KICK SPACE HEATER

SKS SERIES

## HIDE 'N HEAT

“Hide 'n heat” is what the SKS kick space heater by °STELPRO offers. Its redesigned and sleek grille is slimmer than ever, allowing easy installation in narrow spaces like under the kitchen or bathroom cabinets and even into stair risers. Enjoy comfortable forced-air heating from the most discreet fan heater on the market.



### POWER SELECTOR SWITCH

500 W OR 1000 W

### EASY INSTALLATION

### AESTHETIC GRILLE

SINGLE PIECE, FRAMELESS

### IDEAL FOR:

UNDER A KITCHEN OR BATHROOM CABINET, IN A STAIR RISER

### COLOURS

- standard: white, soft white
- luxurious finish: stainless steel (see price list)
- ORORA (optional): denim blue, midnight blue, turquoise, moss green, canary yellow, red, orange, anodized aluminum paint, gravel gray, charcoal, espresso, black (refer to [page 8 of the catalogue](#))

### FINISH

epoxy-polyester powdercoat or stainless steel

### MANUFACTURING

- 22-gauge steel cabinet and 16-gauge steel front
- quiet, 50 CFM capacity
- thermal protection with automatic reset
- added protection provided by a fuse-link (must be replaced once activated)

### WATTAGE & VOLTAGE

power selector switch (500 W or 1000 W)

### ELEMENT

tubular element sheathed with spiral-wound fins for improved heat dissipation

### CONTROL

- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended
- built-in thermostat (optional)

### INSTALLATION

recessed

## ACCESSORIES

PRODUCT	DESCRIPTION	PRICE
SKST1	built-in single pole thermostat	45.00
SKST2	built-in tamper-proof double pole thermostat	56.25
SKSR*	extended grille (23 5/8 in. x 3 3/4 in. - 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project	56.75
SKSRSS	extended stainless steel grille (23 5/8 in. x 3 3/4 in. - 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project	77.25

\* Add W for white or SW for soft white

## TECHNICAL SPECIFICATIONS


PRODUCT	POWER	VOLTAGE	THROW DISTANCE		HEAT RISE		WEIGHT		PRICE	
CODE	WATTS	VOLTS	M	FT.	°C	°F	KG	LB	W OR SW	SS
SKS1001	500 OR 1000	120	1.2	4 (in front)	55	99	4.5	10	286.00	386.00
SKS1002	500 OR 1000	240	1.2	4 (in front)	55	99	4.5	10	286.00	386.00

Add W for white, SW for soft white or SS for stainless steel (see [page 8 of the catalogue](#) for optional colours and contact your °STELPRO representative for all other colours)





## TECHNICAL DRAWINGS

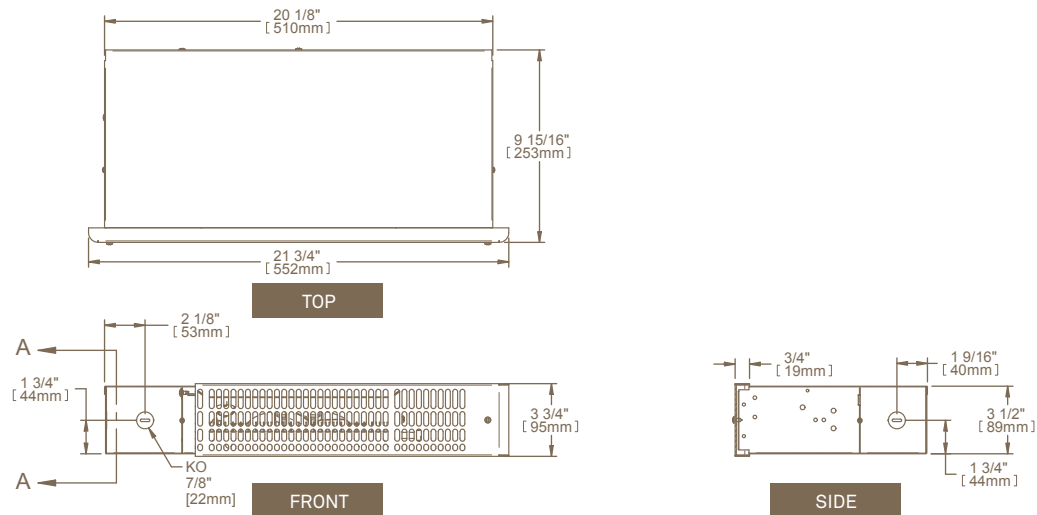

\*STELPRO reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. Returns are not accepted for orders of products with optional colours. For all the latest models and updated prices, please refer to our website at [www.stelpro.com](http://www.stelpro.com).