


## High-Flex HOME 5e® Patch Cords

### APPLICATION

High-Flex HOME 5e Patch Cords provide patching for data applications in Structured Media® Centers. The patch cords offer high-density patching and deliver 100 Mhz bandwidth performance.

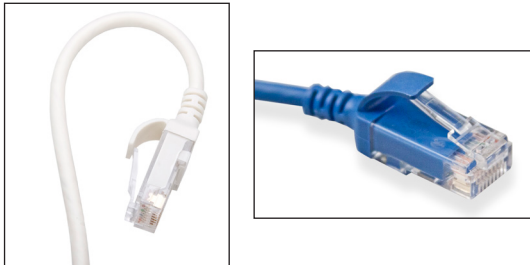

### SPECIFICATION

Patch cords shall provide residential application performance for cross connecting in Structured Media systems comprised of equipment, cable, and appropriate connectors. The patch cords shall be 28-gauge, unshielded, twisted pair, stranded conductor construction with a standard 8-position modular plug on both ends. Patch cords shall have an outer diameter of 0.15" and shall be available in white and blue.

### WARRANTY INFORMATION

For a copy of Leviton product warranties, visit [www.leviton.com/warranty](http://www.leviton.com/warranty).

### FEATURES

- Available in white and blue
- Available in 6", 1', 2', 3', and 4' lengths
- Power over Ethernet (PoE and PoE+) compatible
- Accommodate use in high-density switches, routers, and other electronics
- Bend radius is a narrow 0.60", versus 0.88" for typical CAT 5e patch cords

### DESIGN CONSIDERATIONS

- Designed to provide connectivity solution for residential applications
- Channel Length:
  - Supports 96-meter channels that include 90 meter permanent links
  - Supports 93-meter channels with 10 meters of patch cords included in the channel

### STANDARDS COMPLIANCE

- Meets all applicable standards and listings
- ANSI/TIA-1096-A (formerly FCC Part 68)
  - RoHS compliant

### PHYSICAL SPECIFICATIONS

- Dimensions: 6", 1', 2', 3', and 4' lengths
- Materials:
- 28-gauge, stranded UTP
  - Standard modular non-keyed, 8-position, 8-conductor plug
  - 94V-0 rated
- Outer Diameter: 0.15"
- Bend Radius: 0.60"

### COUNTRY OF ORIGIN

China

### PART NUMBERS

#### Description

#### Part No.

High-Flex HOME 5e Patch Cords

5HHOM-XX\*

XX = Length: 6" (6I), 1' (01), 2' (02), 3' (03), 4' (04)

\* = colors: White (W), Blue (L)



#### Leviton Network Solutions

2222 - 222nd St. SE  
Bothell, WA 98021-4416

tel 1-800-824-3005  
tel +1-425-486-2222  
appeng@leviton.com  
www.leviton.com

#### Asia / Pacific

T +1.631.812.6228  
E infoasean@leviton.com

#### Europe

T +33.6.8869.1380  
E infoeurope@leviton.com

#### Canada

T +1.514.954.1840  
E pcservice@leviton.com

#### India / SAARC

T +91.80.4322.5678  
E infoindia@leviton.com

#### Caribbean

T +1.954.593.1896  
E infocaribbean@leviton.com

#### Mexico

T +52.55.5082.1040  
E lsamarketing@leviton.com

#### China

T +852.2774.9876  
E infochina@leviton.com

#### Middle East & Africa

T +971.4.886.4722  
E lmeinfo@leviton.com

#### Colombia

T +57.1.743.6045  
E infocolombia@leviton.com

#### South Korea

T +82.2.3273.9963  
E infokorea@leviton.com