

# Mounting Adapters for Mercmaster™ LED Low Profile

## NEC/CEC:

*Class I, Division 2, Groups A, B, C, D*  
*Class I, Zone 2 Group IIC*  
*Class II, Division 1, Groups E, F, G*

## NEC/CEC:

*Class II Division 2, Groups F, G*  
*Class III*  
*Simultaneous Exposure*  
*Type 3R, 4, 4X*

## NEC/CEC:

*IP66*  
*Suitable For Use In Wet Locations*  
*Marine Outside Type (Salt Water For USA ONLY)*

## Applications

- Mounting Hood adapters allow the end-user to seamlessly retrofit energy efficient, Mercmaster LED Low profile luminaires to pre-existing mounting hoods
- Adapters are certified for use with Appleton Mercmaster LED Low Profile Luminaires
- Mercmaster LED Low Profile is an enclosed and gasketed luminaire, suitable for use in:
  - A wide range of industrial, chemical processing and other areas where flammable gases and vapors may be present
  - Marine and wet locations
  - Areas of low clearance, low ceiling heights or where fixture weights must be minimized
- Typical applications include:
  - Chemical plants
  - Petrochemical facilities
  - Oil refineries
  - Pulp and paper mills
  - Processing plants
  - Drilling rigs
  - Foundries
  - Waste and sewage treatment
  - Mining
  - Steel mills

## Features

- Available for use with all Mercmaster LED Low Profile Luminaires
- Mercmaster LED Low Profile provides a seamless transition from HID and other legacy sources to LED technology by maintaining the same look and feel as the HID counterpart for HID wattages up to 150W.
- Compact adapter design maintains luminaires compact light weight low profile for low mounting heights.
- Easy, fast installation with no loose parts.
- Labor savings; no need to pull new wires.
- Casted opening for safety cable connection.
- Standard adapter is compatible with ceiling and pendant mounting hoods:
  - Appleton MMII — LPA75, LPA100, LPC75, LPC100
  - Crouse-Hinds\* — APM2, APM3, HPM2, CM2, and CM3
- Offset adapter is compatible with stanchion and wall mounting hoods:
  - Appleton MMII — LPWB75, LPWB100, LPS125, LPS150
  - Crouse-Hinds\*: TWM2, TWM3, JM5, PM5 and QM25.
- Hinge has high lip for added safety during installation and servicing. Hinge and bolt construction assures 360° compression at all points on fixture housing gasket for positive sealing. Swing away design of captive bolt and nut simplifies servicing.
- Mercmaster LED Low Profile's four replaceable globe alternatives provide uniform illumination where it is needed.

## Standard Materials

- Adapters are cast copperfree (4/10 of 1% max.) aluminum

## Standard Finishes

- Gray epoxy powder coat finish, electrostatically applied for complete uniform protection

## Related Products

- Mercmaster LED Low Profile Luminaires

✦ Crouse-Hinds is a registered trademarks of Cooper Crouse-Hinds

Standard Adapter



Pendant/Ceiling Mount Adapters

Offset Adapter



Stanchion/Wall Adapters

## NEC/CEC Certifications and Compliances


- UL Standard: UL 50; UL 844, UL 1598, UL 1598A, UL 8750
- CSA Standard: C22.2 No 0; C22.2 No. 94; C22.2 No. 60529; C22.2 No. 137; C22.2 No. 250.0; C22.2 No. 250.13
- ANSI/IEC Standard: 60529
- CSA: 70072210
- Master Contract: 164460
- Mercmaster LED Low Profile is DLC Qualified Products Listed

# Mounting Adapters for Mercmaster™ LED Low Profile


NEC/CEC:  
Class I, Division 2, Groups A, B, C, D  
Class I, Zone 2 Group IIC  
Class II, Division 1, Groups E, F, G

NEC/CEC:  
Class II Division 2, Groups F, G  
Class III  
Simultaneous Exposure  
Type 3R, 4, 4X

NEC/CEC:  
IP66  
Suitable For Use In Wet Locations  
Marine Outside Type (Salt Water For USA ONLY)

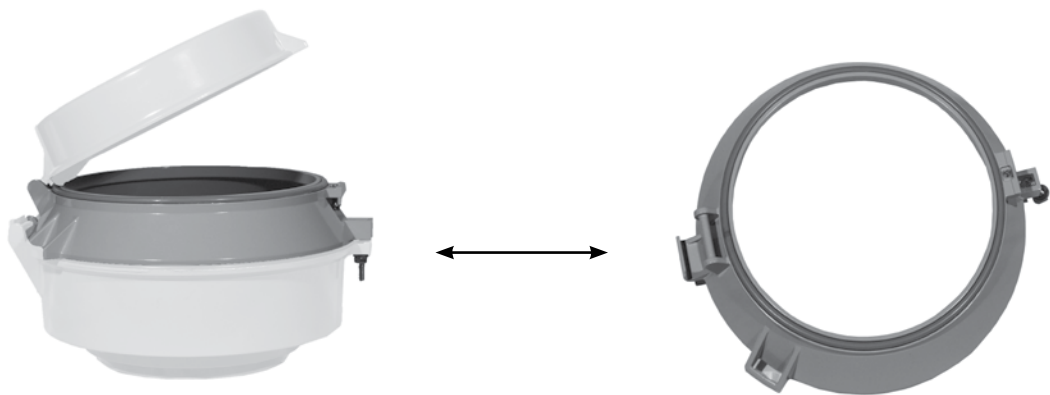

Manufacturer	Mounting Hood	Family	Appleton Adapter Catalog Number
Crouse-Hinds+	APM2/3 - Pendant CM2/3 - Ceiling HPM2 - Flexible Pendant	Champ	MMADCHVS
Appleton™	LPA75/100 - Pendant LPC75/100 - Ceiling	Mercmaster II	MMADIIS

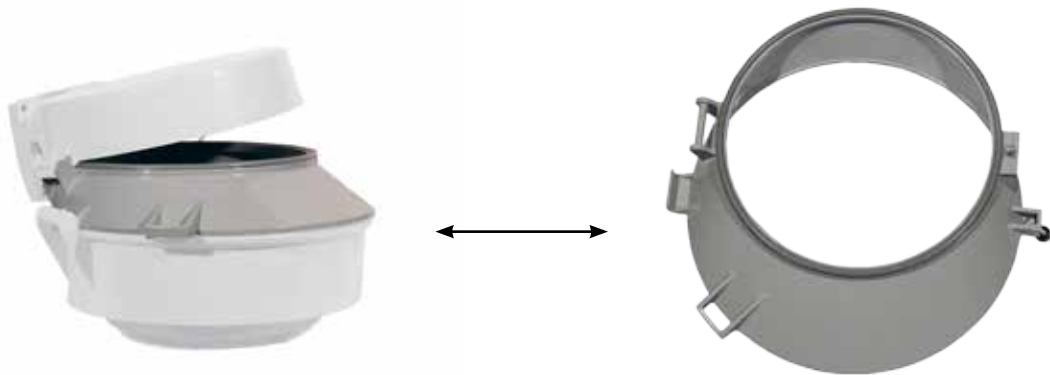

Manufacturer	Mounting Hood	Family	Appleton Adapter Catalog Number
Crouse-Hinds+	TWM2/3 - Wall JM5 - 25° Angle Stanchion PM5w - 90° Straight Stanchion	Champ	MMADCHVA
Appleton™	LPWB75, LPWB100 - Wall LPS125, LPS150 - 25° Angle Stanchion	Mercmaster II	MMADIIA

+ Crouse-Hinds is a registered trademarks of Cooper Crouse-Hinds

# Mounting Adapters for Mercmaster™ LED Low Profile

## NEC/CEC:

Class I, Division 2, Groups A, B, C, D  
Class I, Zone 2 Group IIC  
Class II, Division 1, Groups E, F, G


## NEC/CEC:

Class II Division 2, Groups F, G  
Class III  
Simultaneous Exposure  
Type 3R, 4, 4X


## NEC/CEC:

IP66  
Suitable For Use In Wet Locations  
Marine Outside Type (Salt Water For USA ONLY)


Dimensions in Millimeters (Inches) – Appleton Mercmaster™ II with Adapter and Mercmaster™ LED Low Profile

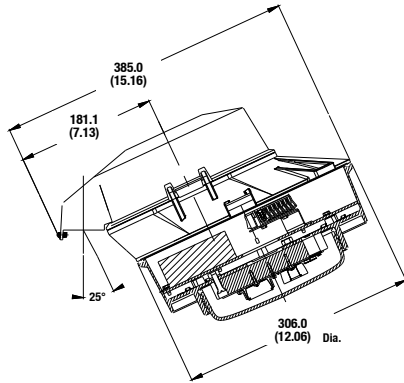


Off Centric Adapter – 25° Stanchion Mount

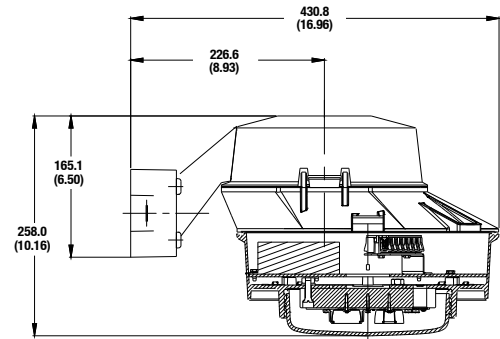

Off Centric Adapter – Wall Mount

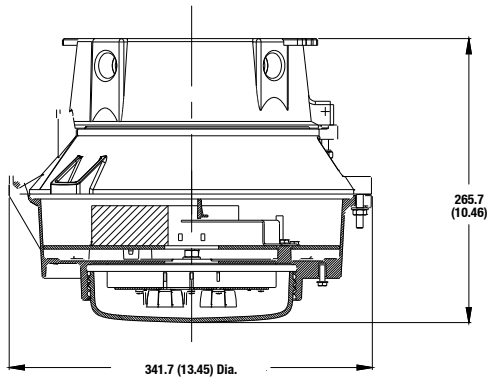

Centric Adapter – Ceiling Mount

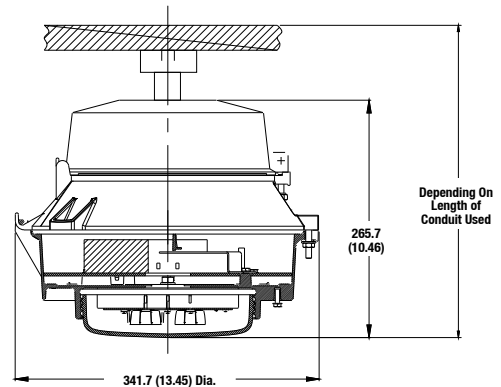

Centric Adapter – Pendant Mount

LIGHTING/LED/FLOODLIGHTS: NEC/CEC, ATEX/IECEx ENCLOSED AND GASKETED

Appleton