

# Juno® VuLite® Economy Recessed Lighting

## Viewing economy recessed downlighting in a different light

Take a new "view" on economy lighting with Juno VuLite. VuLite is an economic alternative for recessed lighting offering a selection of 4", 5" and 6" downlights for use in residential and light commercial applications. The line includes a range of popular trim selections including baffles, cones, adjustables and lensed, providing choices to meet the needs of

various lighting applications. Economy does not mean sacrificing the quality and standards you have come to expect from the Juno brand. You can buy and install VuLite products with total confidence knowing that all products are designed and tested to meet UL requirements and are backed by the leader in residential recessed lighting.

### VuLite Product Offering

#### 4" Housings and Trims

##### Line Voltage Housings



V4IC W



V4TC W



V4TCR W

##### Low Voltage Housings



V4ICLV W



V4TCLV W



V4TCRLV W

##### 4-inch Trims



Baffle



Clear Cone



Gimbal Ring



Eyeball



Flat Lens Shower

## 5" Housings and Trims

### Line Voltage Housings



V51C W



V51CR W



V5TC W



V5TCR W

### 5-inch Trims



Baffle



Clear Cone



White Cone



R/PAR20 Eyeball



PAR30 Eyeball



Flat Lens

## 6" Housings and Trims

### Line Voltage Housings



V61C W and V61CN W



V61CR W



V6TC W



V6TCR W

### 6-inch Trims



Baffle



Full Baffle



Clear Cone



Full Cone



Eyeball



Flat Lens Shower



Drop Opal



Open Frame


# VuLite® 4" Line Voltage Housings and Trims

## IC Housings

### V4IC W

4" IC New Construction  
Energy efficient double wall housing. May be covered with insulation.

Dimensions:  
12"L x 13-3/8"W x 6"H  
Ceiling Cutout: 4-1/2" Diameter

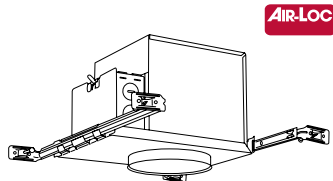

#### Accessories:


**G2405** Set of (4) T-bar clips for installation in suspended ceilings.

## TC Housings

### V4TC W

4" TC New Construction  
Requires 3" spacing from insulation.


Dimensions:  
12-1/8"L x 13-3/8"W x 5-1/2"H  
Ceiling Cutout: 4-1/2" Diameter

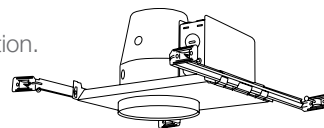

### V4TCR W

4" TC Remodel  
Requires 3" spacing from insulation.

Dimensions:  
12"L x 4-1/4"W x 5-1/2"H  
Ceiling Cutout: 4-3/8" Diameter

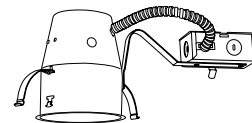

## 4" Compatible Trims - Line Voltage

### Baffle

**V4034 WWH** White  
**V4034 BWH** Black

Aperture: 3-7/8"  
Outer Diameter: 5"

#### Juno Compatible Housings: Lamp Wattage/Type

**V4IC W:** 50W PAR20, 30W R20  
**V4TC W, V4TCR W:** 50W PAR20, 50W R20  
**IC1P, TC1, TC1R:** 50W PAR20, 50W R20  
**IC1:** 50W PAR20, 30W R20



### Eyeball

**V4018 WH** White

Outer Diameter: 5"

#### Juno Compatible Housings: Lamp Wattage/Type

**V4IC W, V4TC W, V4TCR W:** 60W PAR16, 40W R16  
**IC1, IC1P, TC1, TC1R:** 60W PAR16, 40W R16




### Stippled Opal Lens Shower with Reflector

**V4012 WH** White

Outer Diameter: 5"

#### Juno Compatible Housings: Lamp Wattage/Type

(Remove reflector when using Juno IC1 housing)  
**V4IC W:** 35W PAR20, 30W R20  
**V4TC W, V4TCR W:** 50W PAR20, 50W R20  
**IC1:** 35W PAR20, 30W R20  
**IC1P:** 50W PAR20, 30W R20  
**TC1, TC1R:** 50W PAR20, 50W R20

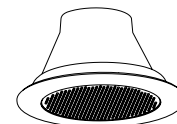


### Cone

**V4017 CWH** Clear

Aperture: 3-7/8"  
Outer Diameter: 5"

#### Juno Compatible Housings: Lamp Wattage/Type

**V4IC W, V4TC W, V4TCR W:** 50W PAR20, 50W R20  
**IC1, IC1P, TC1, TC1R:** 50W PAR20, 50W R20

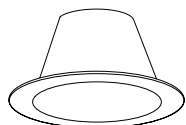


### Gimbal Ring

**V4010 WH** White  
**V4010 BN** Brushed Nickel

Outer Diameter: 5"

#### Juno Compatible Housings: Lamp Wattage/Type

 **V4IC W, V4TC W, V4TCR W:** 50W PAR20  
**IC1P, TC1, TC1R:** 50W PAR20



### Gimbal Ring

**V4040 WH** White  
**V4040 BN** Brushed Nickel

Outer Diameter: 5"

#### Juno Compatible Housings: Lamp Wattage/Type

**V4IC W:** 35W MR16, 35 PAR16 120V Medium Base  
**IC1, IC1P:** 35W MR16, 35W PAR16 120V Medium Base

