



DRIVEN TO OUTPERFORM.™

For the first time in power tool history, M18 FUEL™ products are delivering game-changing corded performance without the cord. The motors on MILWAUKEE® M18 FUEL™ tools are more powerful and energy efficient—outliving any other brand. To add to the revolutionary technology, M18 FUEL™ possesses the smartest electronics found in any power tool. REDLINK PLUS™ electronics manage an array of power requirements across more than 125 M18™ tools using one common battery. MILWAUKEE® built, the M18™ battery delivers cleaner, more consistent power, lasts longer and delivers more run-time in the harshest jobsite conditions.

M18 FUEL™. Feel the Difference.

M18 FUEL™

LONGER MOTOR LIFE | **MORE** POWER | **MORE** RUN-TIME

NOW AVAILABLE




REDLITHIUM
HIGH DEMAND 9.0

UP TO **5X** MORE RUN-TIME | UP TO **35%** MORE POWER | RUNS UP TO **60%** COOLER


1 POWERSTATE™ BRUSHLESS MOTOR

This best-in-class brushless motor works harder and lives longer than all leading competitors.

- MILWAUKEE® Designed and Built Brushless Motor
- Outperforms All Leading Competitors
- Longer Motor Life

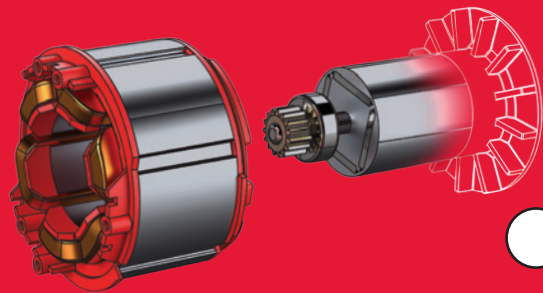


5
YEAR WARRANTY

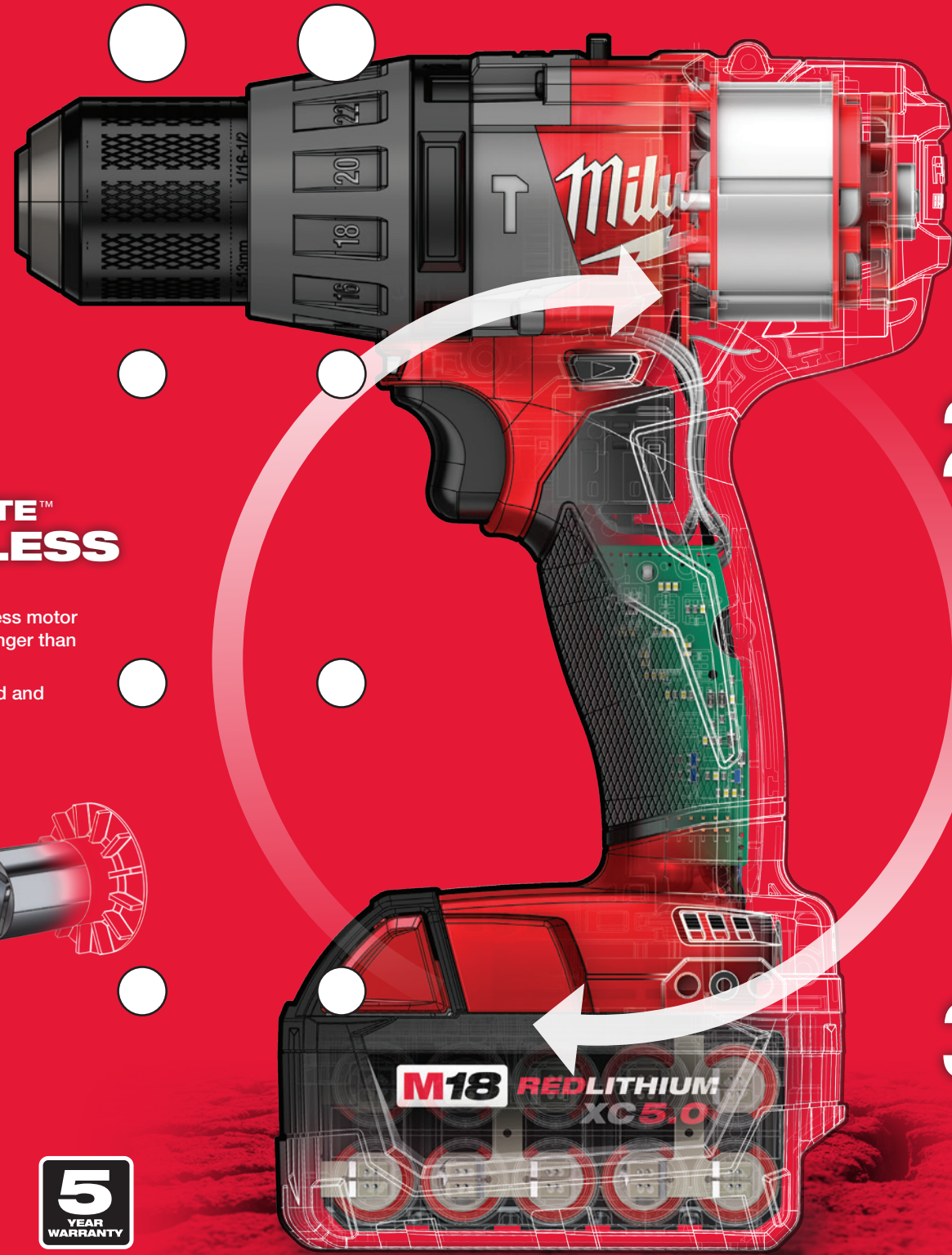

2 REDLINK PLUS™ INTELLIGENCE

The most advanced system of hardware and software in cordless power tool electronics today.

- Most Advanced Electronic System on the Market for Maximum Performance
- Total System Communication with Overload Protection Increases Tool Life

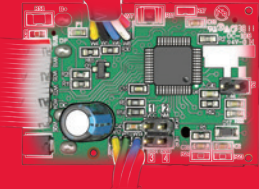

3 REDLITHIUM™ XC5.0 BATTERY PACK

Compatible with the entire M18™ system, it delivers more run-time, power and recharges than the competition.

- Most Durable Pack on the Market
- Over 2X More Recharges than Leading Competitor
- Fuel Gauge Displays Remaining Charge
- Operates Below -18°C / 0°F



M18 FUEL
1/2" Hammer Drill/Driver w/ ONE-KEY™ Kit

2706-22 (2706-20 Tool-Only)

Specifications:

Peak Torque	1,200 in-lbs
RPM	0 – 550 / 0 – 2,000
BPM	0 – 32,000
DRIVE CONTROL™	4-Mode (Customizable)
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-3/5"
Weight	4.9 lbs

Includes: (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Side Handle, Multi-Voltage Charger, Carrying Case



M18™ 1/2" Hammer Drill/Driver Kit

2607-22, 2607-22CT (2607-20 Tool-Only)

Specifications:

Peak Torque	525 in-lbs
RPM	0 – 450 / 0 – 1,800
BPM	0 – 28,800
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-3/4"
Weight	4.5 lbs

Includes: 2607-22 (2) M18™ REDLITHIUM™ XC Extended Capacity Battery Packs, Multi-Voltage Charger, Carrying Case; 2607-22CT Includes (2) M18™ REDLITHIUM™ Compact Battery Packs



M18 FUEL
1/2" Hammer Drill/Driver Kit

2704-22 (2704-20 Tool-Only)

Specifications:

Peak Torque	1,200 in-lbs
RPM	0 – 550 / 0 – 2,000
BPM	0 – 32,000
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-3/4"
Weight	4.9 lbs

Includes: (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Side Handle, Multi-Voltage Charger, Carrying Case



M18 FUEL
1/2" Drill/Driver w/ ONE-KEY™ Kit

2705-22 (2705-20 Tool-Only)

Specifications:

Peak Torque	1,200 in-lbs
RPM	0 – 550 / 0 – 2,000
DRIVE CONTROL™	4-Mode (Customizable)
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-1/5"
Weight	4.8 lbs

Includes: (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Side Handle, Multi-Voltage Charger, Carrying Case



M18™ 1/2" Compact Brushless Hammer Drill/Driver Kit

2702-22CT (2702-20 Tool-Only)

Specifications:

Peak Torque	1,500 in-lbs
RPM	0 – 450 / 0 – 1,800
BPM	0 – 28,800
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-3/8"
Weight	3.8 lbs

Includes: (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs, Multi-Voltage Charger, Carrying Case



M18 FUEL
1/2" Drill/Driver Kit

2703-22 (2703-20 Tool-Only)

Specifications:

Peak Torque	1,200 in-lbs
RPM	0 – 550 / 0 – 2,000
Chuck type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-1/2"
Weight	4.9 lbs

Includes: (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Side Handle, Multi-Voltage Charger, Carrying Case



M18™ 1/2" Compact Brushless Drill/Driver Kit

2701-22CT (2701-20 Tool-Only)

Specifications:

Peak Torque	500 in-lbs
RPM	0 – 450 / 0 – 1,800
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	6-7/8"
Weight	3.7 lbs

Includes: (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs, Multi-Voltage Charger, Carrying Case



M18™ 3/8" Right Angle Drill/Driver Kit

2615-21, 2615-21CT (2615-20 Tool-Only)

Specifications:

Peak Torque	125 in-lbs
RPM	0 – 1,500
Clutch Settings	11 Settings plus Drill Mode
Chuck Type	3/8" Single Sleeve
Head Profile	3-3/4"
Weight	4.3 lbs

Includes: 2615-21 (1) M18™ REDLITHIUM™ XC Extended Capacity Battery Pack, Multi-Voltage Charger, Carrying Case; 2615-21CT Includes (1) M18™ REDLITHIUM™ Compact Battery Pack



M18 FUEL
Drywall Screw Gun Kit

2866-22, 2866-22CT (2866-20 Tool-Only)

Specifications:

RPM	0 – 4,500
Belt Clip	Yes
Auto Start Mode	Yes
Length	9"
Weight	4.1 lbs

Includes: 2866-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, PR2 Bit, Multi-Voltage Charger, Contractor Bag; 2866-22CT Includes (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs



Related Accessory:
49-20-0001 MILWAUKEE® Collated Magazine
 Screw Capacity: Up to 2"
 Compatible with all major screw brands