

SL5-RGB(W) Outdoor Diffusion LED Strip

Description

Diffusion SL5-RGB is a flexible 12mm wide linear LED strip. Diffusion SL5-RGBW is a flexible 14mm wide linear LED strip. Both are available in 16' and 32' rolls that can be cut every 6 LEDs (100mm or 4").

Features

- Includes endcaps and mounting clips with screws
- Long life LED : 50,000 hrs
- Dimmable with dimming power supply
- 2' power feeds on both ends of every roll
- IP67

Custom lengths available upon request

Specifications


- RGB LED : 14.4 W/m (4.32 W/ft)
- RGBW LED : 19.2 W/m (6 W/ft)
- Lamp Life : 50,000 hrs LM80
- LED/Meter : 60/m (18/ft)
- Power Input : 24V DC

Lumens

RGB = Up to 591 lm/m (180 lm/ft)



W(2700K) = Up to 400 lm/m (122 lm/ft)

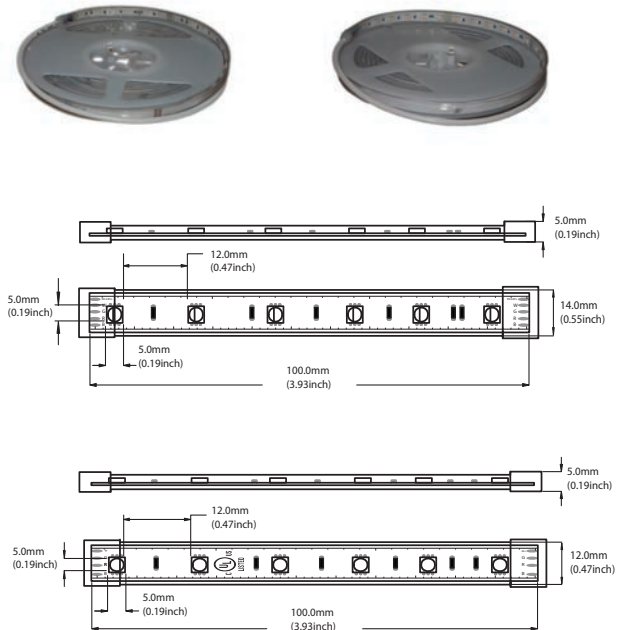

ORDERING
CODE

LENGTH

VOLTAGE

KELVIN

SL5-OUT — xx — 24V — xxxx

SL5-OUT

16 ft
32 ft

24 Volt

RGB
RGBW

- 1 BIN SELECTION
- 2 STEP MACADAM ELLIPSE
- 3 TEST QUALITY CONTROL

