

SL4 - Indoor Diffusion LED Strip

Description

Diffusion SL-4 is a flexible 5mm wide side mount linear LED strip. It is available in 16' rolls that can be cut every 6 LEDs (50mm or 2").

Features

- 3M industrial strength adhesive tape
- Long life LED : 50,000 hrs
- Dimmable with dimming power supply
- 2' power feeds on both ends of every roll

Custom lengths available upon request

Specifications



- LED : 10 W/m (3 W/ft)
- Lamp Life : 50,000 hrs LM80
- LED/Meter : 120/m (36/ft)
- Power Input : 24V DC
- CRI > 91

Lumens

3000K = 728 lm/m (222 lm/ft) 

4000K = 812 lm/m (247 lm/ft) 

Custom Kelvins available upon request

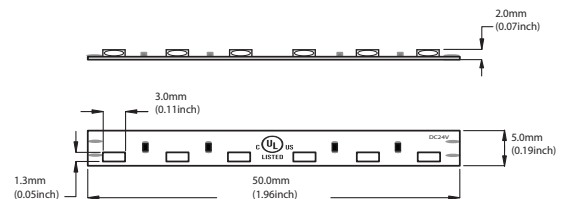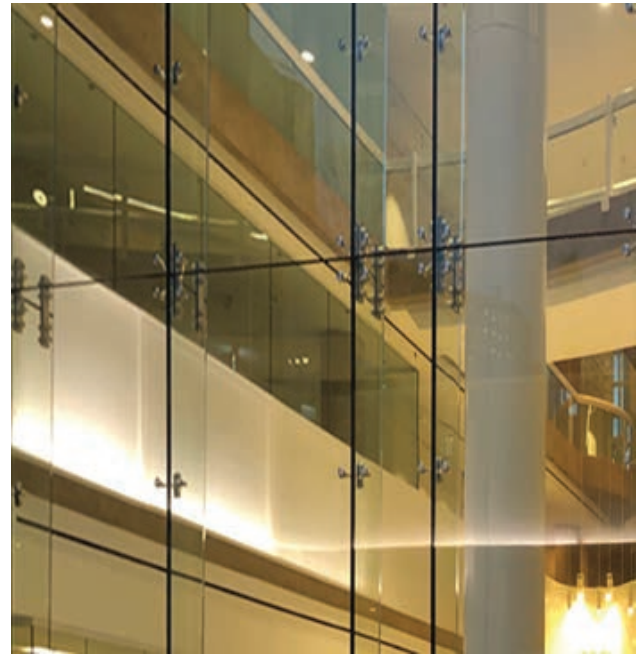

ORDERING
CODE

LENGTH

VOLTAGE

KELVIN

SL4-IN — XX — 24V — XXXX

SL4-IN

16 ft

24 Volt

3000 K
4000 K

- 1 BIN SELECTION
- 2 STEP MACADAM ELLIPSE
- 3 TEST QUALITY CONTROL

