

## CUT LEVEL 1 INSULATED WINTER GLOVES

**ULTIMATE WARMTH.  
ALL-DAY COMFORT.**



Size	1 Pair	12 Pair ( Contractor Pack)
S	48-22-8910	48-22-8910B
M	48-22-8911	48-22-8911B
L	48-22-8912	48-22-8912B

Size	1 Pair	12 Pair ( Contractor Pack)
XL	48-22-8913	48-22-8913B
XXL	48-22-8914	48-22-8914B

## CUT LEVEL 3 INSULATED WINTER GLOVES

**ULTIMATE WARMTH.  
ALL-DAY COMFORT.**



Size	1 Pair	12 Pair ( Contractor Pack)
S	48-22-8920	48-22-8920B
M	48-22-8921	48-22-8921B
L	48-22-8922	48-22-8922B

Size	1 Pair	12 Pair ( Contractor Pack)
XL	48-22-8923	48-22-8923B
XXL	48-22-8924	48-22-8924B

## LOCKING LANYARDS

**BEST SHOCK  
ABSORPTION™**



Double Locking Carabiner

Model #	Description
48-22-8810	10 lbs Locking Tool Lanyard
48-22-8811	10 lbs Extended Reach Locking Tool Lanyard
48-22-8815	15 lb Locking Tool Lanyard
48-22-8850	35 lbs Locking Tool Lanyard

## QUICK-CONNECT LOCKING TOOL LANYARD SYSTEM

**BEST SHOCK  
ABSORPTION™**

**QUICK-CONNECT  
LANYARD SYSTEM**



Quick Tool Change Out

Model #	Description
48-22-8820	10 lbs Quick-Connect Locking Tool Lanyard
48-22-8823	3 Pc 10 lbs Quick-Connect Lanyard Accessory
48-22-8822	3 Pc 5 lbs Quick-Connect Lanyard Accessory

## TAPE & D-RING WEB ATTACHMENTS

### EASILY CONNECT



48-22-8860



48-22-8870



48-22-8871




48-22-8872



Model #	Description
48-22-8860	12' Self-Adhering Tape
48-22-8870	5 Pc 2 lbs D-Ring Web Attachment
48-22-8871	5 Pc 5 lbs D-Ring Web Attachment
48-22-8872	35 lbs D-Ring Web Attachment

## SPLIT RINGS

### EASILY CONNECT

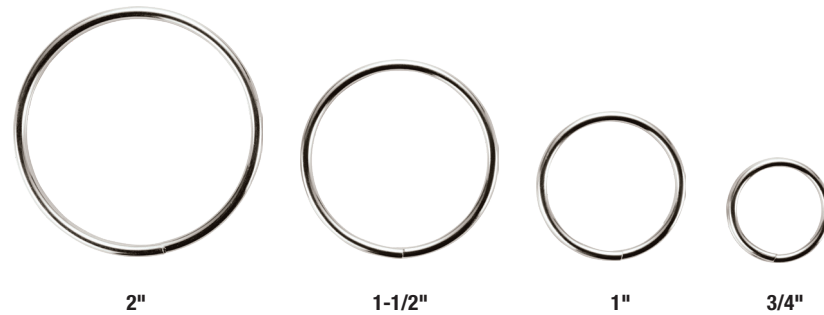

2"

1-1/2"

1"

3/4"



Model #	Description
48-22-8880	5 Pc 2 lbs 3/4" Split Ring
48-22-8881	5 Pc 2 lbs 1" Split Ring
48-22-8882	5 Pc 2 lbs 1-1/2" Split Ring
48-22-8883	5 Pc 2 lbs 2" Split Ring

- 2 TAPE MEASURES
- 4 LONG TAPES & MEASURING WHEELS
- 5 REDSTICK™ LEVELS
- 6 CONCRETE LEVELS & TORPEDO LEVELS
- 7 LASER DISTANCE METERS, CHALK REELS & FOLDING RULES
- 8 INKZALL™ JOBSITE MARKERS
- 9 INKZALL™ PAINT MARKERS, PENS & HIGHLIGHTERS
- 10 FASTENING PLIERS
- 11 FASTENING & CUTTING PLIERS
- 12 CUTTING PLIERS
- 13 COMBINATION & MULTI-FUNCTION PLIERS
- 14 APPLICATION SPECIFIC PLIERS
- 15 TORQUE LOCK™ PLIERS, C-CLAMPS & SPECIALTY
- 16 PIPE WRENCHES
- 18 ADJUSTABLE & BASIN WRENCHES
- 19 RATCHET & SOCKET SETS
- 20 COMBINATION WRENCHES & PRY BARS
- 21 HOOK AND PICK SET & MULTI-BIT DRIVERS
- 22 MULTI-BIT DRIVERS & SCREWDRIVERS
- 23 SCREWDRIVERS
- 25 NUT DRIVERS
- 26 HAMMERS & HAND CLAMPS
- 27 FIXED BLADE & POCKET KNIVES
- 28 POCKET KNIVES
- 29 UTILITY KNIVES
- 32 INSULATION & DUCT KNIVES
- 33 AVIATION SNIPS
- 34 TINNERS SNIPS
- 35 SCISSORS, SEAMER & CRIMPER
- 36 BOLT CUTTERS
- 37 HACKSAWS
- 38 SAWS
- 39 TUBING/PIPE CUTTERS & REAMING PEN
- 40 COPPER TUBING CUTTERS
- 42 LOW VOLTAGE VDV
- 44 PACKOUT™ MODULAR STORAGE
- 48 BAGS
- 49 COOLERS & BACKPACKS
- 50 BACKPACKS
- 52 ORGANIZERS
- 53 WORK BELTS & POUCHES
- 54 WORK GLOVES
- 55 DIPPED GLOVES
- 56 INSULATED WINTER GLOVES
- 57 LANYARD ACCESSORIES



**MILWAUKEE TOOL**  
**13135 West Lisbon Road**  
**Brookfield, WI 53005**

**[milwaukeetool.com](http://milwaukeetool.com)**

