


RIGID PVC CONDUIT
CONDUIT RIGIDE EN PVC

30° SCH40 BEND PE / 30° SCH40 COUDE BU

ISSUE DATE: 2009 02 20
DATE D'EMISSION:

SUPERSEDES: 2003 04 02
REPLACE:

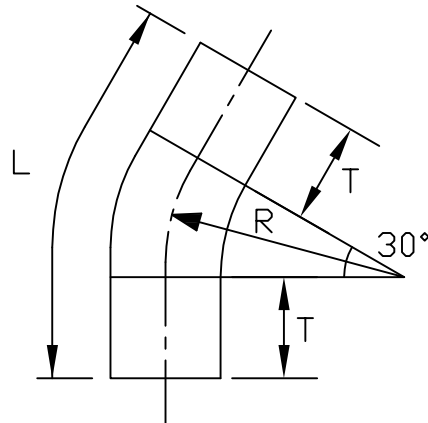

	CODE	Size Grosueur	L Ref.	R Ref.	T Ref.
KRALOY	# 068626 * 069247 # 078570	63mm (2.5")	308mm (12.125")	267mm (10.50")	89mm (3.50")
KRALOY	# 068627 * 069248 # 078571	78mm (3.0")	379mm (14.938")	330mm (13.0")	102mm (4.0")
KRALOY	# 068628 * 069249 # 078572	91mm (3.50")	479mm (18.875")	381mm (15.0")	140mm (5.50")
KRALOY	# 068629 * 069250 # 078573	103mm (4.0")	508mm (20.0")	406mm (16.0")	152mm (6.0")
KRALOY	# 068631 * 069251 # 078574	129mm (5.0")	813mm (32.0")	610mm (24.0")	248mm (9.75")
KRALOY	# 068632 * 069252 # 078575	155mm (6.0")	1016mm (40.0")	762mm (30.0")	305mm (12.0")

#- UL APPROVED / APPROUVES

*- CSA CERTIFIED / CERTIFIE

L-LENGTH OF PIPE BEFORE BENDING / LONGUEUR DU TUYAU AVANT D'ETRE COURBE