

TECHNICAL INFORMATION BULLETIN

MAGNETIC CFL BALLAST

PRE HEAT

ORDERING INFORMATION



Order code: 56611
 Description: 1L PLS- PLC13W 120
 Internal code: SP2RC
 UPC: 69549566118

GENERAL INFORMATION

Ballast type: Magnetic
 Starting method: Preheat Start
 Lamp connection: --
 Input voltage: 120Vac +5% -10%
 Frequency: 60HZ
 Class: P
 Type: 1 outdoor
 Sound rated: A

Lamp type	Number of lamps	Rated lamp watts	Min. start temp. (°F / °C)	Input watts (W)	Input current (A)	Ballast factor	B.E.F.	Power factor	THD %	Lamp crest factor
F14T8	1	16	50/10	16	0.33	0.80	5.00	0.40	15	1.7
F15T8	1	15	50/10	15	0.24	0.82	5.47	0.51	20	1.58
F18T8	1	15	50/10	15	0.25	0.68	4.53	0.56	15	1.57
F14T12	1	16	50/10	16	0.33	0.80	5.00	0.40	15	1.7
F15T12	1	15	50/10	15	0.22	0.85	5.31	0.45	15	1.60
F20T12	1	15	50/10	15	0.27	0.65	4.33	0.58	15	1.57
CFT13W/GX23, CFQ13W/GX23	1	15	50/10	15	0.24	0.90	6.00	0.51	20	1.69

WIRING DIAGRAM

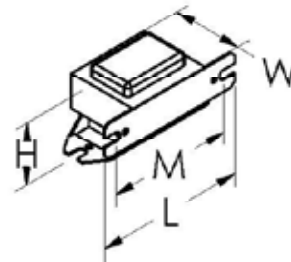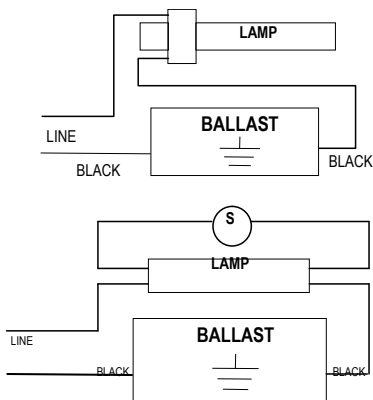

LEAD LENGTHS

Black

INCHES	7 x 15
mm	177.8 x 381

BALLAST FEATURES

Unit	M	W	L	H
INCHES	2.50	1.50	3.00	1.30
mm	63.5	38.1	76.2	33.02

WARRANTY:

Ballast warranty of 2 years for electromagnetic ballasts. Ballast warranty of 3 years for energy saving electromagnetic ballasts. For more information visit our website.



Data is based upon tests performed in a controlled environment and representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.



www.standardpro.com