

FUW-L

3 IN 1 LED FLOOD LIGHT/WALL PACK 22W and 40W (1830 lumens and 3293 lumens)

IP RATING
65



Approvals:
cULus listed
Suitable for wet locations



ICES
005



quick
ship

5
yr
warranty



Conduit mounting
shown

Surface mounting
shown


DESCRIPTION

The designed and versatile FUW-L is a highly efficient LED Flood Light and wall mount luminaire. This fixture is supplied with a photocell (120V), a wall bracket (for surface mounting), a wiring box (for feed-through mounting), and a 1/2" adjustable fitter that mounts on a standard box. This fixture is best suited for entrances, underpasses, or anywhere controlled security lighting is required, as well as general lighting of grounds, and floodlighting of signs and building fronts. The FUW-L is made of tough die cast aluminum housing and is IP65 rated. This fixture also has the option of adding a slipfitter or trunion.

TECHNICAL SPECIFICATIONS

- Die cast aluminum housing
- Integrated photocell (120V)
- Bronze UV resistant powder coat finish
- Input voltage: 120V AC
- High quality, long life LEDs
- Estimated lifespan of 50,000 hours
- 22W offers 1830 total lumens
- 40W offers 3293 total lumens
- 5000K colour temperature
- Low starting temperature of -40°C

DIMENSIONS

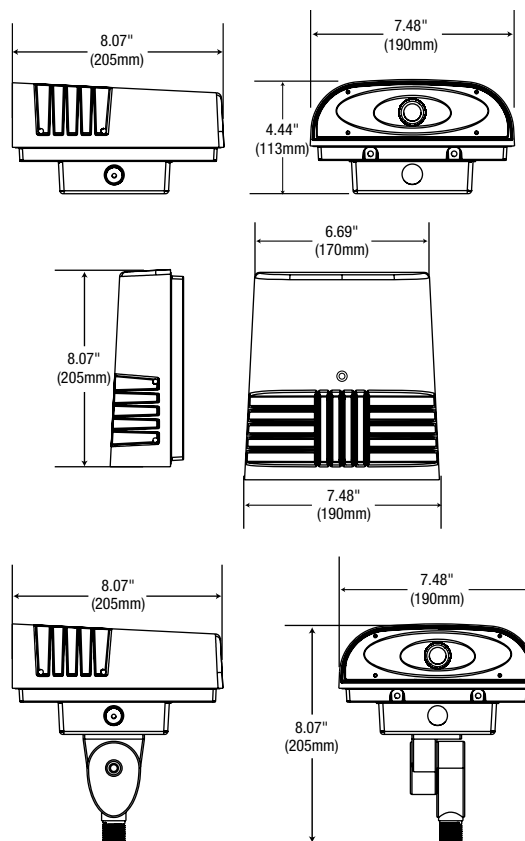

QUICK SHIP ORDERING GUIDE*

Part number	Wattage	Lumens	Voltage	Colour temperature	Efficacy
FUW-LS1-A/50K/P	40W	3293lm	120V	5000K	82lm/W

* **QUICK SHIP:** Product availability is subject to change without notice. Please contact your Stanpro customer service representative to confirm inventory levels at time of order.

ORDERING GUIDE

Series	Lamp type	Lumen package	Voltage	Colour temperature	Casting colour	Accessories
FUW	L - LED	S0 - 1830 Lumens (22W) S1 - 3293 Lumens (40W)	A - 120V (standard) G - 208-277V H - 347V	50K - 5000K	Blank - Bronze (standard) WH - White	A - Slipfitter TR - Trunion or Yoke mount