

SLA-2L

"EASY OUT" STEEL BATTERY UNIT

2 x 2W Crisp White LED heads

6VDC 36W Battery Capacity

Over 4 hours duration standalone unit

Approvals:
CSA Certified to C22.2 #141.15



DESCRIPTION

The commercial SLA-2L series features a steel battery unit designed to provide efficient and reliable emergency lighting. Utilizing a sturdy all steel housing, our series presents a modern and unobtrusive design containing two PAR18 small style heads with 2W crisp white LED. Available in 6VDC, the SLA-2L has over 4 hours duration as a standalone unit and the LED lamps have a limited lifetime warranty.

CIRCUITRY

- 120/347VAC 60Hz input, field selectable
- High efficiency, rapid recovery, precision control charging system
- 6VDC emergency power output versions (as specified)
- Wattage capacity: 36W
- Over 4 hours duration standalone unit
- Momentary push button test switch
- Diagnostic/pilot LED for AC ON and CHARGE
- Fully automatic, current limited charger
- Line latched, low voltage protection
- Solid state design and construction
- Brownout and short circuit protection
- Temperature compensated
- Complete battery recharge in 24 hours
- Maintenance free, sealed lead acid battery

MECHANICAL

- 120VAC line cord supplied standard
- Universal spider knockout pattern and keyhole mounting slots stamped into back of cabinet
- Multiple conduit entry knockouts
- White powder coat finish standard
- PAR18 small style, high impact thermoplastic heads
- 2 x 2W crisp white LED heads
- LED heads with limited lifetime warranty*

 
ORDERING GUIDE

SLA-2L


Series

SLA-2L

DIMENSIONS



Type N – PAR18
Thermoplastic

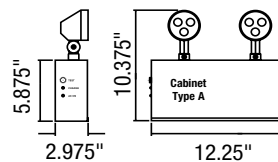

MODEL RATING

Model	Voltage	Wattage capacity			
		30 min.	60 min.	90 min.	120 min.
SLA-2L	6V	36	18	12	9

* For complete warranty details, please see our terms and conditions in our website