

L2WRN

LED SURFACE MOUNT WRAPAROUND



Approvals:
Meets requirements of ICES-005



quick
ship



Not all products are qualified on the DLC QPL. To view our DLC qualified products, please consult the DLC Qualified Products List at www.designlights.org/search.



DESCRIPTION

Stanpro's L2WRN is ideally suited for residential and light commercial applications (utility rooms, stairways, restrooms, etc.) where uniform and efficient lighting is required.

HOUSING & FINISHING

The shallow body is made of die-formed cold rolled steel, post-painted high gloss white.

LENS

Prismatic acrylic frosted K-12 pattern (0.1 inch). Two lens retaining clips included to secure the lens tightly to the fixture.

 

SPECIFICATIONS

- 80+ CRI
- THD < 20%
- Power factor of > 0.90
- Estimated lifespan of over 50 000 hours to L70
- Suitable for damp locations
- 0-10V dimmable ready standard
- Meets requirements of ICES-005 issue 4 for class A products
- Ambient temperature: -20°C to +50°C

MOUNTING

Surface mounting (wall and ceiling).

DIMENSIONS

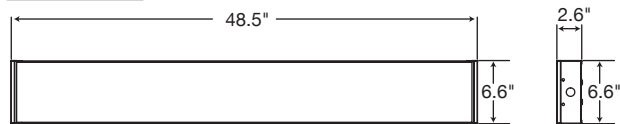

COMPATIBLE DIMMERS

Brand	Model number
Leviton	ILLUMATECH IP710-LFZ
Lutron	DIVADVSTV
Lutron	Maestro MS-Z101
Lutron	Nova T NTSTV
Philips	Sunrise SR1200ZTUNV

Dimming range 10%-100%.

Note: The following merely lists dimmers that have been tested.

QUICK SHIP

Part Number	Size	Lumens	CRI	Voltage	Colour temperature	Stocking SKU
L2WRN-48-1	48 - 48"	4548 lumens (40W)	80	120-277V	40K - 4000k	✓