


Ocal PVC-coated steel strut

Rugged steel channels protected by corrosion-resistant PVC


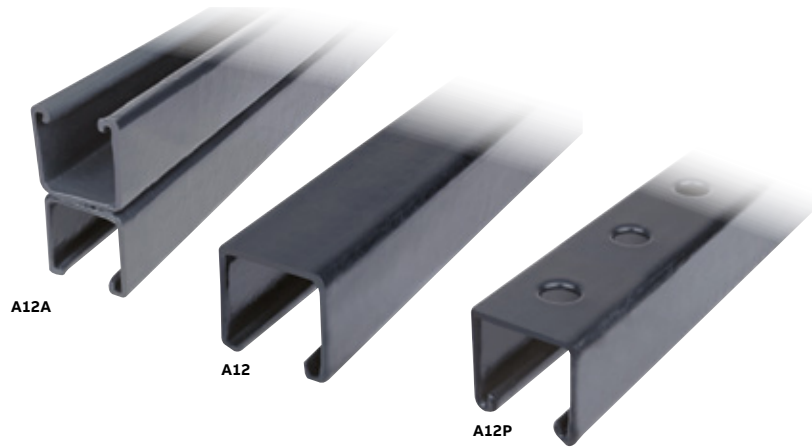


Product features

- Electro-galvanized zinc plated
- Nominal .007 - .015" (7 - 15 mil) PVC coating
- PVC coating available in your choice of blue, white or gray standard colors
- Custom colors also available on request
- Sold in 10-ft. (3.048m) lengths with standard length tolerance of $\pm 1/8"$ (3.18mm)
- Choose between standard $1\frac{5}{8}"$ (41.28mm) and shallow $1\frac{3}{16}"$ (20.64mm) depths
- Available in both solid and punched styles
- Not recommended for vertical applications

Ocal PVC-coated steel strut

Product Code	Style	Steel Thickness		Width x Height	
		Gauge	(mm)	(in.)	(mm)
A12- <u> </u>	Standard	12	2.65	1.63 x 1.63	41.28 x 41.28
A12A- <u> </u>	Back to Back	12	2.65	1.63 x 3.25	41.28 x 82.55
A12P- <u> </u>	Standard Punched	12	2.65	1.63 x 1.63	41.28 x 41.28
C14- <u> </u>	Shallow	14	1.89	1.63 x .81	41.28 x 20.64
C14P- <u> </u>	Shallow Punched	14	1.89	1.63 x .81	41.28 x 20.64

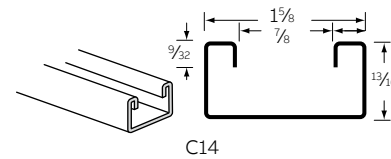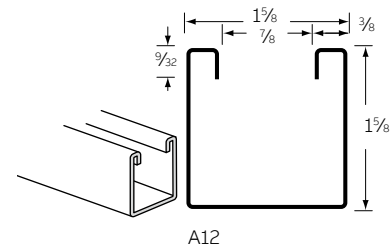

Cat. No.	Colour
----------	--------

A12-

 = space for color identifier

G = Gray

W = White

B = Blue

Custom colors also available.

All-thread rod

Continuously threaded rod for use with conduit hangers and strut to suspend overhead conduit runs



Product features

- All-thread steel rod coated with Nominal .007 - .015" (7 - 15 mil) PVC in blue, white or gray with custom colors available on request
- Available in 1/4", 3/8" or 1/2" standard diameters and in 3-, 6- or 10-ft. standard lengths
- Also available uncoated in Type 304 or Type 316 stainless steel
- Stainless steel all-thread rod comes in 3/8" or 1/2" diameters in 6-ft. standard lengths with other diameters and lengths available on request

Ocal PVC-coated steel all-thread rod

Cat. No.	Trade Size		Length	
	(in.)	(mm)	(ft.)	(mm)
THR1/4X10- <u> </u>	1/4	6.35	10.00	3.05
THR3/8X3- <u> </u>	3/8	9.53	3.00	0.91
THR3/8X6- <u> </u>	3/8	9.53	6.00	1.83
THR3/8X10- <u> </u>	3/8	9.53	10.00	3.05
THR1/2X3- <u> </u>	1/2	12.70	3.00	0.91
THR1/2X6- <u> </u>	1/2	12.70	6.00	1.83
THR1/2X10- <u> </u>	1/2	12.70	10.00	3.05

Stainless steel all-thread rod

Type 304 Stainless	Type 316 Stainless	Trade Size		Length	
Cat. No.	Cat. No.	(in.)	(mm)	(ft.)	(mm)
H104-3/8X6SS	H104 3/8X6SS316	3/8	9.53	6.00	1.83
H104 3/8X12SS	H104-3/8X12SS6	3/8	9.53	12.00	3.66
H104-1/2X6SSC	H104-1/2X6SS6	1/2	12.70	6.00	1.83
H104 1/2X12SS	H104 1/2X12SS316	1/2	12.70	12.00	3.66

Cat. No.	Diameter x Length	Colour
THR	3/8 x 3-	<u> </u>

 = space for color identifier

G = Gray 


W = White 

B = Blue 

Custom colors also available.

Ocal PVC-coated hanger rod beam clamps

Corrosion-protected clamps for hanging threaded rod

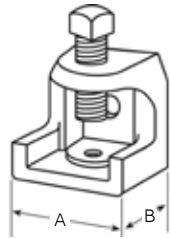

500-G
Hanger Rod Beam Clamp

Product features



 
- Malleable iron construction
- Nominal .007 - .015" (7 - 15 mil) PVC coating in blue, white, gray or custom colors
- 500, 502 and 503 also available uncoated in Type 316 stainless steel; add -SS316 to catalog number to order (for example: 502-SS316)

Ocal PVC-coated hanger rod beam clamps

Cat. No.	Base "A"		Base "B"		Jaw Opening		Tapped Hole		Load Rating [†]	
	(in.)	(mm)	(in.)	(mm)	(in.)	(mm)	(in.)	(mm)	(lbs)	(kg)
500- <u> </u>	1	25.40	1 ¹ / ₄	31.75	1 ⁵ / ₁₆	23.81	1 ¹ / ₄ -20	6.35 - 20	450	204.12
501- <u> </u>	1 ¹ / ₂	38.10	1 ⁵ / ₈	41.28	7 ⁷ / ₈	22.23	1 ⁵ / ₁₆ -18	7.94 - 18	800	362.87
502- <u> </u>	2	50.80	2	50.80	1	25.40	3 ³ / ₈ -16	9.53 - 16	1300	589.67
503- <u> </u>	2 ⁵ / ₈	66.68	2 ¹ / ₂	63.50	1	25.40	1 ¹ / ₂ -13	12.70 - 13	1300	589.67
508- <u> </u>	2 ¹ / ₂	63.50	2 ³ / ₈	60.33	2 ¹ / ₈	53.98	1 ¹ / ₂ -13	12.70 - 13	1700	771.11

* Metric size designator (ANSI C80.1-1994).

[†] Load ratings based on bottom hole of beam clamp with safety factor of three.
CSA File No. LR-52208

Cat. No.	Colour
500- <u> </u>	
<u> </u>	= space for color identifier
G = Gray	
W = White	
B = Blue	
Custom colors also available.	

Ocal PVC-coated mini conduit hangers

Includes stainless steel bolt and nut for fast, easy installation



MINE3/4-G
Mini Conduit Hanger

Product features

- Nominal .007 - .015" (7 - 15 mil) PVC coating in blue, white, gray or custom colors
- Rated for loads of up to 500 lbs (226.80kg) with a safety factor of three

Ocal PVC-coated mini conduit hangers

Cat. No.	Pipe Size (in.)	Metric Size Designator*
MINE1/2-__	1/2	16
MINE3/4-__	3/4	21
MINE1-__	1	27
MINE1-1/4-__	1 1/4	35
MINE1-1/2-__	1 1/2	41

* Metric size designator (ANSI C80.1-1994).

Cat. No.	Pipe Size (in.)	Metric Size Designator*
MINE2-__	2	53
MINE2-1/2-__	2 1/2	63
MINE3-__	3	78
MINE3-1/2-__	3 1/2	91
MINE4-__	4	103

Cat. No.	Colour
----------	--------

MINE1-

__ = space for color identifier

G = Gray

W = White

B = Blue

Custom colors also available.

Pipe straps for strut

Designed for easy attachment of conduit to strut



PVC-coated pipe strap

Just twist-insert these pipe straps anywhere you need them along the slot side of a channel. For additional flexibility, you can position the straps as closely as your pipe couplings permit.




Product features

- Combination slot and hex head bolt for flexibility of attachment
- Captivated square nut on shoulder enable easy one-handed tightening
- Use with either 1⁵/₈" or 1¹/₂" strut for greater versatility
- Shipped pre-assembled for easier counting, sorting and handling
- Available with nominal .007 - .015" (7 - 15 mil) PVC coating in your choice of blue, white or gray standard colors (custom colors also available on request)

Ocal PVC-coated strut pipe straps

Ocal PVC-Coated Strut Pipe Straps	Pipe Size (in.)	Metric Size Designator*
SS1/2- _	1/2	16
SS3/4- _	3/4	21
SS1- _	1	27
SS1-1/4- _	1 1/4	35
SS1-1/2- _	1 1/2	41
SS2- _	2	53
SS2-1/2- _	2 1/2	63
SS3- _	3	78
SS3-1/2- _	3 1/2	91
SS4- _	4	103
SS5- _	5	129

* Metric size designator (ANSI C80.1-1994).

Cat. No.	Colour
SS-1	
_ = space for color identifier	
G = Gray	
W = White	
B = Blue	
Custom colors also available.	

