

---

 TECHNICAL DATA SHEET

# Metallic covers, concealed service top

## 665-CST-M series, for use on floor boxes

### Steel City®



01



02



03

- 
- 01 Brass cover  
Part no.  
665-CST-M-BRS
- 02 Aluminum cover  
Part no.  
665-CST-M-ALM
- 03 Black cover  
Part no.  
665-CST-M-BLK

---

**Features:**

- Gaskets, installed
- Six inch insulated lanyard attached to frame and cover
- MopTite® Cover (When not in use)

---

**Applications:**
**For use on different floor types**

- Tile
- Carpet
- Wood floors

---

**Materials / Finishes:**

- Brass
- Aluminum
- Aluminum, black

---

**Rating:**

- 1,500 lb maximum load capacity

Metallic floor box covers are designed for use with 665 series concealed floor boxes.

**Certifications / Standards:**



---

**Conforms to:**


- UL 514 scrub water requirements for tile, carpet and wood floors (MopTite® Cover)

---


**Options:**

- Lid can be rotated to allow an interchange between open access, for cord exit and sealed unit, for not in use applications.

---

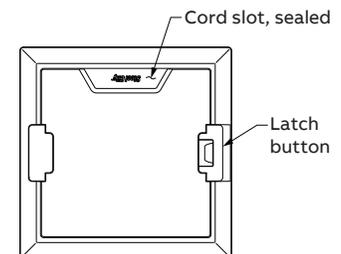**Closed  
Not -in- use:**

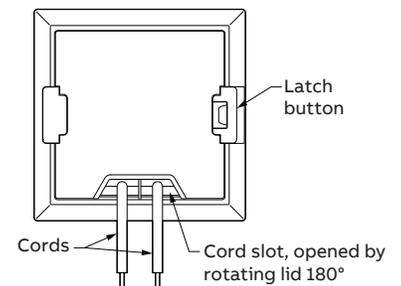

---

**Closed  
While -in- use:**


**Metallic covers, concealed service top**  
Drawing

