

# SKS

## KICK SPACE HEATER



### HIDE 'N HEAT

“Hide 'n heat” is what the SKS kick space heater by Stelpro offers. Its sleek, redesigned grille is slimmer than ever for easy installation in narrow spaces under kitchen or bathroom cabinets or in stair risers. Enjoy comfortable forced-air heating from the most discreet fan heater on the market.

#### POWER SELECTOR SWITCH

#### EASY INSTALLATION

#### ATTRACTIVE GRILLE ONE-PIECE, FRAMELESS

#### COLOURS

- **standard:** white, soft white
- **luxury finish:** stainless steel (see price list)
- **Orora (optional):** refer to [www.stelpro.com/en-CA/Orora](http://www.stelpro.com/en-CA/Orora)

#### FINISH

- epoxy-polyester powdercoat or stainless steel

#### MANUFACTURING

- 22-gauge steel cabinet and 16-gauge steel front
- quiet, 50 CFM capacity
- thermal protection with automatic reset
- added protection provided by a fuse-link (must be replaced once activated)

#### WATTAGE AND VOLTAGE

- power selector switch

#### ELEMENT

- tubular element sheathed with spiral-wound fins for improved heat dissipation

#### CONTROL

- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended
- built-in thermostat (optional)

#### INSTALLATION

- recessed

#### WARRANTY

- five years, \*three years on electronic components

#### IDEAL FOR:

under a kitchen or bathroom cabinet, in a stair riser

# STELPRO

Stelpro reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at [www.stelpro.com](http://www.stelpro.com).



FC\_SKS\_EN\_270420




## TECHNICAL SPECIFICATIONS

PRODUCT	POWER	VOLTAGE	THROW DISTANCE (IN FRONT)		HEAT RISE		WEIGHT		PRICE	
			CODE	WATTS	VOLTS	M	FT	°C	°F	KG
SKS1001	500 OR 1000	120	1.2	4	55	99	4.5	10	309.00	416.00
SKS1002	500/375 OR 1000/750	240/208	1.2	4	55	99	4.5	10	309.00	416.00

Add W for white, SW for soft white or SS for stainless steel (consult the optional colours chart or contact your Stelpro representative for all other colours).

## TECHNICAL DRAWINGS

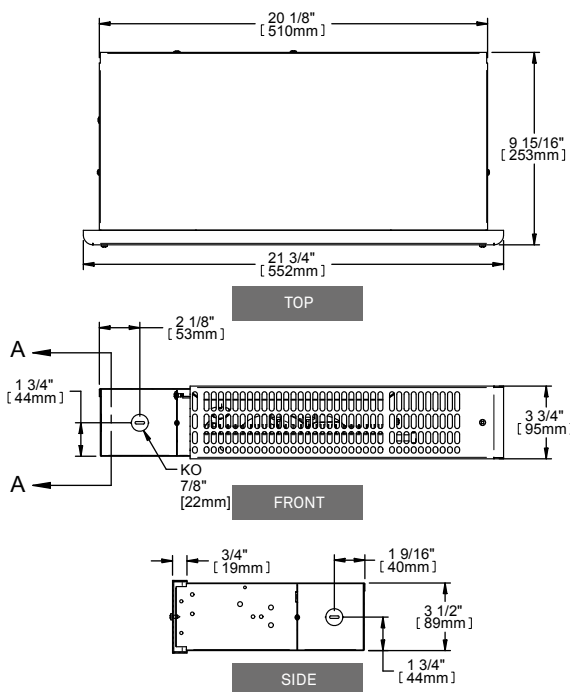

## ACCESSORIES

PRODUCT	DESCRIPTION	PRICE
SKST1	built-in single pole thermostat	49.00
SKST2	built-in tamper-proof double pole thermostat	63.00
SKSR*	extended grille (23 5/8 in. x 3 3/4 in. – 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project	59.25
SKSRSS	extended stainless steel grille (23 5/8 in. x 3 3/4 in. – 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project	80.50

\* Add W for white or SW for soft white.