


MP3-30G

[Print View..](#)
[Print to Pdf..](#)

General Information

Extended Product Type:	MP3-30G
Product ID:	1SFA611102R3002
EAN:	7320500268223
Catalog Description:	MP3-30G Pushbutton
Long Description:	Modular Pushbutton - Momentary - Extended - Green - Non-illuminated - Chrome metal - No contact block

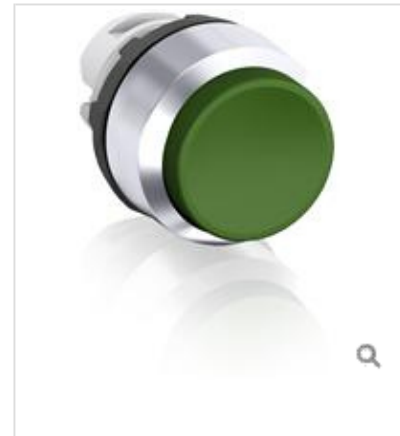

Categories

Products » Low Voltage Products and Systems » Control Products » Pilot
 Devices » Operator and Pilot Lights

Ordering

EAN:	7320500268223
Minimum Order Quantity:	10 piece
Customs Tariff Number:	85369001

Dimensions

Product Net Width:	0.029 m
Product Net Height:	0.029 m
Product Net Depth:	0.038 m
Product Net Weight:	0.026 kg

Container Information

Package Level 1 Units:	1 piece
Package Level 1 Width:	0.11 m
Package Level 1 Height:	0.029 m
Package Level 1 Length:	0.15 m
Package Level 1 Gross Weight:	0.026 kg

Environmental

Ambient Air Temperature:	Operation -25 ... +70 °C Storage -30 ... +85 °C
RoHS Status:	Following EU Directive 2002/95/EC August 18, 2005 and amendment

Additional Information

Actuator Type:	Extended
Bezel Material:	Chrome metal
Block:	No contact block
Color:	Green
Function:	Momentary
IIT Publishing Status:	Level 0 - Information enabled
Illumination:	Non-illuminated
Mechanical Durability:	2 million
Product Main Type:	MP3
Product Name:	Pushbutton

Product Range: Modular
Product Type: MP
RoHS Date: 0635 4

Certificates and Declarations (Document Number)

Declaration of Conformity - CE: 1SFA1-83
RoHS Information: 1SFC151011D0203

Classifications

E-nummer: 3715122
ETIM 4.0: EC002024 - Accessories for control circuit devices
ETIM 5.0: EC002024 - Accessories for control circuit devices
Object Classification Code: S
UNSPSC: 39121512
