


CP-B 24/10.0

[Print View..](#)
[Print to Pdf..](#)

General Information

Extended Product Type:	CP-B 24/10.0
Product ID:	1SVR427060R1000
EAN:	4016779782593
Catalog Description:	CP-B 24/10.0 Buffer module
Long Description:	CP-B 24/10.0 Buffer module 24 V / 10 A, energy storage 10000 Ws

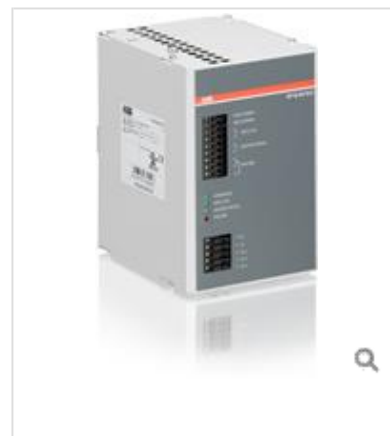

Categories

Products » Low Voltage Products and Systems » Control Products » Power Supplies

Ordering

EAN:	4016779782593
Minimum Order Quantity:	1 piece
Customs Tariff Number:	85044090

Dimensions

Product Net Width:	116.0 mm
Product Net Height:	170.0 mm
Product Net Depth:	147.0 mm
Product Net Weight:	2.100 kg

Container Information

Package Level 1 Width:	210.0 mm
Package Level 1 Length:	260.0 mm
Package Level 1 Height:	175.0 mm
Package Level 1 Gross Weight:	2.500 kg
Package Level 1 Units:	1 piece

Technical

Function:	Buffer module
Input Voltage (U_{in}):	24 V DC
Output Voltage (U_{out}):	24 V DC
Output Current:	10.00 A

Environmental

RoHS Status:	Following EU Directive 2002/95/EC August 18, 2005 and amendment
---------------------	---

Certificates and Declarations (Document Number)

cUL Certificate:	cUL508_E174460
Declaration of Conformity - CE:	1SAD938500-0158
EAC Certificate:	EAC_RU_C-DE.ME77.B.01651
GOST Certificate:	GOST_POCC_CN.AB76.B00924
RoHS Information:	1SAA981052-4401
UL Certificate:	UL508_E174460

Classifications

eClass:	7.0 27049002
ETIM 4.0:	EC002540 - DC-power supply
ETIM 5.0:	EC002540 - DC-power supply
Object Classification Code:	C
UNSPSC:	43172000
