


OHB145J12

ABB contact for Canada [Print to Pdf..](#)

General Information

Extended Product Type:	OHB145J12
Product ID:	1SCA022381R2110
EAN:	6417019124353
Catalog Description:	OHB145J12 Handle
Long Description:	IP 65, NEMA 1, 3R, 12. Indication in types OHB_ and OHY_: I-O/ON-OFF, in types OHG_: I-O, padlockable with 3 padlocks in OFF- position, door interlock in ON- position (defeatable), door drilling, see dimension drawings. The shaft has to be ordered separately.

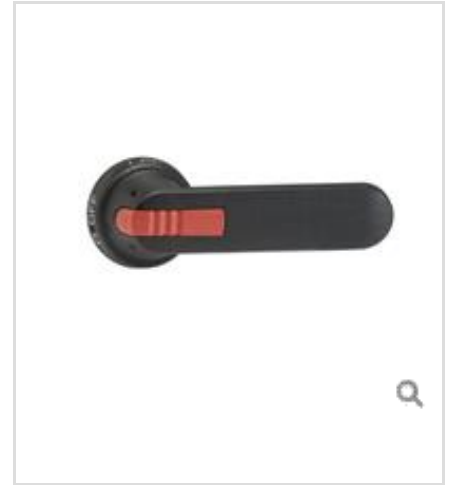

Categories

Products » Low Voltage Products and Systems » Switches » Switch
Disconnectors Accessories

Products » Low Voltage Products and Systems » Switches » Switch Fuses Accessories » Accessories for Switch
Fuses

Ordering

EAN:	6417019124353
Minimum Order Quantity:	1 piece
Customs Tariff Number:	85381000

Dimensions

Product Net Width:	70 mm
Product Net Length:	180 mm
Product Net Depth:	50 mm
Product Net Weight:	0.17 kg

Container Information

Package Level 1 Units:	1 piece
Package Level 1 Width:	70 mm
Package Level 1 Height:	50 mm
Package Level 1 Length:	180 mm
Package Level 1 Gross Weight:	0.17 kg
Package Level 1 EAN:	6417019124353

Environmental

RoHS Status:	Planned to follow EU Directive 2002/95/EC August 18, 2005 and amendment after 2006-07-01
---------------------	--

Additional Information

Color:	Black
Handle Length:	145.0 mm

Product Main Type: OHB 145J12
Product Name: Handle
Shaft Diameter: 12 mm
Suitable For: OT90A...315_

Certificates and Declarations (Document Number)

RoHS Information: 1SCC390010D0201

Classifications

E-nummer: 3171347
ETIM 5.0: EC000229 - Handle for power circuit breaker
Object Classification Code: N/A
