

# Day-Brite

## CFI

by Signify

### Surface & Suspended

Accessories & mounting hardware

	Surface Paralouwer	Surface Modular	HW Wrap	DW Straight Side Wrap**	Caravel Wrap***	OW Wrap	Slim Jim	N Strip	T Strip RS & Slimline	TH Strip 800 & 1500 mA	TW Strip Slimline	TW Strip 800 & 1500mA	Staggered Strip						
<b>Surface Mount</b>	✓	✓	✓	✓	✓	✓	✓	✓	✓		✓		✓						
<b>CS-400</b>	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓						
<b>CS-500</b>	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓						
<b>CEN-600</b>	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓						
<b>CEN-600-C</b>	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓						
<b>CTBH-1</b>							✓		✓										
<b>CTBH-2</b>							✓		✓										
<b>CTBH-3</b>											✓	✓							
<b>TC-1</b>							✓		✓		✓	✓							
<b>TC-2</b>										✓									
<b>TH-1</b>							✓		✓										
<b>TH-2</b>							✓		✓										
<b>TH-4</b>											✓	✓							
<b>TH-5</b>										✓									
<b>FKR-126</b>							✓		✓	✓	✓	✓							
<b>5988W*</b>							✓	✓	✓		✓								
<b>5977W*</b>							✓	✓	✓		✓								


 
 
 
 
 
 
 
 
 
 
See other side for illustrations.



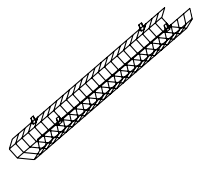
For "TS" Strip see page 1455-IF.

\* Use for luminaires 4' or less.

\*\* 3 lamp Designer Straight Side Wrap cannot be stem mounted.

\*\*\*Consult factory for stem mounting of 3 lamp Caravel.

Item	Catalog #	Description
	CS-400	Rigid Canopy order stems separately (one)
	CS-500	42" Top Swivel Canopy order stems separately (one)
	CEN-600	42" Top Swivel Canopy and Bottom Leveler (555146), order stems separately (one)
	CEN-600-C	42" Top Swivel Canopy bottom swivel to meet California standards. Includes two 555146 levelers, order stems separately (one)
	CS-3	Stem Coupler (one)
	CS-12 = 12" CS-18 = 18" CS-24 = 24" CS-30 = 30" CS-36 = 36" CS-48 = 48"	Stems, 3/8" Trade Size (5/8" O.D.) (Will work with 1/2" trade size K.O.'s which are actually 7/8" in diameter) (one) (locknuts are included with canopies above)
	CTBH-1 CTBH-2	"T" strip T-bar hangers flush mounting (one) 1-1/2" from ceiling mounting (shallow channel 1-7/8" Rapid Start & Slimline) (one)
	CTBH-3	1-1/2" from ceiling mounting (deep channel 2-3/4") (one)
	TC-1	"T" strip Heavy Duty Coupler (one)
	TC-2	"TH" strip Heavy Duty Coupler (one)
	TH-1	"T" strip Sliding Hangers flush mounting (shallow Rapid Start and Slimline) (one)
	TH-2	1-1/2" from ceiling mounting (shallow Rapid Start and Slimline) (one)
	TH-4	1-1/2" from ceiling mounting (deep 800 and 1500mA) (one)
	TH-5	"TH" strip Sliding Hanger 1-1/2" from ceiling mounting (one)

Item	Catalog #	Description
	FKR-126	Chain Hanger Set Includes two 5' heavy duty link chains with "V" hooks
	5988W 5977W	Hydee Hangers For 4' and smaller units only, includes two 5' chains and hooks 120V, 15 AMP Receptacle- NEMA 5-15R 277V, 15 AMP Receptacle- NEMA L7-15R
	CGS-4 CG-2 CG-3 CG-4	Wire Guards (not for use with "TW" or "TS" strips) For 4' "N" narrow cross section strip For 2' "T" strip For 3' "T" strip For 4' "T", "TH", or "HDS" strips (use 2 for 8')
	CM1G-2 CM1G-3 CM1G-4	For 2' "M" Strip, 1-lamp For 3' "M" Strip, 1-lamp For 4' "M" Strip, 1-lamp (use 2 for 8')
	CM1G-5 CM2G-2 CM2G-3 CM2G-4	For 5' "M" Strip, 1-lamp For 2' "M" Strip, 2-lamp For 3' "M" Strip, 2-lamp For 4' "M" Strip, 2-lamp (use 2 for 8')
	CM2G-5	For 5' "M" Strip, 2-lamp

Consult  
manufacturer's rep  
for applications  
using reflectors.

