


## ADJUSTABLE ALZAK® CONE ☆☆☆

Accent light with Alzak® cone offers non-glare optics for added visual comfort. Recessed lamp rotates 360° horizontally and 35° vertically, can be aimed without removing trim. Accomodate all ceiling type from 1/8" to 1" thick.

NON-IC REMODELER				NON-IC FRAME-IN-KIT		
300MRX	300ESX	3401MREX	303MRE	302MRX	302MREX	302ESX
50W MR-16	50W ES/ESD-16	50W MR-16	N/A	50W MR-16	50W MR-16	50W ES/ESD-16

IC FRAME-IN-KIT			AIRSEAL® IC FRAME-IN KIT		
302MRC7X	302MRC9X	302ESICX	302MRAICX	302MRAICEX	302ESAICX
50W MR-16	50W MR-16	50W ES/ESD-16	50W MR-16	50W MR-16	50W ES/ESD-16

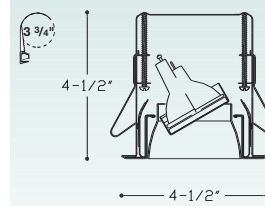

**304BAX** Specular black Alzak® cone and white flange

**304CLX** Specular clear Alzak® cone and white flange

**304GDX** Specular gold Alzak® cone and white flange

**304CCDX** Comfort clear™ diffuse cone and white flange



**BA**




**CL**



**GD**



**CCD**

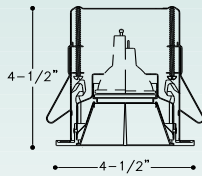

**372CHX** Chrome baffle and white flange

**372WHX** White baffle and flange

## CROSS BAFFLE ☆☆☆

Exclusive cross blade louver provides a well-shielded soft lighting effect. High reflectivity white or chrome reflector and white flange offered. Accommodate all ceiling type of 1/8" to 1" thick.

NON-IC REMODELER				NON-IC FRAME-IN-KIT		
300MRX	300ESX	3401MREX	303MRE	302MRX	302MREX	302ESX
50W MR-16	50W ES/ESD-16	50W MR-16	N/A	50W MR-16	50W MR-16	50W ES/ESD-16


IC FRAME-IN-KIT			AIRSEAL® IC FRAME-IN KIT		
302MRIC7X	302MRIC9X	302ESICX	302MRAICX	302MRAICEX	302ESAICX
N/A	50W MR-16	50W ES/ESD-16	50W MR-16	50W MR-16	50W ES/ESD-16



**CH**



**WH**

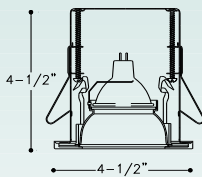

**377CHX** Frosted lens and chrome flange

**377WHX** Frosted lens and white flange

## SHOWER LIGHT (FLAT LENS) ☆☆

Simple architectural flange with frosted flat lens diffuser for a new appearance. Specially designed for wet locations such as shower (Gasket included). Accommodate all ceiling type from 1/8" to 1" thick.

NON-IC REMODELER				NON-IC FRAME-IN-KIT		
300MRX	300ESX	3401MREX	303MRE	302MRX	302MREX	302ESX
50W MR-16	N/A	50W MR-16	N/A	50W MR-16	50W MR-16	N/A

IC FRAME-IN-KIT			AIRSEAL® IC FRAME-IN KIT		
302MRIC7X	302MRIC9X	302ESICX	302MRAICX	302MRAICEX	302ESAICX
N/A	50W MR-16	N/A	50W MR-16	50W MR-16	N/A



**CH**



**WH**

## BASIC ADJUSTABLE TRUNCATED CONE ☆☆☆

Accent light with Alzak® Truncated Cone offers non-glare optics for added visual comfort. Recessed lamp rotates 360° horizontally and 45° vertically, can be aimed without removing trim. Accomodate all ceiling type from 1/8" to 1" thick.

NON-IC REMODELER				NON-IC FRAME-IN-KIT		
300MRX	300ESX	3401MREX	303MRE	302MRX	302MREX	302ESX
50W MR-16	50W ES/ESD-16	50W MR-16	N/A	50W MR-16	50W MR-16	50W ES/ESD-16


IC FRAME-IN-KIT			AIRSEAL® IC FRAME-IN KIT		
302MRC7X	302MRC9X	302ESICX	302MRAICX	302MRAICEX	302ESAICX
N/A	50W MR-16	50W ES/ESD-16	50W MR-16	50W MR-16	50W ES/ESD-16



**CH**



**BS**

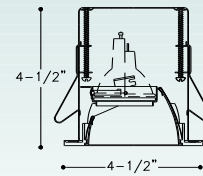

**384CHX** Chrome and white flange

**384BSX** Brass and white flange

## BASIC ADJUSTABLE TRUNCATED BAFFLE ☆☆☆

Accent light with Alzak® Truncated Baffle offers non-glare optics for added visual comfort. Recessed lamp rotates 360° horizontally and 45° vertically, can be aimed without removing trim. Accomodate all ceiling type from 1/8" to 1" thick.

NON-IC REMODELER				NON-IC FRAME-IN-KIT		
300MRX	300ESX	3401MREX	303MRE	302MRX	302MREX	302ESX
50W MR-16	50W ES/ESD-16	50W MR-16	N/A	50W MR-16	50W MR-16	50W ES/ESD-16


IC FRAME-IN-KIT			AIRSEAL® IC FRAME-IN KIT		
302MRC7X	302MRC9X	302ESICX	302MRAICX	302MRAICEX	302ESAICX
N/A	50W MR-16	50W ES/ESD-16	50W MR-16	50W MR-16	50W ES/ESD-16



**BK**



**WH**

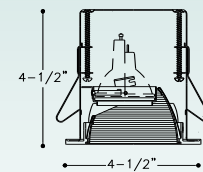

**385BKX** Black phenolic step baffle and white flange

**385WHX** White phenolic step baffle and white flange