


Service Entrance Cable Fittings

Oil- and water-resistant neoprene bushing specially designed for sealing around underground feeder cable!

Underground Liquidtight Feeder-Cable Fittings

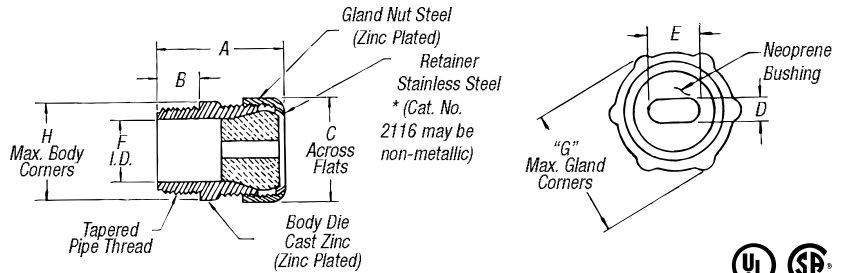


- Stainless steel retaining ring provides bearing surface for glandnut and eliminates cable twist
- Ribbed glandnut tightens easily with wrench to form high-strength connection

CAT. NO.	HUB SIZE	CABLE OPENING	DIMENSIONS (IN.)										
			A	B	C	D		E		F	G	H	
						MIN.	MAX.	MIN.	MAX.				
2116-TB*	1/2"	.235 x .500	1 1/16	3/8	1	.060	.235	.350	.350	.500	3/16	1 1/8	1 1/8
2237	3/4"	.230 x .430	1 1/16	3/8	1 1/32	.080	.230	.320	.320	.430	1/16	1 3/8	1 3/8
2238	3/4"	.235 x .465	1 1/16	3/8	1 1/32	.050	.235	.340	.340	.465	1/16	1 3/8	1 3/8
2239	3/4"	.240 x .685	1 1/16	3/8	1 1/32	.060	.240	.500	.500	.685	1/16	1 3/8	1 3/8

* Not CSA Certified
UL File No. E-23017
CSA File No. 2884

Rocking action of foot allows each strap to accept a wide range of wire sizes!

Cable Straps

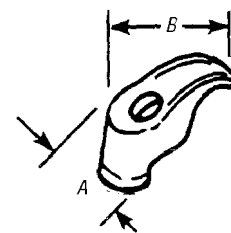

- Hole for 1/4" screw
- Hot-dipped galvanized malleable iron construction

CAT. NO.	WIRE SIZE	DIMENSIONS (IN.)	
		A	B
1341-TB	2-#10	3/8	1 1/8
1344	3-#6 or 3-#8	3/8	1 15/16
1345*	3-#4 or 3-#2	13/16	1 59/64
1346	3-1/0	3/4	2 1/16
1347	3-4/0	3/4	2 25/32

* Steel, hot-dipped galvanized.
UL not applicable
CSA Certified