

# CADDY PYRAMID



CADDY PYRAMID

# CADDY PYRAMID

## CADDY PYRAMID EZ Rubber-Based Support

- Quick height adjustment accommodates for uneven roofs or sloped condensate lines
- No tools or fasteners needed; fast snap-on installation
- Design sheds water and helps reduce pipe corrosion
- Roof-friendly; made of UV-stabilized EPDM material



Patent No.: 8,356,778


Material: EPDM-SBR Rubber

Part Number	Description	F ↓
RPSE1H24	1" Rigid/Pipe, 1.315" OD, 1 3/4"-4"	170 lb
RPSE1H57	1" Rigid/Pipe, 1.315" OD, 5"-7"	170 lb
RPSE2H46	2" Rigid/Pipe, 2.37" OD, 4"-6"	250 lb
RPSE4H46	4" Rigid/Pipe, 4.5" OD, 4"-6"	400 lb

Ultimate load at 1/4" (6.35 mm) deflection. Contact project or roofing engineer for maximum allowable load on individual project roof system.

## CADDY PYRAMID Universal Support

- Captive stainless steel nuts allow for custom attachment methods to the support base including easy attachment of stainless steel strut, threaded rod or other project-specific hardware
- Foam bottom offers low abrasion interface for better roof membrane protection
- Compatible with roof surfaces including single ply, bituminous, metal and spray foam
- Provides superior load distribution, even with varying rooftop surfaces
- Multiple sizes and load ratings offer the ability to tailor the solution to the application
- Base is manufactured from UV-stabilized thermoplastic material
- Supports green building requirements; thermoplastic bases are made from recycled material and can contribute to earning LEED credits

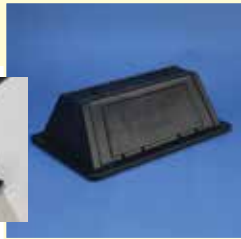

CADDY PYRAMID

Material: Polyethylene; Polypropylene; Stainless Steel 18-8  
Temperature: -50 to 150 °F  
Static Load Safety Factor: 3:1

Part Number	Description	F ↓
PBU6	5 1/2" x 4"	300 lb
PBU10	10" x 4"	1,000 lb
PBU16	16" x 4"	1,500 lb

