

**TYPE 4 AND 4X DEEP-HINGED WINDOW KITS**



**INDUSTRY STANDARDS**

**Stainless Steel**

UL 508A Listed; Type 3R, 4, 4X, 12; File No. E61997  
 cUL Listed per CSA C22.2, No. 94; Type 3R, 4, 4X, 12; File No. E61997

NEMA/EEMAC Type 3R, 4, 4X, 12  
 IEC 60529, IP66

**Mild Steel**

UL 508A Listed; Type 4, 12; File No. E61997  
 cUL Listed per CSA C22.2 No. 94; Type 4, 12; File No. E61997

NEMA/EEMAC Type 4, 12

**APPLICATION**

Deep-hinged window kits provide protection, visibility and easy access to equipment and components installed behind the viewing area. Window kits are conveniently sized to allow direct mounting in the usable door area of Hoffman NEMA and CONCEPT® wall-mount enclosures, as well as any Hoffman enclosure with a suitably sized mounting surface. Deep-hinged window kits provide protection, visibility and easy access to equipment and components installed behind the viewing area. These kits have an aesthetic appearance, quarter-turn latching for easy access, .25-in. (6-mm) thick, clear polycarbonate material for viewing, 2.5-in. (64-mm) depth to allow for deep controls and a built-in gasket compression stop to facilitate flush mounting. Each kit comes with a mounting template and hardware to allow for easy installation and can be mounted either left or right hinged.

**SPECIFICATIONS**

- Manufactured from Type 316L stainless steel or painted mild steel
- Quarter-turn latches for quick access
- 0.25-in. (6-mm) thick, clear polycarbonate windows for easy viewing
- 2.5-in. (64-mm) deep to allow for deep controls
- Built-in gasket compression stop on back of window kit facilitates flush mounting
- Designed for either left or right hinging
- Includes mounting template and mounting hardware
- Easy-to-remove clip-style hinge pin

**FINISH**

- Stainless steel: Enclosures are unpainted; door and body have a smooth #4 brushed finish
- Mild steel: ANSI 61 gray polyester powder paint inside and out

**ACCESSORIES**

Touch-up Paint (ATPPY61)


**OPTIONS**

- Optional Handles**
- CWHNL** - Nonlocking
- CWHK** - Keylocking
- CWHPTO** - Padlocking

**BULLETIN: A80SW, A80W**

Standard Product

Catalog Number	AxBxC in./mm	Material	Window Size M x N in./mm
AWDH1418N4	12.19 x 14.56 x 2.73 310 x 370 x 69	Steel	8.68 x 9.83 220 x 250
AWDH1418N4SS	12.19 x 14.56 x 2.73 310 x 370 x 69	316L Stainless steel	8.68 x 9.83 220 x 250
AWDH1612N4	14.19 x 8.14 x 2.73 360 x 207 x 69	Steel	10.68 x 3.41 271 x 87
AWDH1612N4SS	14.19 x 8.14 x 2.73 360 x 207 x 69	316L Stainless steel	10.68 x 3.41 271 x 87
AWDH2016N4	18.19 x 12.14 x 2.73 462 x 308 x 69	Steel	14.68 x 7.41 373 x 188
AWDH2016N4SS	18.19 x 12.14 x 2.73 462 x 308 x 69	316L Stainless steel	14.68 x 7.41 373 x 188
AWDH2416N4	22.19 x 12.14 x 2.73 563 x 308 x 69	Steel	18.68 x 7.41 474 x 188
AWDH2416N4SS	22.19 x 12.14 x 2.73 563 x 308 x 69	316L Stainless steel	18.68 x 7.41 474 x 188
AWDH2420N4	22.19 x 16.14 x 2.73 563 x 410 x 69	Steel	18.68 x 11.41 474 x 290
AWDH2420N4SS	22.19 x 16.14 x 2.73 563 x 410 x 69	316L Stainless steel	18.68 x 11.41 474 x 290
AWDH2430N4	22.19 x 26.14 x 2.73 563 x 664 x 69	Steel	18.68 x 20.22 474 x 514
AWDH2430N4SS	22.19 x 26.14 x 2.73 563 x 664 x 69	316L Stainless steel	18.68 x 20.22 474 x 514
AWDH3024N4	28.19 x 20.14 x 2.73 716 x 512 x 69	Steel	24.68 x 14.22 627 x 361
AWDH3024N4SS	28.19 x 20.14 x 2.73 716 x 512 x 69	316L Stainless steel	24.68 x 14.22 627 x 361
AWDH3624N4	34.19 x 20.14 x 2.73 868 x 512 x 69	Steel	30.68 x 14.22 779 x 361
AWDH3624N4SS	34.19 x 20.14 x 2.73 868 x 512 x 69	316L Stainless steel	30.68 x 14.22 779 x 361

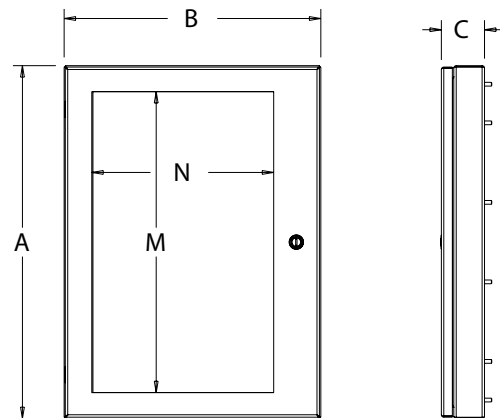

87948405