

Cable/Conduit




Cable/Conduit

Cable/Conduit


 

Clamps and Clips

Push In Conduit Clamp

- Push-in installation of conduit
- Eliminates need for offset bending conduit
- May be used for either vertical or horizontal installations

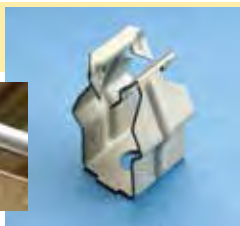


Material: Spring Steel
Finish: CADDY® ARMOUR

Part Number	Description			
8P4I	1/2" EMT, 1/4" Hole, Threaded	25 lb	15 lb	100 pc
8P	1/2" EMT, 9/32" Hole, Plain	25 lb	15 lb	100 pc
12P4I	3/4" EMT, 1/4" Hole, Threaded	25 lb	15 lb	100 pc
12P	3/4" EMT, 9/32" Hole, Plain	25 lb	15 lb	100 pc
16P4I	1" EMT, 1/4" Hole, Threaded	25 lb	15 lb	100 pc
16P	1" EMT, 9/32" Hole, Plain	25 lb	15 lb	100 pc

 
 

Snap Close Conduit/Pipe Clamp

- May be used for either vertical or horizontal installations
- Helps to guide alignment with electrical box knockouts
- Finger closure

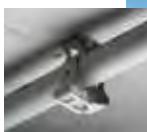

Material: Spring Steel
Finish: CADDY® ARMOUR



Part Number	Description			
6M4I	3/8" Flexible, 14-2 to 12-3 MC/AC, 1/4" Hole, Threaded	100 lb	25 lb	100 pc
6M	3/8" Flexible, 14-2 to 12-3 MC/AC, 9/32" Hole, Plain	100 lb	25 lb	100 pc
812M4I	1/2", 3/4" EMT, 1/2", 3/4" Rigid/Pipe, 1/4" Hole, Threaded	100 lb	25 lb	100 pc
812M	1/2", 3/4" EMT, 1/2", 3/4" Rigid/Pipe, 9/32" Hole, Plain	100 lb	25 lb	100 pc
16M4I	1" EMT, 1" Rigid/Pipe, 1/4" Hole, Threaded	100 lb	25 lb	100 pc
16M	1" EMT, 1" Rigid/Pipe, 9/32" Hole, Plain	100 lb	25 lb	100 pc
20M4I	1 1/4" EMT, 1 1/4" Rigid/Pipe, 1/4" Hole, Threaded	100 lb	25 lb	100 pc
20M	1 1/4" EMT, 1 1/4" Rigid/Pipe, 9/32" Hole, Plain	100 lb	25 lb	100 pc
24M4I	1 1/2" EMT, 1 1/2" Rigid/Pipe, 1/4" Hole, Threaded	100 lb	25 lb	100 pc
24M	1 1/2" EMT, 1 1/2" Rigid/Pipe, 9/32" Hole, Plain	100 lb	25 lb	100 pc
32M4I	2" EMT, 2" Rigid/Pipe, 1/4" Hole, Threaded	100 lb	25 lb	100 pc
32M	2" EMT, 2" Rigid/Pipe, 9/32" Hole, Plain	100 lb	25 lb	100 pc

