

Threaded Rod Hangers




Threaded Rod Hangers

 
Threaded Rod Hangers

Hammer-On Flange Clip, Bottom Mount with Retainer

- Only one piece to install
- Fast hammer-on installation
- Riveted retainer strap replaces cumbersome assemblies and hardware
- Retainer strap is easily bent into position
- Lightweight design
- 1/4" x 3/8" stud included

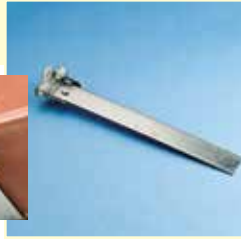


 

Material: Spring Steel
Finish: CADDY ARMOUR

Part Number	Description	
CM24S	1/8"–1/4" Flange	75 lb
CM58S	5/16"–1/2" Flange	75 lb
CM912S	9/16"–3/4" Flange	75 lb

Hammer-On Flange Clip, Side Mount

- Provides a "portable" hole
- Fits most beams and bulb tees
- Installs with just a hammer

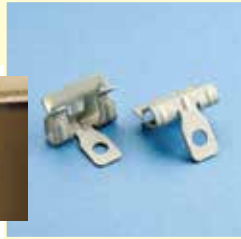

Part Number	Description			Certifications
Material: Spring Steel — Finish: CADDY ARMOUR				
2H4	3/32"–9/64" Flange	160 lb	100 pc	cULus
4H24	1/8"–1/4" Flange	200 lb	100 pc	cULus
4H58	5/16"–1/2" Flange	200 lb	100 pc	cULus
4H912	9/16"–3/4" Flange	200 lb	100 pc	cULus
Material: Stainless Steel 301				
4H24SS	S301, 1/8"–1/4" Flange	140 lb	100 pc	–
4H58SS	S301, 5/16"–1/2" Flange	140 lb	100 pc	–
4H912SS	S301, 9/16"–3/4" Flange	140 lb	100 pc	–