

Cable/Conduit

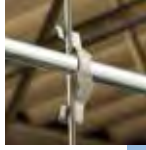


Cable/Conduit

Cable/Conduit Rod/Wire

 
 

Cable/Conduit Clip

- Supports conduit to rod, wire or flange
- Can also be used for flexible metallic tubing, armored cable, portable cables, control tubes and communications cable
- Available for EMT, rigid, ENT, IMT, MC/AC and aluminum conduit
- No installation tools required



Material: Spring Steel
Finish: CADDY® ARMOUR



Part Number	Description				Certifications
K8	1/2" EMT, 1/2" Rigid, 12-3 MC/AC	25 lb	50 lb	100 pc	cULus
K12	1/2", 3/4", 1" EMT, 1/2", 3/4" Rigid	25 lb	50 lb	100 pc	cULus
K16	3/4", 1" EMT, 1/2", 3/4" Rigid	25 lb	50 lb	100 pc	cULus
K20	1", 1 1/4" EMT, 3/4", 1" Rigid	25 lb	50 lb	100 pc	cULus
KX	14-2 to 12-3 MC/AC	-	-	100 pc	cULus
KXBP	14-2 to 12-3 MC/AC	-	-	1 pc	-

May require dedicated drop wire/rod and EC311. Consult local authority.
For horizontal application only when using plain rods.

Cable/Conduit

Conduit Size	#10 or #12 Wire	#8 or #10 Wire	3/16" or 1/4" Rod	1/8" - 1/4" Flange	5/16" - 3/8" Flange	7/16" - 1/2" Flange
1/2" EMT	K8	K8	K8	K8	K12	K12
1/2" Rigid	K8	K12	K12	K12	K12	K16
3/4" EMT	K12	K12	K12	K12	K16	K16
3/4" Rigid	K12	K12	K16	K16	K20	K20
1" EMT	-	K12	K16	K16	K20	K20
1" Rigid	-	-	-	K20	K20	K20
1 1/4" EMT	-	K20	K20	K20	-	-

Cable Size	#12 Wire	#8, #9, #10 Wire
14-2 (.433" - .475" OD)	KX	KX
14-3 (.453" - .500" OD)	KX	KX
12-2 (.467" - .510" OD)	KX	KX
12-3 (.489" - .535" OD)	KX	K8

