


# 3M™ Dual Lock™ Reclosable Fasteners

## Holding Power to Replace Screws, Bolts and Rivets

Durable enough to last through repeated opening and closing. Unique mushroom-shaped heads snap shut and stay locked.

- Durable — up to 1,000 openings and closings before losing 50% of original tensile strength
- Helps reduce vibration
- Temperature, moisture and UV resistant
- Strong, pressure-sensitive adhesive bonds on contact
- Interlocking mushroom-shaped heads have **5X the tensile strength** of hook-and-loop products

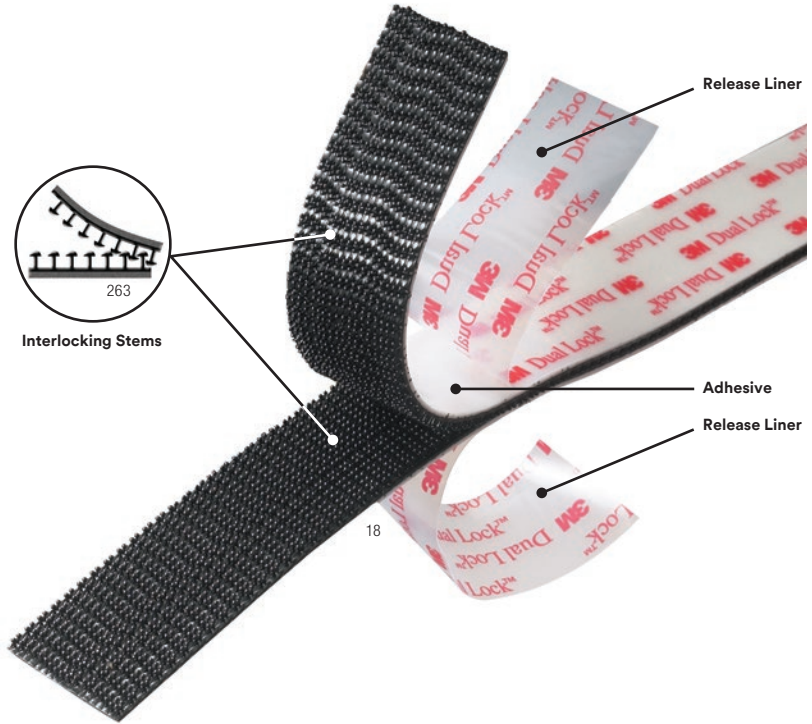

Secure plastic signs to window glass. 39



Anchor vehicle accessories to dashboard. 266



Attach elevator control panel to interior wall. 267



Fasten ceiling panels to interior for future access. 268



Attach access panels to industrial, electronic and electrical equipment. 27

# 3M™ Dual Lock™ Reclosable Fasteners and Applications



- Best Suggested Product
- Primer Recommended
- ▲ Performance Dependent on Selected Attachment Method

Product	Stem Density (per sq/in)	Adhesive	Color	3M Liner	Engaged Thickness	Temperature Resistance °F (°C)	Substrates					Use	Markets											
							Metals (Al & SS)	Glass	Plastics (Acrylic, PC, ABS)	Powder Coated Paints	Low Surface Energy (PP, PE)		Aerospace & Rail	Appliance & Electronics	Design & Construction	Furniture & Upholstery	General Industrial	Marine & Specialty Vehicle	POP, Display & Signage					
SJ3540	250	Rubber	Black	White, 5 mil (0.13mm) Polyolefin	0.23 in (5.7mm)	120 (49)	■		■	■	■	Indoor												
SJ3541	400																							
SJ3542	170																							
SJ3550	250	White Acrylic	Black	Clear, 4 mil (0.10mm) Polyolefin	0.23 in (5.7mm)	200 (93)	■	■	■	●	●	Indoor/Outdoor	■	■	■	■	■	■	■	■	■			
SJ3551	400																							
SJ3552	170																							
SJ3558	250	White Acrylic	Clear*	Clear, 4 mil (0.10mm) Polyolefin	0.23 in (5.7mm)	200 (93)	■	■	■	●	●	Indoor/Outdoor	■	■	■	■	■	■	■	■	■			
SJ3560	250	Clear Acrylic	Clear	Clear, 4 mil (0.10mm) Polyolefin	0.23 in (5.7mm)	220 (104)	■	■	■	●	●	Indoor/Outdoor	■	■	■	■	■	■	■	■	■			
SJ3561	400																							
SJ3562	170																							
SJ3550CF	250	Clear Acrylic	Black	Clear, 4 mil (0.10mm) Polyolefin	0.23 in (5.7mm)	220 (104)	■	■	■	●	●	Indoor/Outdoor	■	■	■	■	■	■	■	■	■			
SJ3551CF	400																							
SJ3552CF	170																							
SJ3870	250	Modified Acrylic	Black	Red, 4.5 mil (0.11mm) Polyolefin	0.24 in (6.1mm)	140 (60)	■		■	■	●	Indoor/Outdoor									■			
SJ3871	400																							
SJ3872	170																							
SJ3782	250	Low Surface Energy Acrylic	Black	Brown, 83# Polykraft	0.16 in (4.1mm)	120 (49)	■		■	■	■	Indoor/Outdoor	■								■			
SJ3440	250	None	Black	No Liner	0.15 in (3.86mm)	220 (104)	▲	▲	▲	▲	▲	Indoor/Outdoor		▲	▲	▲	▲	▲	▲	▲	▲			
SJ3441	400																							
SJ3442	170																							
SJ3443	400	Non-woven Backing with No Adhesive	Black	No Liner	0.28 in (7.1mm)	220 (104)	▲	▲	▲	▲	▲	Indoor/Outdoor		▲	▲	▲	▲	▲	▲	▲	▲			
SJ3444	170																							
SJ3445	250																							
SJ3460	250	None	Clear	No Liner	0.15 in (3.86mm)	220 (104)	▲	▲	▲	▲	▲	Indoor/Outdoor	▲	▲	▲	▲	▲	▲	▲	▲	▲			
SJ3463	400	Piece Part Circle'	Black	No Liner	0.20 in** (5.1mm)	220 (104)	■		■	■	■	Indoor/Outdoor	■	■	■	■	■	■	■	■	■			
SJ3481	400	Rigid Strip'	Black	No Liner	0.20 in** (5.1mm)	220 (104)	▲	▲	▲	▲	▲	Indoor/Outdoor	▲	▲	▲	▲	▲	▲	▲	▲	▲			
SJ4570	Low Profile/Thin	Low Surface Energy Acrylic	Clear	Brown, 83# Polykraft	0.098 in (2.489mm)	158 (70)	■		■	■	■	Indoor/Outdoor	■	■	■	■	■	■	■	■	■			
SJ4575			Black																					
SJ4580		Clear Acrylic	Clear	Red, 4.5 mil (0.11mm) Polyolefin	0.12 in (3.0mm)	200 (93)	■	■	■	●	●	Indoor/Outdoor	■	■	■	■	■	■	■	■	■			


\*Clear fastener utilizes a white adhesive giving the product a white appearance    \*\*Single thickness; not engaged    †No adhesive

Note: The technical information and data on these pages should be considered representative or typical only and should not be used for specification purposes.

# 3M™ Hook and Loop Reclosable Fasteners

## Hooks on One Side, Loops on the Other for Secure, Repeated Closures

- Reliable PSA holds on contact with a variety of materials
- Low profile options, as much as 75% thinner than standard product
- Up to 5,000 closures for standard Hook and Loop
- Flame resistant product available
- Also available without adhesive

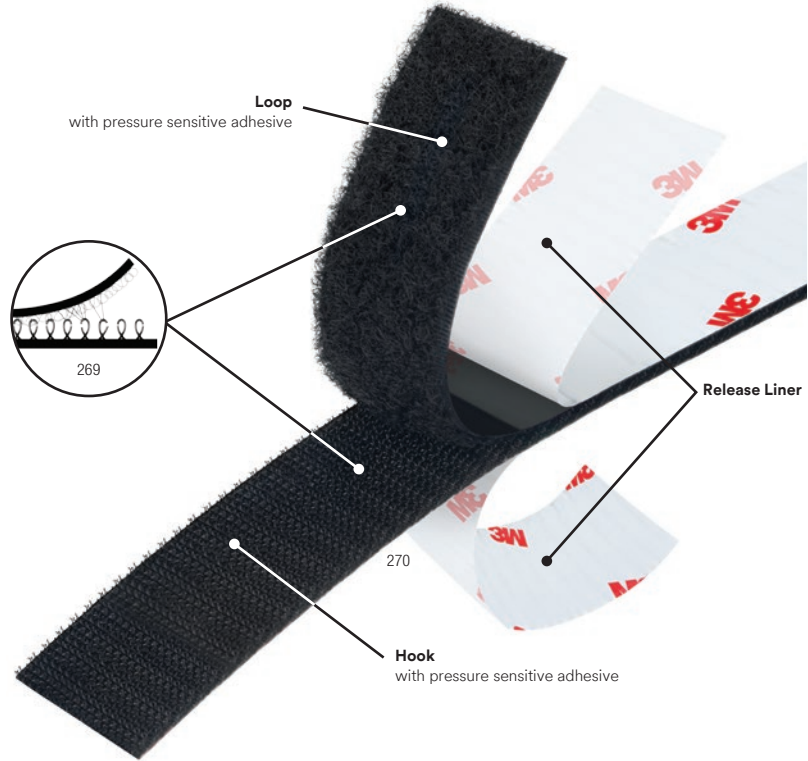

Attach cushioning panels in an ambulance or bus.



Sew to the fabric and leather of jackets and gloves.



Use as a replacement for string, tapes, rubber bands, wire and strapping.



Attach removable seat cushions.



Hang graphics and banners that change frequently.