

Block and Tackle

Block and Tackle

- These are **NOT** occupational protective devices. **NOT** for human support.
- Light, galvanized-steel shell blocks are fitted with snubbing hooks to hold the load.
- Sheaves are strong, yet are lightweight aluminum alloy with all-bronze bushings.
- Available with standard snap hooks or guarded snap hooks (with snap hook nose lengthened to extend over the latch or keeper).
- Choice of forged hook Cat. No. 258 or swivel hook Cat. No. 259.
- Hooks fit under insulator and engage pin on cross arm.
- All Klein block and tackle use high-quality, 3/8" diameter rope.
- Catalog numbers followed by S/R have rope spliced to block.
- Maximum safe load is 750 lbs. (338 kg).



1802-30 S/R

Cat. No.	Description	Weight (lbs.)
1802-30	Blocks with standard snap hooks. Furnished with 25' (7.6 m) of 3/8" (10 mm) rope. Has Cat. No. 267 block with snap hook and a detachable forged anchor hook (Cat. No. 258) on one end, and block Cat. No. 268 with eye and rope tie-off hook on other end.	2.80
1802-30 S/R	same as Cat. No. 1802-30, but with rope spliced to Cat. No. 268 block	2.80
1802-30S	same as Cat. No. 1802-30, except supplied with a detachable swivel anchor hook (Cat. No. 259) instead of hook Cat. No. 258	2.85
1802-30S S/R	same as Cat. No. 1802-30S, but with rope spliced to Cat. No. 268 block	2.85
H1802-30	Blocks with guarded snap hooks. Furnished with 25' (7.6 m) of 3/8" (10 mm) rope. Has Cat. No. H267 block with guarded snap hook and a detachable forged anchor hook (Cat. No. 258) on one end and block Cat. No. H268 (with guarded snap hook, eye and rope tie-off hook) on other end.	2.90
H1802-30 S/R	same as Cat. No. H1802-30, but with rope spliced to Cat. No. H268 block	2.90
H1802-30S	same as Cat. No. H1802-30, except supplied with a detachable swivel anchor hook (Cat. No. 259) instead of hook Cat. No. 258	3.00
H1802-30S S/R	same as Cat. No. H1802-30S, but with rope spliced to Cat. No. H268 block	3.00

Anchor Hook



258

- Forged hook is designed to slip under insulator and engage pin of cross arm.
- Maximum safe load 750 lbs. (340 kg).
- Standard on Klein block & tackle Cat. Nos. 1802-30 and H1802-30.

Cat. No.	Eye I.D.	Throat Opening	Overall Length	Weight (lbs.)
258	5/8" (16 mm)	1-7/8" (48 mm)	5-1/2" (140 mm)	.42

Swivel Anchor Hook




259

- Swivel clevis on this forged hook will engage with snap on Klein block & tackle Cat. Nos. 1802-30 and H1802-30.
- Swivel prevents twisting and kinking of rope.
- Maximum safe load 750 lbs. (340 kg).

Cat. No.	Swivel Opening	Throat Opening	Overall Length	Weight (lbs.)
259	1-3/16" x 1" (30 mm x 25 mm)	1-7/8" (48 mm)	6-1/2" (165 mm)	.40

Heavy-Duty Snap Hook

- Snaps on with one hand.
- Forged hook may be used on many conventional steel blocks, 4" (102 mm) or smaller.
- Maximum safe load 8000 lbs. (3629 kg).

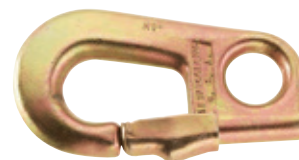

455

Cat. No.	Eye I.D.	Throat Opening	Overall Length	Weight (lbs.)
455	15/16" (24 mm)	1" (25 mm)	5" (127 mm)	.84

All dimensions are in inches and (millimeters).

WARNING: These are NOT occupational protective devices. Do NOT use for human support.

