

Single (Thin) Wall Tubing: 3M™ FP-301 Thin-Wall Tubing



3M™ Heat Shrink Thin-Wall Tubing FP-301 (1 Inch)


Ordering Size: 1" (25,4 mm)

Expanded I.D. (Min.): 1.00" (25,40 mm)

Recovered I.D. (Max.): 0.500" (12,70 mm)

Recovered Wall Thickness (Nominal): 0.035" (0,89 mm)

Material	Polyolefin
Shrink Ratio	2:1
Operating Temperature	-67 to 275°F (-55 to 135°C)
Voltage	600 Volts Max.
RoHS 2011/65/EU	Yes
Application Specifications	SAE-AMS-DTL-23053/5, Class 1, 2; AMS-3636, AMS-3637
Agency Approvals	
Manufacturing Origin	

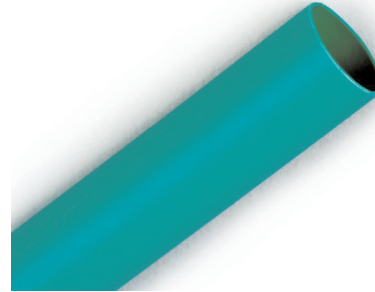

Order No.	UPC	Color	Format	Flame Retardant	Case Qty.
FP301-1-6"-Clear-10-10 Pc Pks	051128-60119	Clear	6" (152,4 mm) pieces	No	10 pcs/pk, 10 pks
FP301-1-6"-Black-10-10 Pc Pks	051128-60118	Black	6" (152,4 mm) pieces	Yes	10 pcs/pk, 10 pks
FP301-1-48"-Black-5 Pcs	051128-59604	Black	48" (1,22 m) sticks	Yes	5 pcs
FP301-1-48"-Black-24 Pcs	051128-59841	Black	48" (1,22 m) sticks	Yes	24 pcs
FP301-1-48"-Blue-5 Pcs	051128-59609	Blue	48" (1,22 m) sticks	Yes	5 pcs
FP301-1-48"-Clear-5 Pcs	051128-59605	Clear	48" (1,22 m) sticks	No	5 pcs
FP301-1-48"-Clear-24 Pcs	051128-59856	Clear	48" (1,22 m) sticks	No	24 pcs
FP301-1-48"-Green-5 Pcs	051128-59785	Green	48" (1,22 m) sticks	Yes	5 pcs
FP301-1-48"-Red-5 Pcs	051128-59607	Red	48" (1,22 m) sticks	Yes	5 pcs
FP301-1-48"-White-5 Pcs	051128-59606	White	48" (1,22 m) sticks	Yes	5 pcs
FP301-1-48"-Yellow-5 Pcs	051128-59608	Yellow	48" (1,22 m) sticks	Yes	5 pcs
FP301-1-48"-Black-Hdr-5 Pcs	051128-59681	Black	48" (1,22 m) sticks w/ Hdr Label	Yes	5 pcs
FP301-1-48"-Blue-Hdr-5 Pcs	051128-59686	Blue	48" (1,22 m) sticks w/ Hdr Label	Yes	5 pcs
FP301-1-48"-Clear-Hdr-5 Pcs	051128-59682	Clear	48" (1,22 m) sticks w/ Hdr Label	No	5 pcs
FP301-1-48"-Green-Hdr-5 Pcs	051128-59784	Green	48" (1,22 m) sticks w/ Hdr Label	Yes	5 pcs
FP301-1-48"-Red-Hdr-5 Pcs	051128-59684	Red	48" (1,22 m) sticks w/ Hdr Label	Yes	5 pcs
FP301-1-48"-White-Hdr-5 Pcs	051128-59683	White	48" (1,22 m) sticks w/ Hdr Label	Yes	5 pcs
FP301-1-48"-Yellow-Hdr-5 Pcs	051128-59685	Yellow	48" (1,22 m) sticks w/ Hdr Label	Yes	5 pcs
FP301-1-25'-Black-Reel	054007-40066	Black	25' (7,62 m) reel	Yes	1 reel
FP301-1-50'-Black-Spool	051135-35598	Black	50' (15,24 m) spool	Yes	3 spools
FP301-1-Blue-50'	051135-35601	Blue	50' (15,24 m) spool	Yes	3 spools
FP301-1-50'-Clear-Spool	051135-35603	Clear	50' (15,24 m) spool	No	3 spools
FP301-1-Green-50'	051135-37768	Green	50' (15,24 m) spool	Yes	3 spools
FP301-1-Red-50'	051135-35600	Red	50' (15,24 m) spool	Yes	3 spools
FP301-1-White-50'	051135-35599	White	50' (15,24 m) spool	Yes	3 spools
FP301-1-Yellow-50'	051135-35602	Yellow	50' (15,24 m) spool	Yes	3 spools
FP301-1-100'-Black-Spool	054007-08508	Black	100' (30,48 m) spool	Yes	3 spools
FP301-1-100'-Clear-Spool	054007-08532	Clear	100' (30,48 m) spool	No	3 spools