

Single (Thin) Wall Tubing: 3M™ FP-301 Thin-Wall Tubing



3M™ Heat Shrink Thin-Wall Tubing FP-301 (3/4 Inch)


Ordering Size: 3/4" (19,0 mm)

Expanded I.D. (Min.): 0.750" (19,05 mm)

Recovered I.D. (Max.): 0.375" (9,53 mm)

Recovered Wall Thickness (Nominal): 0.030" (0,76 mm)

Material	Polyolefin
Shrink Ratio	2:1
Operating Temperature	-67 to 275°F (-55 to 135°C)
Voltage	600 Volts Max.
RoHS 2011/65/EU	Yes
Application Specifications	SAE-AMS-DTL-23053/5, Class 1, 2; AMS-3636, AMS-3637
Agency Approvals	
Manufacturing Origin	

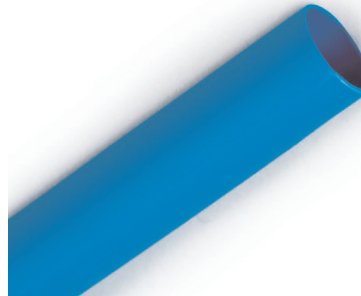

Order No.	UPC	Color	Format	Flame Retardant	Case Qty.
FP301-3/4-6"-Clear-10-10 Pc Pks	051128-60125	Clear	6" (152,4 mm) pieces	No	10/pk, 10 pks
FP301-3/4-6"-Black-10-10 Pc Pks	051128-60124	Black	6" (152,4 mm) pieces	Yes	10/pk, 10 pks
FP301-3/4-6"-Black-200 Pcs	051128-59894	Black	6" (152,4 mm) pieces	Yes	200 pcs
FP301-3/4-48"-Black-12 Pcs	051128-59598	Black	48" (1,22 m) sticks	Yes	12 pcs
FP301-3/4-48"-Black-50 Pcs	051128-59864	Black	48" (1,22 m) sticks	Yes	50 pcs
FP301-3/4-48"-Clear-12 Pcs	051128-59599	Clear	48" (1,22 m) sticks	No	12 pcs
FP301-3/4-48"-Clear-50 Pcs	051128-59855	Clear	48" (1,22 m) sticks	No	50 pcs
FP301-3/4-48"-Blue-12 Pcs	051128-59603	Blue	48" (1,22 m) sticks	Yes	12 pcs
FP301-3/4-48"-Green-12 Pcs	051128-59783	Green	48" (1,22 m) sticks	Yes	12 pcs
FP301-3/4-48"-Red-12 Pcs	051128-59601	Red	48" (1,22 m) sticks	Yes	12 pcs
FP301-3/4-48"-White-12 Pcs	051128-59600	White	48" (1,22 m) sticks	Yes	12 pcs
FP301-3/4-48"-Yellow-12 Pcs	051128-59602	Yellow	48" (1,22 m) sticks	Yes	12 pcs
FP301-3/4-48"-Black-Hdr-12 Pcs	051128-59675	Black	48" (1,22 m) sticks w/ Hdr Label	Yes	12 pcs
FP301-3/4-48"-Blue-Hdr-12 Pcs	051128-59680	Blue	48" (1,22 m) sticks w/ Hdr Label	Yes	12 pcs
FP301-3/4-48"-Clear-Hdr-12 Pcs	051128-59676	Clear	48" (1,22 m) sticks w/ Hdr Label	No	12 pcs
FP301-3/4-48"-Green-Hdr-12 Pcs	051128-59782	Green	48" (1,22 m) sticks w/ Hdr Label	Yes	12 pcs
FP301-3/4-48"-Red-Hdr-12 Pcs	051128-59678	Red	48" (1,22 m) sticks w/ Hdr Label	Yes	12 pcs
FP301-3/4-48"-White-Hdr-12 Pcs	051128-59677	White	48" (1,22 m) sticks w/ Hdr Label	Yes	12 pcs
FP301-3/4-48"-Yellow-Hdr-12 Pcs	051128-59679	Yellow	48" (1,22 m) sticks w/ Hdr Label	Yes	12 pcs
FP301-3/4-25'-Black-Reel	054007-40065	Black	25' (7,62 m) reel	Yes	1 reel
FP301-3/4-50'-Black-Spool	051135-35592	Black	50' (15,24 m) spool	Yes	3 spools
FP301-3/4-Blue-50'	051135-35595	Blue	50' (15,24 m) spool	Yes	3 spools
FP301-3/4-50'-Clear-Spool	051135-35597	Clear	50' (15,24 m) spool	No	3 spools
FP301-3/4-Green-50'	051135-37348	Green	50' (15,24 m) spool	Yes	3 spools
FP301-3/4-Red-50'	051135-35594	Red	50' (15,24 m) spool	Yes	3 spools
FP301-3/4-White-50'	051135-35593	White	50' (15,24 m) spool	Yes	3 spools
FP301-3/4-Yellow-50'	051135-35596	Yellow	50' (15,24 m) spool	Yes	3 spools
FP301-3/4-200'-Black-Spool	054007-08502	Black	200' (60,96 m) spool	Yes	3 spools
FP301-3/4-200'-Clear-Spool	054007-08531	Clear	200' (60,96 m) spool	No	3 spools