

Single (Thin) Wall Tubing: 3M™ FP-301 Thin-Wall Tubing




3M™ Heat Shrink Thin-Wall Tubing FP-301 (3/32 Inch)


Ordering Size: 3/32"

Expanded I.D. (Min.): 0.093" (2,36 mm)

Recovered I.D. (Max.): 0.046" (1,17 mm)

Recovered Wall Thickness (Nominal): 0.020" (0,51 mm)

Material	Polyolefin
Expanded/Recovered I.D.	0.093"/0.046" (2,36/1,17 mm)
Shrink Ratio	2:1
Operating Temperature	-67 to 275°F (-55 to 135°C)
Voltage	600 Volts Max.
RoHS 2011/65/EU	Yes
Application Specifications	SAE-AMS-DTL-23053/5, Class 1, 2; AMS-3636, AMS-3637
Agency Approvals	 
Manufacturing Origin	

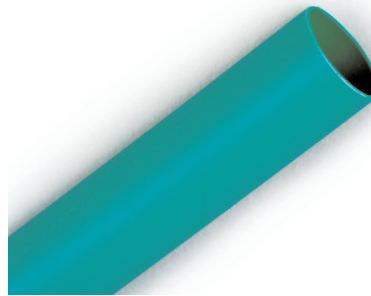

Order No.	UPC	Color	Format	Flame Retardant	Case Qty.
FP301-3/32-6"-Black-10-10 Pc Pks	051128-60122	Black	6" (152,4 mm) pieces	Yes	10/pk, 10 pks
FP301-3/32-6"-Black-200 Pcs	051128-59888	Black	6" (152,4 mm) pieces	Yes	200 pcs
FP301-3/32-6"-Clear-10-10 Pc Pks	051128-60123	Clear	6" (152,4 mm) pieces	No	10/pk, 10 pks
FP301-3/32-48"-Black-25 Pcs	051128-59972	Black	48" (1,22 m) sticks	Yes	25 pcs
FP301-3/32-48"-Black-250 Pcs	051128-59810	Black	48" (1,22 m) sticks	Yes	250 pcs
FP301-3/32-48"-Clear-25 Pcs	051128-59973	Clear	48" (1,22 m) sticks	No	25 pcs
FP301-3/32-48"-Clear-250 Pcs	051128-59814	Clear	48" (1,22 m) sticks	No	250 pcs
FP301-3/32-48"-Blue-25 Pcs	051128-59977	Blue	48" (1,22 m) sticks	Yes	25 pcs
FP301-3/32-48"-Green-25 Pcs	051128-59978	Green	48" (1,22 m) sticks	Yes	25 pcs
FP301-3/32-48"-Red-25 Pcs	051128-59975	Red	48" (1,22 m) sticks	Yes	25 pcs
FP301-3/32-48"-White-25 Pcs	051128-59974	White	48" (1,22 m) sticks	Yes	25 pcs
FP301-3/32-48"-Yellow-25 Pcs	051128-59976	Yellow	48" (1,22 m) sticks	Yes	25 pcs
FP301-3/32-48"-Black-Hdr-25 Pcs	051128-59633	Black	48" (1,22 m) sticks w/ Hdr Label	Yes	25 pcs
FP301-3/32-48"-Blue-Hdr-25 Pcs	051128-59638	Blue	48" (1,22 m) sticks w/ Hdr Label	Yes	25 pcs
FP301-3/32-48"-Clear-Hdr-25 Pcs	051128-59634	Clear	48" (1,22 m) sticks w/ Hdr Label	No	25 pcs
FP301-3/32-48"-Green-Hdr-25 Pcs	051128-59639	Green	48" (1,22 m) sticks w/ Hdr Label	Yes	25 pcs
FP301-3/32-48"-Red-Hdr-25 Pcs	051128-59636	Red	48" (1,22 m) sticks w/ Hdr Label	Yes	25 pcs
FP301-3/32-48"-White-Hdr-25 Pcs	051128-59635	White	48" (1,22 m) sticks w/ Hdr Label	Yes	25 pcs
FP301-3/32-48"-Yellow-Hdr-25 Pcs	051128-59637	Yellow	48" (1,22 m) sticks w/ Hdr Label	Yes	25 pcs
FP301-3/32-25'-Black-Reel	054007-40059	Black	25' (7,62 m) reel	Yes	1 reel
FP301-3/32-100'-Black-Spool	051135-35556	Black	100' (30,48 m) spool	Yes	3 spools
FP301-3/32-Blue-100'	051135-35559	Blue	100' (30,48 m) spool	Yes	3 spools
FP301-3/32-100'-Clear-Spool	051135-35548	Clear	100' (30,48 m) spool	No	3 spools
FP301-3/32-Green-100'	051135-37592	Green	100' (30,48 m) spool	Yes	3 spools
FP301-3/32-Red-100'	051135-35558	Red	100' (30,48 m) spool	Yes	3 spools
FP301-3/32-White-100'	051135-35557	White	100' (30,48 m) spool	Yes	3 spools
FP301-3/32-Yellow-100'	051135-35560	Yellow	100' (30,48 m) spool	Yes	3 spools
FP301-3/32-500'-Black-Spool	054007-08466	Black	500' (152,40 m) spool	Yes	3 spools
FP301-3/32-500'-Clear-Spool	054007-08525	Clear	500' (152,40 m) spool	No	3 spools