


**TWO HOLE HYLUG™ CODE  
CONDUCTOR STANDARD  
BARREL**  
(Continued)



45° and 90° angles available. Please contact Customer Service to order: 1-800-346-4175

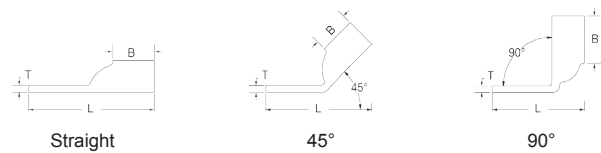

**NOTE:** Field bending straight lugs to achieve an angular connection will void UL Listing / CSA Certifications and BURNDY will not be liable for the connection.

Catalog Number	Conductor		Stud Hole Size	Stud Hole Spacing	Tongue Width	Figure Dimensions			Dieless (# of crimps)	Installation Tooling				Wire Strip Length			
	AWG	MM <sup>2</sup> ***				(B)	(T)	(L)		Mech.	Hydraulic		Color Code		Die Index		
											MD6, OUR840, MD7-34R	BCT500HS, Y500CTHS				Y35, Y39, Y750 Y46*, PAT750	
YA3CL-2TC14	3 AWG #2 Sol.	25	1/4	5/8"	0.55	0.88	0.09	2.45	W3CRT (1)	W3CRT (1)	U3CRT (1)	White	9	15/16			
YA3C-2L			5/16	5/8"	0.55	0.88	0.09	2.64									
YA3CL-2TC38			3/8	1"	0.58	0.88	0.08	3.06									
YA2CL-2TC14	#2 AWG	35	1/4	5/8"	0.60	0.88	0.11	2.47	Y122CMR** (2) Y1MRTC (2) MY29-3 (1) MY29-11 (1) MRC840 (1) Y644HSXT (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT (1)	W2CVT (1) W2CRT (1) X2CRT (1)	W2CVT (1) W2CRT (1) X2CRT (1)	U2CRT (1)	Brown	10	15/16		
YA2CL-2TC14E2			1/4	3/4"	0.60	0.88	0.11	2.60									
YA2CL-2TC14E1			1/4	1"	0.60	0.88	0.11	2.85									
YA2C-2L			5/16	3/4"	0.60	0.88	0.11	2.67									
YA2CL-2TC516			5/16	1"	0.60	0.88	0.11	2.91									
YA2CL-2TC38			3/8	1"	0.60	0.88	0.11	3.03									
YA2C-2LN			1/2	1-3/4"	0.83	0.88	0.12	4.27									
YA1CL-2TC14			1 AWG	50	1/4	5/8"	0.68	0.88								0.10	2.51
YA1CL-2TC14E2					1/4	3/4"	0.68	0.88								0.10	2.64
YA1C-2L	5/16	7/8"			0.68	0.88	0.10	2.82									
YA1CL-2TC38	3/8	1"			0.68	0.88	0.10	3.07									
YA1C-2LN	1/2	1-3/4"			0.83	0.88	0.12	4.32									
YA25L-2TC14	1/0 AWG	—			1/4	5/8"	0.75	0.88	0.12	2.54	W25VT (2) W25RT (2) X25RT (2)	W25VT (2) W25RT (2) X25RT (2)	U25RT (1) U2CABT (1)	Pink	12 or 348	15/16	
YA25L-2TC14E2			1/4	3/4"	0.75	0.88	0.12	2.66									
YA25L-2TC14E1			1/4	1"	0.75	0.88	0.12	2.91									
YA25-2L			5/16	7/8"	0.75	0.88	0.12	2.85									
YA25L-2TC38			3/8	1"	0.75	0.88	0.12	3.10									
YA25-2LN			1/2	1-3/4"	0.83	0.88	0.11	4.29									
YA26L-2TC14	2/0 AWG	70	1/4	5/8"	0.83	0.94	0.12	2.64	MY29-3 (1) MY29-11 (1) MRC840 (2) Y644HSXT (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT (1)	W26VT (2) W26RT (2) X26RT (2)	W26VT (2) W26RT (2) X26RT (2)	U26RT (1)	Black	13	1		
YA26L-2TC14E2			1/4	3/4"	0.83	0.94	0.12	2.76									
YA26L-2TC14E1			1/4	1"	0.83	0.94	0.12	3.01									
YA26-2L			5/16	7/8"	0.83	0.94	0.12	2.95									
YA26L-2TC38			3/8	1"	0.83	0.94	0.12	3.20									
YA26-2LN			1/2	1-3/4"	0.83	0.94	0.12	4.39									
YA27L-2TC14E2	3/0 AWG	—	1/4	3/4"	1.00	1.00	0.12	2.86	W27VT (2) W27RT (2) X27RT (3)	W27VT (2) W27RT (2) X27RT (3)	U27RT (1)	Orange	14	1-1/16			
YA27L-2TC38			3/8	1"	1.00	1.00	0.12	3.30									
YA27-2LN			1/2	1-3/4"	0.91	1.00	0.13	4.48									
YA28L-2TC14E2	4/0 AWG	—	1/4	3/4"	1.02	0.88	0.14	2.78	W28VT (2) W28RT (2) X28RT (3)	W28VT (2) W28RT (2) X28RT (3)	U28RT (1)	Purple	15	1-1/8			
YA28L-2TC14E1			1/4	1"	1.02	0.88	0.14	3.03									
YA28L2NTC516			5/16	1-3/4"	1.02	0.88	0.14	3.84									
YA28L-2TC38E2			3/8	3/4"	1.02	0.88	0.14	2.97									
YA28L-2TC38			3/8	1"	1.02	0.88	0.14	3.22									
YA28-2LN			1/2	1-3/4"	1.02	0.88	0.14	4.41									
YA29L-2TC38	250 kcmil	—	3/8	1.00"	1.10	1.06	0.16	3.43	MY29-3 (1) MY29-11 (1) Y644HSXT (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT (1)	W29VT (2) X29RT (4)	W29VT (2) W29RT (2) X29RT (4)	U29RT (1)	Yellow	16	1-1/8		
YA29-2LN			1/2	1-3/4"	1.10	1.06	0.16	4.62									

-- Color code not assigned  
\* Use PUADP-1 adapter with U dies in Y46 HYPRESS™  
\*\* Y122CMR tool #10-#2 AWG Wire only

\*\*\* The MM<sup>2</sup> conductor sizes listed are the recommendations for Class 2 conductor  
▲ See tooling section of this catalog for complete tool and die listings

◆ For applications greater than 2000 volts consult cable manufacturer for voltage stress relief instructions  
Note: All dimensions shown are for reference only