

**Stainless Steel Cable Ties and Accessories**

**TYS - Multi-Lok™ Self-Locking**



**Strong — holds in excess of 200 lb. — and self locking**

- Corrosion-resistant, providing a safe, strong, worry-free hold
- Unique, self-locking, multiple-locking system holds in excess of 200 lb.
- Manufactured from Type 316 stainless steel
- Available in two widths and various lengths


Cat. No.	Tensile Strength (lb./N)	Width (in./mm)	Length (in./mm)	Weight (lb./kg)	Std. Pkg.
<b>Type 316 Stainless Steel – Uncoated</b>					
<b>TYS6-280</b>	250/1,112	0.28/7.00	6/150	0.66/0.30	100
<b>TYS9-280</b>			9/225	0.99/0.45	
<b>TYS12-280</b>			12/300	1.32/0.60	
<b>TYS18-280</b>			18/450	1.76/0.80	
<b>TYS24-280</b>			24/610	2.64/1.20	
<b>TYS6-470</b>		0.47/12.00	6/150	1.10/0.50	
<b>TYS9-470</b>			9/225	1.65/0.75	
<b>TYS12-470</b>			12/300	2.20/1.00	
<b>TYS18-470</b>			18/450	2.97/1.35	
<b>TYS24-470</b>			24/610	4.29/1.95	

0.010 in. (0.245mm) Thickness

**How it works:**

As the free end of the Multi-Lok tie passes through the buckle, three separate teeth (four teeth in the 12mm Multi-Lok) mesh with corresponding slots in the band, automatically locking the tie as it is being tensioned.

- Nylon 11 weather-resistant coating is unaffected by UV sunlight, resistant to corrosion, chemicals, weathering and protects cable insulation
- Coated with halogen-free, non-toxic black nylon 11

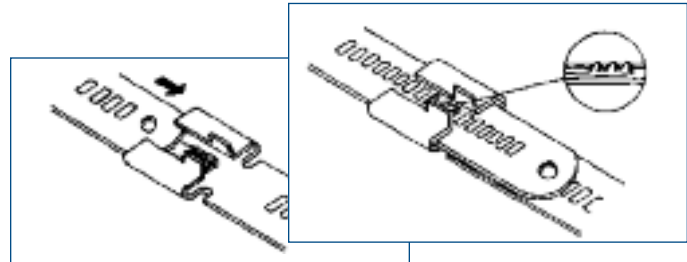

Cat. No.	Tensile Strength (lb./N)	Width (in./mm)	Length (in./mm)	Weight (lb./kg)	Std. Pkg.
<b>Type 316 Stainless Steel – Nylon 11 Coated</b>					
<b>TYS6-280C</b>	250/1,112	0.28/7.00	6/150	0.66/0.30	100
<b>TYS9-280C</b>			9/225	0.99/0.45	
<b>TYS12-280C</b>			12/300	1.32/0.60	
<b>TYS18-280C</b>			18/450	1.76/0.80	
<b>TYS24-280C</b>			24/610	2.64/1.20	
<b>TYS6-470C</b>		0.47/12.00	6/150	1.10/0.50	
<b>TYS9-470C</b>			9/225	1.65/0.75	
<b>TYS12-470C</b>			12/300	2.20/1.00	
<b>TYS18-470C</b>			18/450	2.97/1.35	
<b>TYS24-470C</b>			24/610	4.29/1.95	

0.010 in. (0.245mm) Thickness