


## Ty-Rap® High-Performance Stainless Steel Cable Ties


Strong and slip-free with a unique dual lock.

### Ty-Rap® Dual-Lock Stainless Steel Cable Ties

- 304 grade stainless steel construction
- Two-piece design
- Fast, easy installation
- Mini ties (.18" wide) offer 100 lbs. tensile strength
- Standard ties (.25" wide) offer 200 lbs. tensile strength
- Also available in 316 grade stainless steel (to order, add -316 suffix to catalog number)

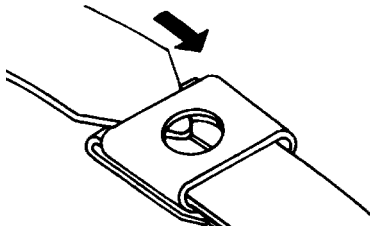

After wrapping the object to be tied, insert the free end of the tie through the buckle and into the tool.

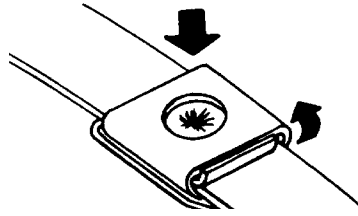

Squeeze the handle of the tool to create the dual lock and cut off the tail. The cable tie forms a low-profile dual lock.



The tail is formed into a fold lock behind the buckle. The tool forces a dimple in the band into a hole in the buckle.

| CAT. NO.                                   | FOR BUNDLE DIAMETER OF IN/MM | TENSILE STRENGTH LBS/N | WIDTH IN/MM | LENGTH IN/MM | WEIGHT LBS/KG | STD. PKG. QTY. |
|--|------------------------------|------------------------|-------------|--------------|---------------|----------------|
| <b>Mini Stainless Steel Cable Ties</b>     |                              |                        |             |              |               |                |
| SS7-180                                    | 1/25                         | 100/444.8              | .18/4.5     | 6.5/165      | .70/.32       | 100            |
| SS10-180                                   | 2/51                         | 100/444.8              | .18/4.5     | 10.0/254     | .90/.41       | 100            |
| SS16-180                                   | 4/102                        | 100/444.8              | .18/4.5     | 16.0/406     | 1.40/.64      | 100            |
| SS23-180                                   | 6/152                        | 100/444.8              | .18/4.5     | 22.5/572     | 1.85/.84      | 100            |
| SS29-180                                   | 8/203                        | 100/444.8              | .18/4.5     | 29.0/737     | 2.35/1.07     | 100            |
| <b>Standard Stainless Steel Cable Ties</b> |                              |                        |             |              |               |                |
| SS10-250                                   | 2/51                         | 200/890                | .25/6.35    | 10.0/254     | 1.10/.50      | 100            |
| SS17-250                                   | 4/101                        | 200/890                | .25/6.35    | 16.5/419     | 1.80/.82      | 100            |
| SS23-250                                   | 6/152                        | 200/890                | .25/6.35    | 22.5/572     | 2.50/1.13     | 100            |
| SS29-250                                   | 8/203                        | 200/890                | .25/6.35    | 29.0/737     | 3.20/1.45     | 100            |
| SS35-250                                   | 10/254                       | 200/890                | .25/6.35    | 35.0/ 889    | 3.80/1.72     | 100            |

304 Stainless Steel

.015" (.38mm) Thickness

**Note:** Other lengths available on special request.

Add suffix -316 for 316 Stainless Steel.