


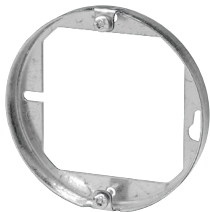







4 in. Octagonal Boxes

Conduit Knockouts

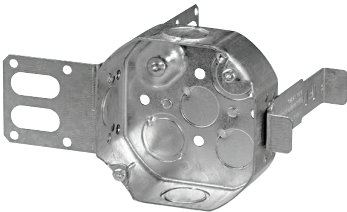				
BCOBEX	BC56111	BC54151-K	CI54151-KSSX	
Octagonal box extension.	Ceiling pan.	Concentric knockouts.	Concentric knockouts. "Wraparound" bracket for 2-1/2 in. and 3-5/8 in. steel studs. With integral support bracket.	
				
BC55151-K	BC54171-K	CI54171-KSSX	CI54171-KSSX-1	CI55171-K
Extension ring with ground screw. Concentric knockouts.	Concentric knockouts.	Concentric knockouts. "Wraparound" bracket for 2-1/2 in. and 3-5/8 in. steel studs. With integral support bracket.	Mounting strap (offset for 2 x 1/2 in. drywall thicknesses).	Extension ring with ground screw. Concentric knockouts.



Cat. No.	Description
1/2 in. Deep — Extensions	
BCOBEX	Extension for octagonal boxes. 1/2 in. non-adjustable depth. Complete with mounting screws (5 cu. in.)

Cat. No.	Volume (Cu. in.)	Features		Knockouts			
		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	3/4 in. sides	3/4 in. bottom
1-1/2 in. Deep							
BC56111	5.0	-	yes	-	4	-	-
1-1/2 in. Deep							
BC54151-K	15.0	-	yes	4	4	2	2
CI54151-KSSX	15.0	"SSX"	yes	2	4	2	2
BC55151-K	15.0	-	yes	4	-	2	-
2-1/8 in. Deep							
BC54171-K	21.0	-	yes	4	4	2	2
CI54171-KSSX	21.0	"SSX"	yes	2	4	2	2
CI54171-KSSX-1	21.0	"SSX-1"	yes	2	4	2	2
CI55171-K	21.0	-	yes	4	-	2	-