



Beam Clamps

Beam Clamps for Hanging Rod

U562 Beam Clamp

U562HDG
U562EG
U562
U562SS6

Optional Use of
U562HDG
Beam Clamp

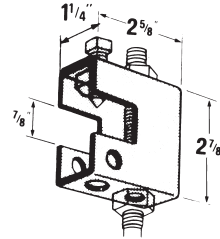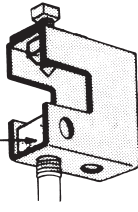

E146 square nut order separately.
1/2 in. set screw included.

1/2 in. set screw included.


Rod Size (in.)	Wt./C lb.	Design Load lb./ea
1/2	80	800

Rod Size (in.)	Wt./C lb.	Design Load lb./ea
1/2	80	500

For 20° swivel application use ES-145-1/2 nut.

UM562 Beam Clamp

UM562HDGC
UM562EG
UM562
UM562SS6

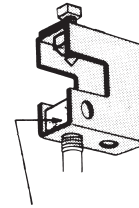


E146 square nut order separately.
1/2 in. set screw included.

Rod Size (in.)	Wt./C lb.	Design Load lb./ea
1/2	100	1200

For 20° swivel application use ES-145-1/2 nut.

US562 Beam Clamp with Swing Hanger

US562HDG
US562EG
US562

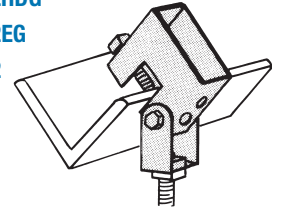



1/2 in. set screw included.

Rod Size (in.)	Wt./C lb.	Design Load lb./ea
1/2	113	800

U563 Beam Clamp

U563HDG
U563EG
U563
U563SS6

Optional Use of
U563HDG
Beam Clamp

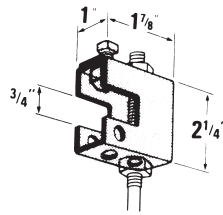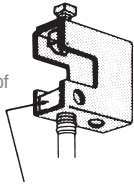

Square nut order separately.
3/8 in. set screw included.


3/8 in. set screw included.

Rod Size (in.)	Wt./C lb.	Design Load lb./ea
3/8	33	400

Rod Size (in.)	Wt./C lb.	Design Load lb./ea
3/8	33	240

US563 Beam Clamp with Swing Hanger

US563HDG
US563

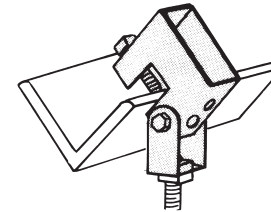


3/8 in. set screw included.

Rod Size (in.)	Wt./C lb.	Design Load lb./ea
3/8	50	400

U569 Beam Clamp

U569HDG
U569

Maximum flange width 5 in.

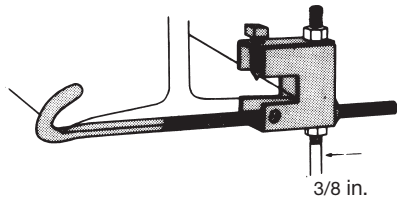


Cat. No.	A Size (in.)	Wt./C lb.	Design Load lb./ea
U569	3/8	150	400

A570 Beam Clamp with Safety Rod

A570HDG

Flange width 4 in. min. - 8 in. max.
For use with 3/8 in. rod see U-569.

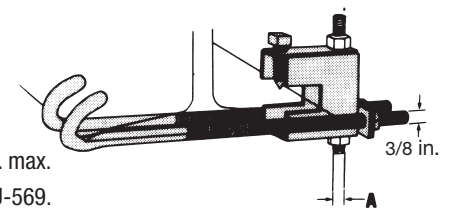

Cat. No.	A Size (in.)	Wt./C lb.	Design Load lb./ea
A570HDG	1/2	220	500

Materials HDG(C) Hot-Dipped Galvanized
EG(C) ElectroGalvanized
(No suffix) GoldGalv®
SS6(C) Stainless Steel 316