



## Pole Line Hardware

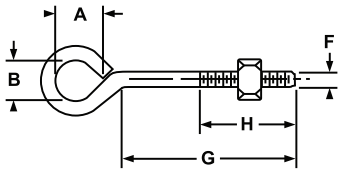

CATALOGUE NUMBER	DESCRIPTION	F DIA. (in.)	G LENGTH (in.)	H MIN. (in.)	WEIGHT (100 PCS)		STD. PKG
					lb.	kg	
<b>B0506</b>	Oval eye bolt	5/8	6	3	122	55.4	50
<b>B0508</b>	Oval eye bolt	5/8	8	4	136	61.8	50
<b>B0510</b>	Oval eye bolt	5/8	10	4	150	68.1	50
<b>B0512</b>	Oval eye bolt	5/8	12	4	168	76.3	50

## Drive Hooks

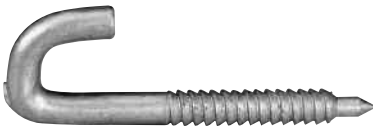


CATALOGUE NUMBER	LENGTH (in.)	DIAMETER (in.)	WEIGHT (100 pcs)		STD PKG
			lb	kg	
<b>CP500</b>	5-1/4	7/16	0.36	0.16	25

Drive Hook hot dip galvanized.

## Guy Strain Insulator



CATALOGUE NUMBER	LENGTH (in.)	DIAMETER (in.)	WEIGHT (100 pcs)		STD PKG
			lb	kg	
<b>504WGS</b>	4-1/4	2-7/8	1.0	0.45	1
<b>506WGS</b>	5-1/2	3-3/8	1.0	0.45	1

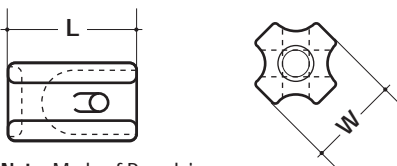

Note: Made of Porcelain

## Guy Wire Guard



CATALOGUE NUMBER FLARED	COLOR	LENGTH (ft)	WEIGHT (100 pcs)		STD PKG
			lb	kg	
<b>2YG</b>	Yellow	6.7	3.35	1.46	10

