


Primary switch mode power supplies

CP-D and CP-E



CP-D 12/0.83,
CP-D 24/0.42

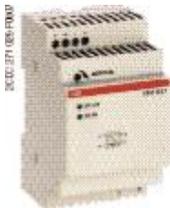

CP-D 12/2.1
CP-D 24/1.3



CP-E 5/3.0



CP-E 24/5.0



CP-E 48/5.0



CP-RUD

Full range of product and technical information place this part number in a search engine and download
2CDC110004C0206

CP-D range

Type	Input voltage range	Rated output voltage / current	Order Code	Price
CP-D 12/0.83	90-264 V AC/ 120-370 V DC	12 V DC /0.83 A	1SVR427041R1000	
CP-D 12/2.1	90-264 V AC/ 120-370 V DC	12 V DC /2.1 A	1SVR427043R1200	

CP-D 24/0.42	90-264 V AC/ 120-370 V DC	24 V DC /0.42 A	1SVR427041R0000	
CP-D 24/1.3	90-264 V AC/ 120-370 V DC	24 V DC /1.3 A	1SVR427043R0100	
CP-D 24/2.5	90-264 V AC/ 120-370 V DC	24 V DC /2.5 A	1SVR427044R0200	
CP-D 24/4.2	90-264 V AC/ 120-370 V DC	24 V DC /4.2 A	1SVR427045R0400	

CP-E range

Type	Input voltage range	Rated output voltage / current	Order Code	Price
CP-E 5/3.0	90-265 V AC/ 120-370 V DC	5 V DC /3 A	1SVR427033R3000	

CP-E 12/2.5	85-264 V AC/ 90-375 V DC	12 V DC /2.5 A	1SVR427032R1000	
CP-E 12/10.0	90-132 V AC, 186-264 V AC/ 210-370 V DC	12 V DC /10 A	1SVR427035R1000	

CP-E 24/0.75	90-265 V AC/ 120-370 V DC	24 V DC /0.75 A	1SVR427030R0000	
CP-E 24/1.25	85-264 V AC/ 90-375 V DC	24 V DC /1.25 A	1SVR427031R0000	
CP-E 24/2.5	85-264 V AC/ 90-375 V DC	24 V DC /2.5 A	1SVR427032R0000	
CP-E 24/5.0	90-132 V AC, 186-264 V AC/ 210-370 V DC	24 V DC /5 A	1SVR427034R0000	
CP-E 24/10.0	93-132 V AC, 186-264 V AC/ 210-370 V DC	24 V DC /10 A	1SVR427035R0000	
CP-E 24/20.0	90-264 V AC/ 120-370 V DC	24 V DC /20 A	1SVR427036R0000	

CP-E 48/0.62	85-264 V AC/ 90-375 V DC	48 V DC / 0.625 A	1SVR427030R2000	
CP-E 48/1.25	85-264 V AC/ 90-375 V DC	48 V DC /1.25 A	1SVR427031R2000	
CP-E 48/5.0	93-132 V AC, 186-264 V AC/ 210-370 V DC	48 V DC /5 A	1SVR427034R2000	
CP-E 48/10.0	90-264 V AC/ 120-370 V DC	48 V DC /10 A	1SVR427035R2000	

Redundancy units

for decoupling of two CP-E power supply units

Type	Suitable for decoupling of CP-E power supply units	Order Code	Price
------	--	------------	-------

CP-RUD: 2 inputs each up to 2.5 A and 1 output up to 5 A

CP-RUD	< 35 V and < 5 A	1SVR423418R9000	
--------	------------------	-----------------	--

CP-A RU: 2 inputs each up to 20 A and 1 output up to 40 A

CP-A RU	< 40 V and > 5 A	1SVR427071R0000	
---------	------------------	-----------------	--