

Carflex® One-Piece Liquidtight Fittings

Product Overview

Unique Design

The simple, one-piece body design of the Carflex® One-Piece Liquidtight Nonmetallic Fitting requires no disassembly of components for installation. The system is so strong that there is no need for a compression nut.

PVC Construction


PVC construction of the fitting and locknut provides unparalleled protection from water, oil and dust. Totally nonmetallic, the system is non-conductive and will not corrode or rust. Temperatures up to 60°C

Features

- Approved for indoor and outdoor locations
- Listed for "Wet Locations"




Straight Fittings

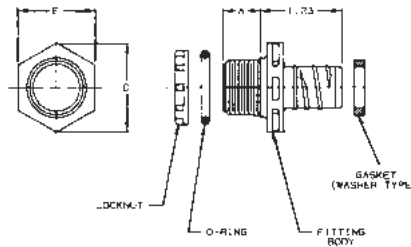

Cat. No.	Trade Size (in.)	Std. Ctn. Qty.	Std. Ctn. Wt. (lb.)	Thread Size	Dimensions (in.)		
					A	D	E
LN43DA	1/2	100	2.8	14 NPT	0.56	1.34	1.19
LN43EA	3/4	50	2.2	14 NPT	0.56	1.63	1.44
LN43FA	1	25	3	11-1/2 NPT	0.69	1.99	1.75

90° Fittings

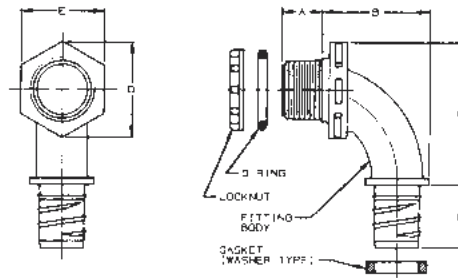

Cat. No.	Trade Size (in.)	Std. Ctn. Qty.	Std. Ctn. Wt. (lb.)	Thread Size	Dimensions (in.)				
					A	B	C	D	E
LN20DA	1/2	100	4.3	14 NPT	0.56	1.50	1.99	1.34	1.19
LN20EA	3/4	50	3.1	14 NPT	0.56	1.73	2.25	1.63	1.44
LN20FA	1	25	3.2	11-1/2 NPT	0.69	1.86	2.58	1.99	1.75