


Molded Case Circuit Breakers

External Accessories

Selection

Max-Flex™, Flange Mounted Variable Depth Operators

Frames	NEMA Type	Complete Kit		Handle Only		Breaker Operator		36" Cable	
		Catalog Number	List Price \$	Catalog Number	List Price \$	Catalog Number	List Price \$	Catalog Number	List Price \$
ED	1, 3 (R), 12	FHOE036 ^①		FHOH		FHOEBO ^①		FHOEC036	
	4 (x)	—		FHOH4					
FD	1, 3 (R), 12	FHOF036		FHOH		FHOFBO		FHOFC036	
	4 (x)	—		FHOH4					
JD, LD, SJD, SLD	1, 3 (R), 12	FHOJ036		FHOH		FHOJBO		FHOJC036	
	4 (x)	—		FHOH4					
LMD	1, 3 (R), 12	FHOLM036		FHOH		FHOLMBO		FHOJC036	
	4 (x)	—		FHOH4					
MD, ND, PD, RD, SMD, SND, SPD	1, 3 (R), 12	FHON048		FHOHN		FHONBO		FHONC048 ^②	
	4 (x)	—		FHOHN4					

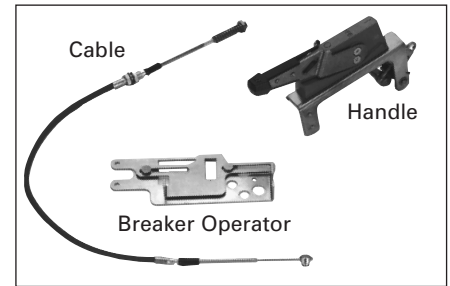

Max-Flex™

Max-Flex™ handles are available with solid black handles instead of the customary "red for on" flange handle. These are preferred for use in IEC markets, where red handles have specific meaning. Order components separately, appending the letter "i" to the catalog number (e.g. FHOHi).

Alternate Length Cable Only

Inches	ED		FD		JD/LD/LMD		MD/ND/PD/RD	
	Catalog Number	List Price \$	Catalog Number	List Price \$	Catalog Number	List Price \$	Catalog Number	List Price \$
48	FHOEC048		FHOFC048		FHOJC048		FHONC048	
60	FHOEC060		FHOFC060		FHOJC060		FHONC060	
72	FHOEC072		FHOFC072		FHOJC072		FHONC072	
84	FHOEC084▲		FHOFC084▲		FHOJC084▲		FHONC084▲	
96	FHOEC096		FHOFC096		FHOJC096		FHONC096	
120	FHOEC120▲		FHOFC120		FHOJC120▲		FHONC120▲	
144	FHOEC144▲		FHOFC144▲		FHOJC144▲		FHONC144▲	

Handle Auxiliary Switch

For use with Max-Flex and Rotary Door operators (FHOH and RHOH). 1 NO and 1 NC contact.

For Use With	Catalog Number	List Price \$
ED, JD, LD, LMD, ND, PD, RD, SD, Max Flex	HAS1	

Fixed Depth Flange Mounting

Frames	Minimum Enclosure Depth	NEMA Type	Left Hand Mount		Right Hand Mount	
			Catalog Number	List Price \$	Catalog Number	List Price \$
ED	6.44	1, 3R, 12	FDFBEL▲		FDFBER▲	
		4, 4X	FDFBEL4▲		FDFBER4▲	
FD	6.44	1, 3R, 12	FDFBFL▲		FDFBFR▲	
		4, 4X	FDFBFL4▲		FDFBFR4▲	

Max-Flex™ handles are available with solid black handles instead of the customary "Red for On" flange handle. These are preferred for use in IEC markets, where red handles have specific meaning. Order components separately, appending the letter "i" to the catalog number (e.g. FHOHi).



▲ Built to order. Allow 6-8 weeks for delivery.

① For 1- or 2-pole breaker order FHOED036 complete kit or FHOEDBO breaker operator only.

② 48 inch cable is standard length for M through R frame Max-Flex operators.