

Q-BIC Remote Fixtures

Surface Mounted Series



Features

- Cubic, vandal-resistant surface-mounted fixture
- Single, double or twin cube with center body
- CSA certified to C22.2 N°50.



Typical Specification

Remote heads Series Q-BIC shall be comprised of one (single) or two (double or twin) 12-Watt adjustable halogen lamps. Each lamp shall be housed in an impact-resistant polycarbonate cube. The cube lens shall be frosted to diffuse the light.

Heads shall provide mounting holes for installation to a standard octagonal box.

The remote unit shall be the Lumacell model:
RSQ_X _____ .

In the same family...



Q-BIC


Battery Units **p. 136 - 137**

Project / Location		Date
Contractor		Prepared by
LUMACELL Model		



RSQB / RSQBD / RSQB2

Dimensions

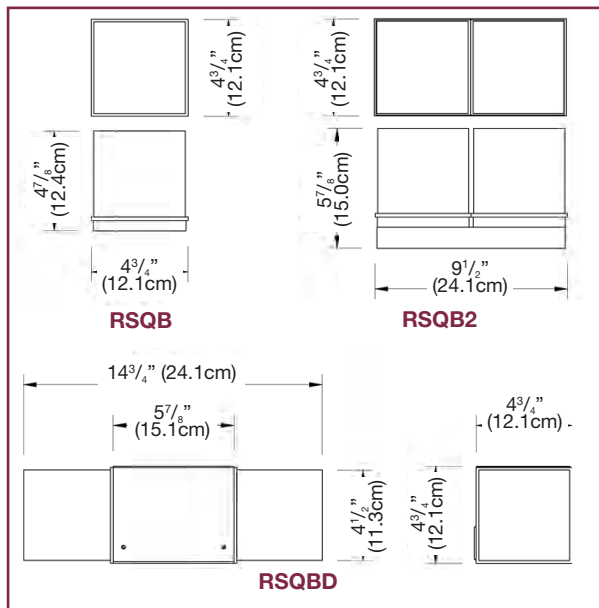

Wire Guards

460.0035-L	Wall Mount (RSQB)
460.0100-L	Wall Mount (RSQBD)
460.0032-L	Wall Mount (RSQB2)

Replacement Lamps

Model	Lamp Type	Voltage-Wattage
570.0016-L	Mini tungsten, wedge base	6V-9W
580.0011-L	Mini Halogen (quartz), bi-pin	6V-12W
580.0079-L	MR16, flood	6V-10W

See the complete list p. 196 to 199.

Ordering Information

Series	Voltage/Wattage/Lamp Type	Colour	Options
RSQB = single cube	T6V9W = 6V-9W, tungsten, wedge base	Blank = factory white	Blank = no options
RSQBD = double cube	T12V9W = 12V-9W, tungsten, wedge base	BK = black	TP = tamper proof screws
RSQB2 = twin cube	T12V18W = 12V-18W, tungsten, wedge base		*690.0454-L = tamper proof bit
	T24V9W = 24V-9W, tungsten, wedge base		
	T24V18W = 24V-18W, tungsten, wedge base		
	T32V15W = 32V-15W, tungsten, wedge base		
	6V8W = 6V-8W, quartz bi-pin		
	6V12W = 6V-12W, quartz bi-pin		
	12V8W = 12V-8W, quartz bi-pin		
	12V12W = 12V-12W, quartz bi-pins		
	24V20W = 24V-20W, quartz bi-pin		
	120V20W = 120V-20W, GU10		
	120V35W = 120V-35W, GU10		
	M6V6W = 6V-6W, MR16		
	M6V10W = 6V-10W, MR16		
	M12V12W = 12V-12W, MR16		
	M12V20W = 12V-20W, MR16		
	M12V35W = 12V-35W, MR16		
	M12V50W = 12V-50W, MR16		
	M24V20W = 24V-20W, MR16		
	M24V35W = 24V-35W, MR16		
	M24V50W = 24V-50W, MR16		

*One bit needed per order.

EXAMPLE: RSQBT6V9W