

Molded Case Circuit Breakers

LD 600A Frame Sentron Series

Selection

Type HLD6-A, HLXD6-A^{②③④}

Black Label

Interchangeable Trip						
Continuous Current Rating @ 40°C	Complete Breaker Unassembled w/Lugs		Frame Only		Trip Unit Only	
	Catalog Number	List Price \$	Catalog Number	List Price \$	Catalog Number	List Price \$
2-Pole 600V AC, 250V DC (3 Pole Width)						
250	HLD62B250■	5868.00	HLD62F600■	4094.00	JD62T250■	1662.00
300	HLD62B300■	5868.00			JD62T300■	1662.00
350	HLD62B350■	5868.00			JD62T350■	1662.00
400	HLD62B400■	5868.00			JD62T400■	1662.00
450	HLD62B450■	5868.00			LD62T450■	1662.00
500	HLD62B500■	5868.00			LD62T500■	1662.00
600	HLD62B600■	5868.00			LD62T600■	1662.00

3-Pole 600V AC, 500V DC^{①⑤}

250	HLD63B250■	7465.00	HLD63F600■	5446.00	JD63T250■	1851.00
300	HLD63B300■	7465.00			JD63T300■	1851.00
350	HLD63B350■	7465.00			JD63T350■	1851.00
400	HLD63B400■	7465.00			JD63T400■	1851.00
450	HLD63B450■	7465.00			LD63T450■	1851.00
500	HLD63B500■	7465.00			LD63T500■	1851.00
600	HLD63B600■	7465.00			LD63T600■	1851.00

Type HHL6, HHLXD6^{②③④}

2-Pole 600V AC (3 Pole Width)

Black Label

250	HHL62B250■	7318.00	HHL62F600■	5544.00	JD62T250■	1662.00
300	HHL62B300■	7318.00			JD62T300■	1662.00
350	HHL62B350■	7318.00			JD62T350■	1662.00
400	HHL62B400■	7318.00			JD62T400■	1662.00
450	HHL62B450■	7318.00			HHL62T450■	1662.00
500	HHL62B500■	7318.00			HHL62T500■	1662.00
600	HHL62B600■	7318.00			HHL62T600■	1662.00

3-Pole 600V AC

250	HHL63B250■	8864.00	HHL63F600■	6845.00	JD63T250■	1851.00
300	HHL63B300■	8864.00			JD63T300■	1851.00
350	HHL63B350■	8864.00			JD63T350■	1851.00
400	HHL63B400■	8864.00			JD63T400■	1851.00
450	HHL63B450■	8864.00			HHL63T450■	1851.00
500	HHL63B500■	8864.00			HHL63T500■	1851.00
600	HHL63B600■	8864.00			HHL63T600■	1851.00

Type CLD6-A^{③④}

Fuseless Current Limiting

Red Label

Non-Interchangeable Trip (Assembled Circuit Breaker)				
Continuous Current Rating @ 40°C	2-Pole		3-Pole	
	600V AC/250V DC		600V AC/500V DC	
	Catalog Number	List Price \$	Catalog Number	List Price \$
450	For 2-pole application use outside poles of 3-pole circuit breaker		CLD63B450■	11666.00
500			CLD63B500■	11666.00
600			CLD63B600■	11666.00

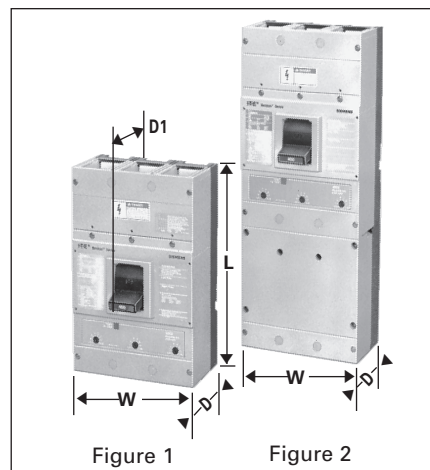


Figure 1

Figure 2

Dimensions (in inches)

Breaker Type	W	L	D	To Handle D1
Figure 1 LXD6-A, LD6-A HLD6-A, HHLXD6, LXD6-ETI ^⑥ , SLD6, SHLD6	7.5	11	4	5.44
Figure 2 CLD6, CLD6-ETI ^⑥ , SCLD6	7.5	17.86	4	5.44

Enclosures: (except SCLD6)

Type	Catalog Number	List Price \$
1	LD6N1	402.00
3R	LD6N3R	1447.00
12	LD6N12	875.00
4X	LD6SS4	6211.00
7,9	ED6	10131.00
Neutral	W60993	353.00

For inches / millimeters conversion, see Application Data section

■ Built to order. Allow 2-3 weeks for delivery.

④ When wired as shown on page 17/3, this circuit breaker is UL listed and rated for use on 500V DC ungrounded UPS systems only.

⑤ For complete assembled 3 pole HLD6 or HHL6 type circuit breaker change the prefix identifier HLD6 or HHL6 to HLXD6 or HHLXD6. Price is sum of frame and trip units prices, e.g. price of HLXD6B400 is the price of HLD63F600 plus the price of LD63T600. Order the terminal connectors separately.■

⑥ Type HLXD6, HHLXD6, & CLD6 Circuit Breakers are UL Listed for reverse feed applications.

⑦ LXD6-ETI, CLD6-ETI see page 17/52 for ordering information.

⑧ CE Applies to non-interchangeable type HLXD only.

⑨ HACR rated.