

Guy Hooks




K133A

CATALOGUE NUMBER	BOLT SIZE (in.)	WEIGHT (100 pcs)		STD PKG
		lb	kg	
CH912	5/8	90	40.9	50
K133A	5/8 - 3/4	118	53.6	25

CH912 Prevent the guy from slipping down, when the pole is guyed at a sharp angle. Made of half oval steel, the round side serving as protection to the strands.

K133A Iron guy hook for use with 5/8" or 3/4" bolt. Equipped with teeth to imbed in the wood fibres.

Screw Anchor

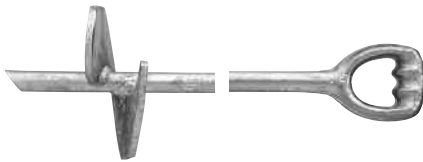

CATALOGUE NUMBER	ROD DIA. (in.)	LENGTH (ft)	PLATE DIA. (in.)	WEIGHT (100 pcs)		STD PKG
				lb	kg	
TS346	3/4	5.6	6	1050	477.2	2

Installed by placing a rod into the heavy forged oval eye to screw the anchor into the ground.

Anchor Rods



CATALOGUE NUMBER	ROD DIA. (in.)	LENGTH (ft)	TYPE	WEIGHT (100 pcs)		STD PKG
				lb	kg	
AR586	5/8	6	Double thimble	750	340.9	5
AR347	3/4	7	Double thimble	1320	600.0	5

Expanding Anchor



CATALOGUE NUMBER	HOLE SIZE (in.) REQUIRED	AREA (sq. in.)	ROD DIA. (in.)	WEIGHT (100 pcs)		STD PKG
				lb	kg	
EA08	8	135	5/8 - 3/4	950	431.8	5

These heavy duty steel anchors have 8 blades that expand to form a square, with equalized load distribution all around the anchor.