


### Industrial grade AC toggle switches


#### Product description

Single-pole, double-pole, 3-way, 4-way  
 15A, 120/277V/AC; 15A, 347V/AC  
 20A, 120/277V/AC; 20A, 347V/AC; 30A, 120/277V/AC


#### Premium industrial grade AC toggle switches, back & side wire

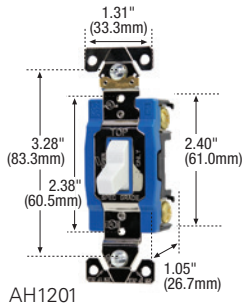


AH1201

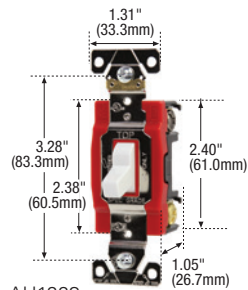

AH1223

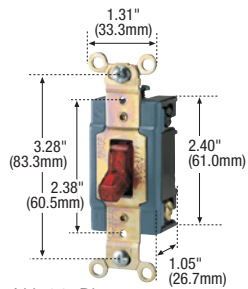

AH1201PL

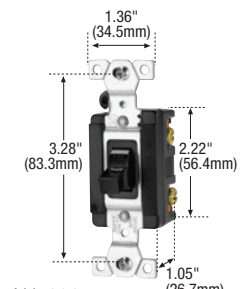

AH18201

Rating	A	V/AC	Description	Color suffix	Catalog no.				
15	120/277		Single-pole, toggle	B, GY, RD, V, W	<input type="checkbox"/> AH1201__				
			Double-pole toggle	B, GY, V, W	<input type="checkbox"/> AH1202__				
			3-Way, toggle	B, GY, RD, V, W	<input type="checkbox"/> AH1203__				
			4-Way, toggle	B, GY, V, W	<input type="checkbox"/> AH1204__				
20	120/277		Single-pole, toggle	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> AH1221__				
			Double-pole toggle	B, GY, RD, V, W	<input type="checkbox"/> AH1222__				
			3-Way, toggle	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> AH1223__				
			4-Way, toggle	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> AH1224__				
30	120/277		Single-pole, toggle	B, RD, V, W	<input type="checkbox"/> 3031__*				
			Double-pole toggle	B, RD, V, W	<input type="checkbox"/> 3032__*				

\* Not NOM cert

#### Industrial grade AC toggle switches, back & side wire



Rating	A	V/AC	Description	Color suffix	Catalog no.				
15	120/277		Single-pole, lighted toggle	V, W	<input type="checkbox"/> AH1201LT__				
			3-Way, lighted toggle	V, W	<input type="checkbox"/> AH1203LT__				
			Single-pole, pilot lighted red toggle	RD	<input type="checkbox"/> AH1201PL				
			Double-pole, pilot lighted red toggle	RD	<input type="checkbox"/> AH1202PL				
20	120/277		Single-pole, lighted toggle	V, W	<input type="checkbox"/> AH1221LT__				
			3-Way, lighted toggle	V, W	<input type="checkbox"/> AH1223LT__				
			Single-pole, pilot lighted red toggle	RD	<input type="checkbox"/> AH1221PL				
			Double-pole, pilot lighted red toggle	RD	<input type="checkbox"/> AH1222PL				
30	120/277		Double-pole, pilot lighted red toggle	RD	<input type="checkbox"/> 3032PL*				

\* Not NOM cert

#### Industrial grade AC toggle switches, back & side wire

 


Rating	A	V/AC	Description	Color suffix	Catalog no.				
15	347		Single-pole, Canadian voltage toggle	B, I, W	<input type="checkbox"/> AH18201__«				
			Double-pole, Canadian voltage toggle	B, I	<input type="checkbox"/> AH18202__«				
			3-Way, Canadian voltage toggle	B, I, W	<input type="checkbox"/> AH18203__«				
20	347		Single-pole, Canadian voltage toggle	B, I, W	<input type="checkbox"/> AH18221__«				
			Double-pole, Canadian voltage toggle	B, I	<input type="checkbox"/> AH18222__«				
			3-Way, Canadian voltage toggle	B, I, W	<input type="checkbox"/> AH18223__«				

« No Color suffix = Brown, I = Ivory

#### Color ordering information:

For ordering devices, include Catalog no. Followed by the Color suffix: B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V or I (Ivory), W (White)



Specification information: 120/277V Industrial: E-36, 120/277V industrial ArrowLink modular: E-43

Compliances, specifications and availability are subject to change without notice.

ArrowLink option available. Add "M" suffix to Standard catalog number (example AH1201B, AH1201BM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page E-4

Build-to-spec customizable devices - Page A-6

RoHS compliant - Page Q-30