


## Safety grip hospital grade plugs & connectors features & benefits

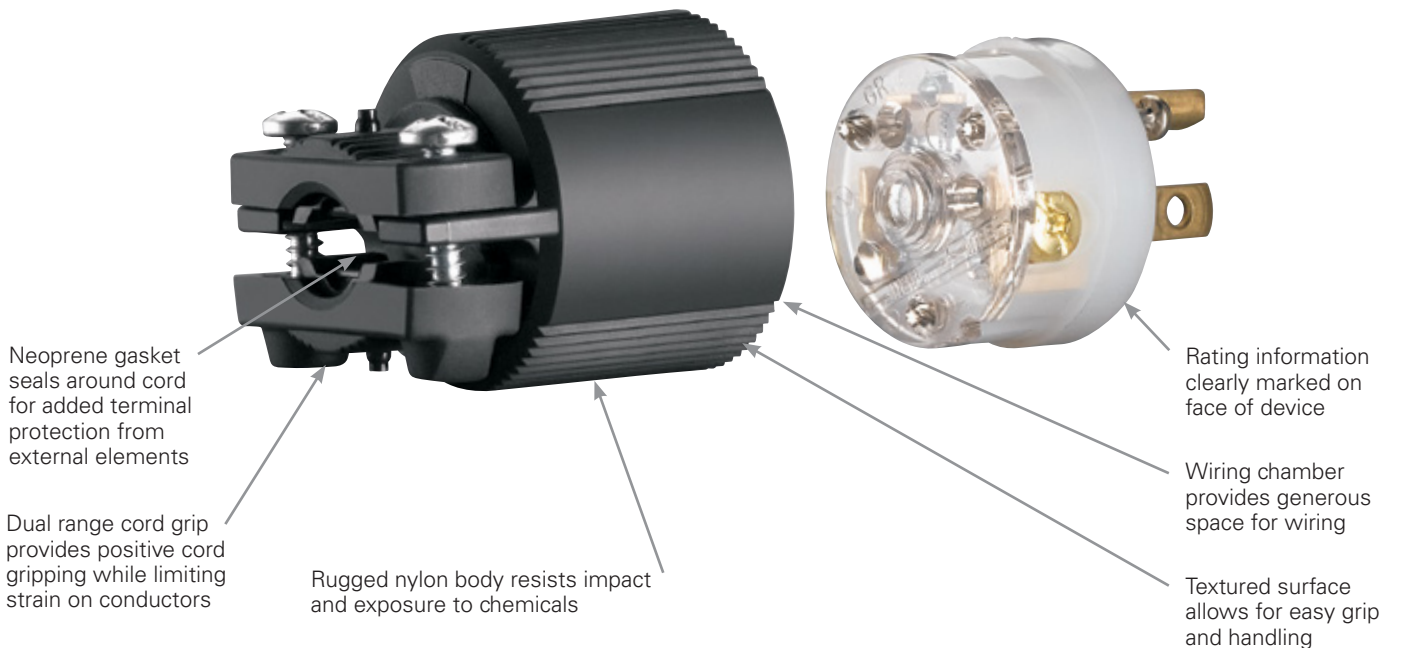

Safety grip hospital grade devices exceed federal spec. and hospital grade testing for use in demanding healthcare environments




Clear terminal cover allows for easy inspection of conductors and terminations



Retained quick drive assembly screws speed installation



Four position angled plug option is ideal for applications requiring power cord to lay close to walls and floors

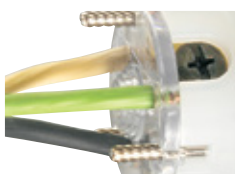

Tapered, individual wire pockets guide stranded wire into contact area for ease of installation




Multiple-head drive screws provide versatility for ease of use

Compliances, specifications and availability are subject to change without notice.


[www.eaton.com](http://www.eaton.com)  
[www.eaton.com/arrowhart](http://www.eaton.com/arrowhart)

### Quick grip hospital and industrial grade plugs & connectors features & benefits

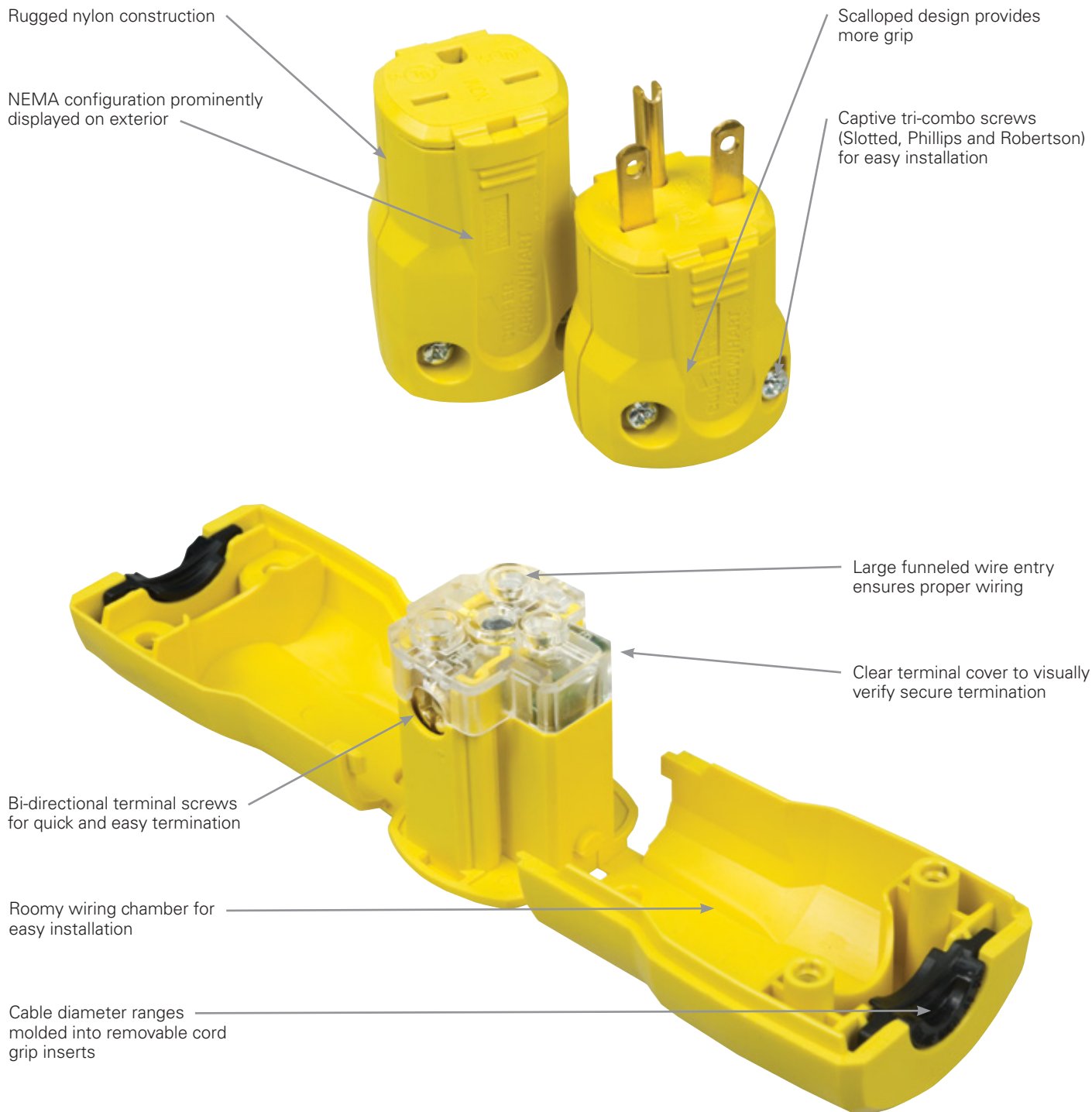


Compliances, specifications and availability are subject to change without notice.

## Auto grip hospital and industrial grade plugs & connectors features & benefits

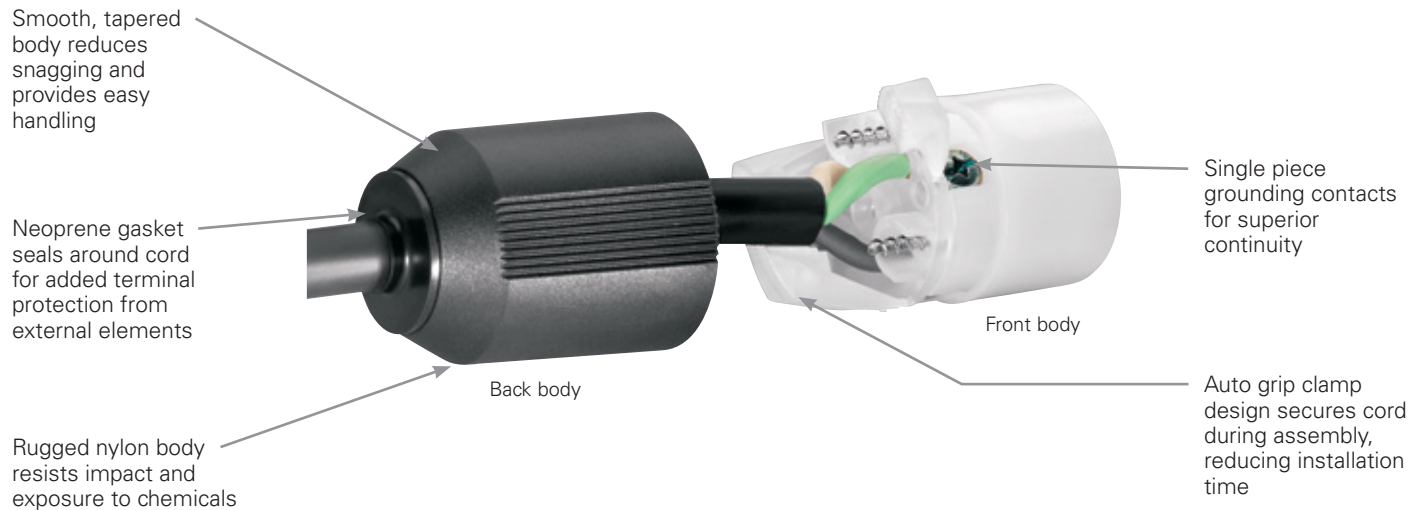

Auto grip hospital grade devices exceed federal spec. and hospital grade testing for use in demanding healthcare environments

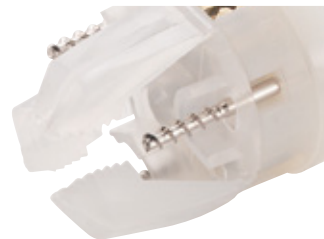

Unique clamp design secures cord during assembly, reducing installation time



Retained quick drive assembly screws speed installation



Multiple-head drive screws provide versatility for ease of use




Tapered, individual wire pockets guide stranded wire into contact area for ease of installation

Compliances, specifications and availability are subject to change without notice.

[www.eaton.com](http://www.eaton.com)  
[www.eaton.com/arrowhart](http://www.eaton.com/arrowhart)



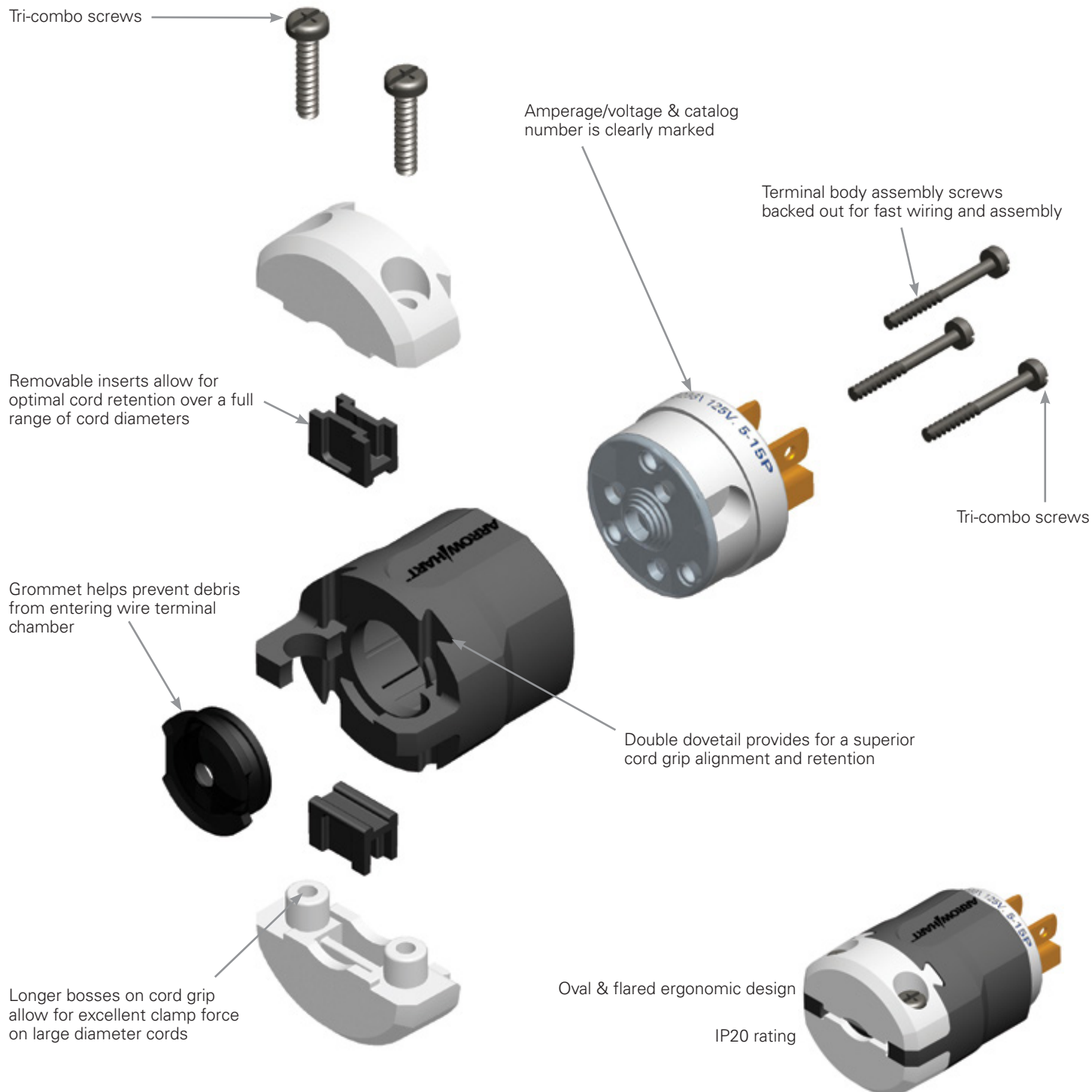

### Arrow Hart industrial grade ultra grip straight blade plugs & connectors redesign




Compliances, specifications and availability are subject to change without notice.

# Industrial grade plugs & connectors

## Industrial grade plugs & connectors quick reference guide

AMP	V/AC	NEMA	Grip	Special	Body	Color	Page	Plug	Connector
15	125	 5-15P 5-15R	ULTRA		STR	BK & W	B-10	AH5266	AH5269
					STR	BK	B-10	AH5266BK	AH5269BK
				HG	STR	BK & W	B-8	AH8215HG	AH8219HG
			SAFETY		ANG	BK & W	B-10	AH5266A	—
				HG	ANG	BK & W	B-8	AH8215HGA	—
				HG	ANG	C	B-8	AH8215HGAC	—
				HG	STR	C	B-8	AH8215HGC	AH8219HGC
			QUICK		STR	BK	B-10	AH5965BK	AH5969BK
					STR	Y	B-10	AH5965Y	AH5969Y
				HG	STR	W	B-8	AH8115W	AH8119W
			AUTO		STR	BK & W	B-10	5266N	5269N
				HG	STR	BK & W	B-8	5266NHG	5269NHG
20	125	 5-20P 5-20R	ULTRA		STR	BK & W	B-11	AH5366	AH5369
				HG	STR	BK & W	B-8	AH8315HG	AH8319HG
			SAFETY	HG	ANG	BK & W	B-8	AH8315HGA	—
				HG	ANG	C	B-8	AH8315HGAC	—
			QUICK		STR	BK	B-11	AH5364BK	AH5369BK
					STR	Y	B-11	AH5364Y	AH5369Y
				HG	STR	BK & W	B-8	5366NHG	5369NHG
15	250	 6-15P 6-15R	ULTRA		STR	BK & W	B-11	AH5666	AH5669
				HG	ANG	BK & W	B-9	AH8225HGA	—
			SAFETY	HG	ANG	C	B-9	AH8225HGAC	—
					STR	BK	B-11	AH5666BK	AH5669BK
			QUICK		STR	Y	B-11	AH5666Y	AH5669Y
					STR	BK & W	B-11	5666N	5669N
			AUTO		STR	BK & W	B-11	5666N	5669N
20	250	 6-20P 6-20R	ULTRA		STR	BK & W	B-12	AH5466	AH5469
				HG	ANG	BK & W	B-9	AH8325HGA	—
			SAFETY	HG	ANG	C	B-9	AH8325HGAC	—
					STR	BK	B-12	AH5464BK	AH5469BK
			QUICK		STR	Y	B-12	AH5464Y	AH5469Y
					STR	BK & W	B-12	5466N	5469N
			AUTO		STR	BK & W	B-12	5466N	5469N

 Hospital Grade

AMP	V/AC	NEMA	Color	Page	Flanged Inlet	Flanged Outlet
15	125	15-May	BK & W	B-10	AH5278C	AH5279C
			STEEL	B-10	AH5278	AH5246
20	125	20-May	BK & W	B-11	AH5778C	AH5779C
15	250	15-Jun	BK & W	B-11	AH5678C	AH5679C
20	250	20-Jun	BK & W	B-12	5878C	5879C

Compliances, specifications and availability are subject to change without notice.

www.eaton.com  
www.eaton.com/arrowhart

## Industrial grade straight blade devices

## Product description


2-pole, 3-wire grounding  
15A, 125V/AC  
NEMA 5-15



5-15P



5-15R

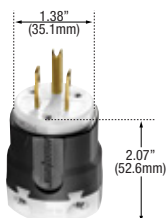

AH5266



AH5969BK



AH5278C



AH5278

## Industrial grade plugs &amp; connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	125	5-15	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH5266	□ AH5269	•	•
			Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK	□ AH5266BK	□ AH5269BK	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH5266A	—	•	•
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	BK	□ AH5965BK	□ AH5969BK	•	
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	Y	□ AH5965Y	□ AH5969Y	•	
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ 5266N	□ 5269N	•	•

## Industrial grade flanged inlets &amp; outlets



Rating A	V/AC	NEMA	Description	Color	Inlet catalog no.	Outlet catalog no.	
15	125	5-15	Nylon construction, back wire	BK & W	□ AH5278C <sup>†</sup>	□ AH5279C <sup>*</sup>	•
			Metal shell, back wire	Steel	□ AH5278 <sup>Δ</sup>	□ AH5246	•

\* UL and CSA Listed, <sup>†</sup> Fed Spec certified, <sup>Δ</sup>Only NOM spec

Industrial grade dimensional  
Information: B-16, B-17

## Specification information:

Safety grip industrial plugs & connectors: B-24  
Quick grip plugs & connectors: B-24  
Auto grip industrial plugs & connectors: B-24  
Industrial flanged inlets & Flanged outlets: B-25

## Color information:

BK (Black), W (White), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32