

Electrical accessory families

Electrical accessories for a variety of new and replacement applications

Arrow Hart has one of the most extensive lines of sign and scoreboard lighting devices in the industry and offers a variety of materials for a wide range of incandescent and fluorescent applications including electrical equipment, harnesses and light strings



Ceiling lampholders

Our ceiling lampholder family includes lampholders made of high-temperature thermoplastic or high-strength insulator porcelain in either pull chain or keyless configurations with or without extra 2-pole, 2-wire or 2-pole, 3-wire outlets.



Fluorescent lampholders

The fluorescent family of lampholders includes recessed double contact, slimline and medium bi-pin lampholder styles in either plunger or stationary styles.



Pigtail lampholders

Primarily for use in electrical equipment, harnesses and light strings, our pigtail lampholders are available in either medium base or miniature base, and include weatherproof rubber or phenolic designs.



Sign & scoreboard lampholders

Arrow Hart's broad selection of sign and scoreboard lampholders includes Attachon designs in medium, intermediate and candelabra bases in a variety of panel mounting options featuring snap-in, screw-in, hook, no hook, and spring-washer models.



Sockets

This family of lampholders includes heater and cleat sockets for use with heater elements, stage lighting and similar applications in Edison, medium, candelabra and miniature bases.



Canopy & circuit control switches

For use in fixtures, appliances, doorways and equipment, this family includes a variety of styles and sizes of push button and pull chain canopy switches and circuit control toggle switches.

Fluorescent lampholders

Product description

Medium bi-pin
660W, 600V/AC

Features

- For replacement use in fluorescent lighting fixtures
- Captive pal nut for easy mounting
- Use for flush or surface mounting
- Push-in wire terminals feature release slots

Fluorescent lampholders




Rating		Description	Color	Catalog no.	
W	V/AC				
660	600	Standard, push wire, slide-on & screw switch	W	□ 2509W	•
		Short, push wire, slide-on & screw switch	W	□ 2510W	•
		Standard, screw terminals, screw switch	W	□ 924W†	


For panel cutout dimensional data, see Section Q-Technical Reference
† Not UL Listed or CSA certified



2509W

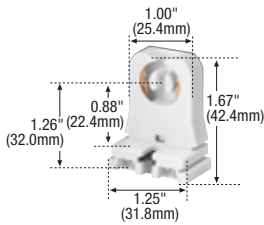

2510W

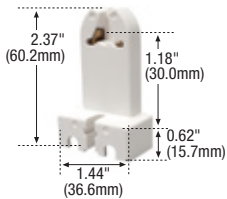

924W

Pigtail lampholders

Product description

Medium base
660W, 250V/AC; 660W, 600V/AC

Features

- For use in electrical equipment, harnesses, light strings and related applications
- Rubber sockets have an extended lip to seal against bulb
- Wire leads are 5" (127.0mm) of color-coded stranded wire, stripped 1" (25.4mm) for easy connection
- Metal shell interiors are aluminum, 145 nickel plated copper with sealed leads where they enter husk

Pigtail lampholders



Rating		Description	Catalog no.		
W	V/AC				
660	250	Phenolic, wire size #14 AWG	□ 722*	•	
660	600	Weatherproof rubber, wire size #14 AWG	□ 145	•	

For panel cutout dimensional data, see Section Q-Technical Reference
*Only UL Listed



722



145

Color information:

W (White)



(White)

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32