
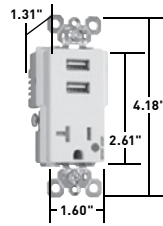


# STRAIGHT BLADE RECEPTACLES

## Fed Spec & Hospital Grade USB Chargers with Tamper-Resistant Receptacles

2 Pole, 3 Wire Grounding 15 & 20A, 125V & 120V

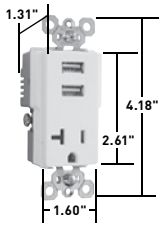

TR5361USBW

TR8301USBW

### Features

- Compact-design Tamper-Resistant receptacle and two 5-volt DC USB ports that work with USB 2.0 & 3.0 compatible devices.
- 3.1A USB type A receptacle charges fast, eliminates the need for bulky AC adapters.
- Back and side wire terminals accommodate #14 AWG - #10 AWG stranded and solid wire.
- Zinc-plated ground terminal screw.
- Stainless steel auto-ground clip assures positive ground.
- Tamper-Resistant, patented shutter system prevents improper insertion of foreign objects. Meets National Electric Code® Tamper-Resistant requirements.

CATALOG NUMBER	RATING		COLOR	TOTAL CHARGING CAPACITY	3rd PARTY COMPLIANCE		
	A.	V.			ETL	UL498 UL1310	FSUL WC596
<b>FED SPEC USB CHARGERS WITH TAMPER-RESISTANT RECEPTACLE</b>							
TR5261USBI	15	125	Ivory	2.1 Amp	•	•	•
TR5261USBW	15	125	White	2.1 Amp	•	•	•
TR5261USB	15	125	Brown	2.1 Amp	•	•	•
TR5261USBGRY	15	125	Gray	2.1 Amp	•	•	•
TR5261USBBK	15	125	Black	2.1 Amp	•	•	•
TR5261USBRED	15	125	Red	2.1 Amp	•	•	•
TR5261USBLA	15	125	Light Almond	2.1 Amp	•	•	•
TR5261USBNI	15	125	Nickel	2.1 Amp	•	•	•
TR5361USBI	20	125	Ivory	2.1 Amp	•	•	•
TR5361USBW	20	125	White	2.1 Amp	•	•	•
TR5361USB	20	125	Brown	2.1 Amp	•	•	•
TR5361USBGRY	20	125	Gray	2.1 Amp	•	•	•
TR5361USBBK	20	125	Black	2.1 Amp	•	•	•
TR5361USBLA	20	125	Light Almond	2.1 Amp	•	•	•
TR5361USBNI	20	125	Nickel	2.1 Amp	•	•	•
<b>HOSPITAL GRADE USB CHARGERS WITH TAMPER-RESISTANT RECEPTACLE</b>							
TR8201USBI	15	125	Ivory	2.1 Amp	•	•	•
TR8201USBW	15	125	White	2.1 Amp	•	•	•
TR8201USB	15	125	Brown	2.1 Amp	•	•	•
TR8201USBGRY	15	125	Gray	2.1 Amp	•	•	•
TR8201USBBK	15	125	Black	2.1 Amp	•	•	•
TR8201USBRED	15	125	Red	2.1 Amp	•	•	•
TR8201USBLA	15	125	Light Almond	2.1 Amp	•	•	•
TR8301USBI	20	125	Ivory	2.1 Amp	•	•	•
TR8301USBW	20	125	White	2.1 Amp	•	•	•
TR8301USB	20	125	Brown	2.1 Amp	•	•	•
TR8301USBGRY	20	125	Gray	2.1 Amp	•	•	•
TR8301USBBK	20	125	Black	2.1 Amp	•	•	•
TR8301USBRED	20	125	Red	2.1 Amp	•	•	•
TR8301USBLA	20	125	Light Almond	2.1 Amp	•	•	•

STRAIGHT BLADE RECEPTACLES

# DEVICES & WALL PLATES

## Color Selection Chart

### Devices & Plastic Wall Plate Colors



Ivory    Light Almond    White    Green    Antique Brass    Dark Bronze    Nickel



Black    Blue    Brown    Gray    Orange    Red

See specific device and wall plate catalog charts for particular color availabilities.

### Metal Wall Plates


Metal Finish



Aluminum    Brass (Brushed)    Polished Brass    Stainless Steel    Brushed Bronze    Chrome

### Custom Metal Wall Plates Paint Finish Colors

Paint Color

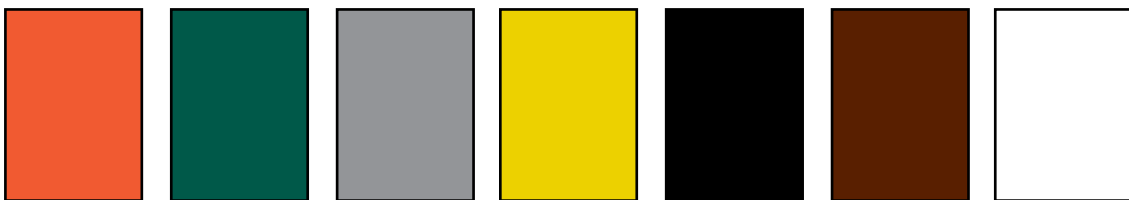

Orange    Green    Gray    Yellow    Glossy Black    Brown    White



Primer    Red    Pink    Flat Black    Ivory    Light Almond    Blue

To order custom metal wall plates, see Pages P-40 – P-44.

**For additional colors consult factory.**