


# SWITCHES

**Manual Controllers** 15, 20 & 30A, 120/277VAC – Maintained Contact  
 15, 20 & 30A, 120/277VAC – Momentary Contact

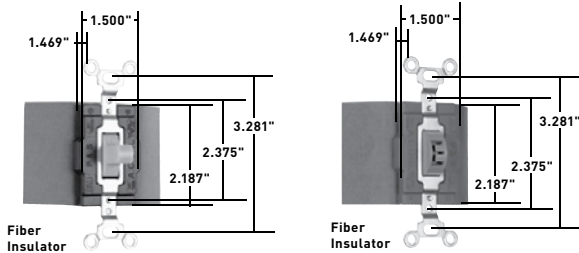

**Maintained and Momentary Contact**

**Locking**

## Applications

For ON-OFF control of motors on small machine tools, pumps, fans and air conditioning equipment that require heavy-duty AC Double Throw Center OFF controls.

## Features

- Oversized silver alloy contacts for long life and better heat dissipation.
- Side wired terminals accept #14 AWG – #10 AWG copper or copper-clad conductors.
- Fiber terminal insulation barriers standard.
- Can be mounted in standard device boxes or in NEMA 1 sheet steel enclosures.
- Bodies, covers and toggles molded of durable nylon.
- Single Pole-Double Throw and Double Pole-Double Throw.
- Locking Switches supplied with one 1498 NT key.
- Normally open.

CATALOG NUMBER		RATING		
S.P.D.T.	D.P.D.T.	A.	VAC	COLOR
<b>MAINTAINED CONTACT THREE POSITION – TWO CIRCUIT, CENTER OFF</b>				
1221I	1222I	15	120/277	Ivory
1221W	1222W	15	120/277	White
1221	1222	15	120/277	Brown
1221LA		15	120/277	Light Almond
1221L	1222L	15	120/277	Locking
1225I	1226I	20	120/277	Ivory
1225W	1226W	20	120/277	White
1225	1226	20	120/277	Brown
1225GRY		20	120/277	Gray
1225LA		20	120/277	Light Almond
1225L	1226L	20	120/277	Locking
1227I	1228I	30	120/277	Ivory
1227	1228	30	120/277	Brown
<b>MAINTAINED CONTACT EITHER DIRECTION TWO POSITION, NO CENTER OFF</b>				
1275	1276	30	120/277	Brown
<b>MOMENTARY CONTACT EITHER DIRECTION THREE POSITION, CENTER OFF</b>				
1250I		15	120/277	Ivory
1250W		15	120/277	White
1250		15	120/277	Brown
1250GRY		15	120/277	Gray
1250RED		15	120/277	Red
1250L		15	120/277	Locking
1251I		20	120/277	Ivory
1251W		20	120/277	White
1251		20	120/277	Brown
1251GRY		20	120/277	Gray
1251RED		20	120/277	Red
1251LA		20	120/277	Light Almond
1251L		20	120/277	Locking
	1256I	30	120/277	Ivory
	1256W	30	120/277	White
1255	1256	30	120/277	Brown
1255L	1256L	30	120/277	Locking

CATALOG NUMBER	DESCRIPTION
<b>LOCK SWITCH REPLACEMENT KEYS</b>	
1498	Fits switches manufactured before 1976.
1498NT	Fits switches manufactured between 1976-present.

## HP Conversion Table

1221 SERIES	
<b>15 Amp</b>	1/2 Horsepower at 120VAC 2 Horsepower at 240VAC
<b>20 Amp</b>	1 Horsepower at 120VAC 2 Horsepower at 240VAC
<b>30 Amp</b>	2 Horsepower at 120VAC 2 Horsepower at 240VAC
1250 SERIES	
<b>15 Amp</b>	1/2 Horsepower at 120VAC 2 Horsepower at 240VAC
<b>20 Amp</b>	1 Horsepower at 120VAC 2 Horsepower at 240VAC
<b>30 Amp</b>	2 Horsepower at 120VAC 2 Horsepower at 240VAC

# DEVICES & WALL PLATES

## Color Selection Chart

### Devices & Plastic Wall Plate Colors



Ivory    Light Almond    White    Green    Antique Brass    Dark Bronze    Nickel



Black    Blue    Brown    Gray    Orange    Red

See specific device and wall plate catalog charts for particular color availabilities.

### Metal Wall Plates

Metal Finish



Aluminum    Brass (Brushed)    Polished Brass    Stainless Steel    Brushed Bronze    Chrome

### Custom Metal Wall Plates Paint Finish Colors

Paint Color



Orange    Green    Gray    Yellow    Glossy Black    Brown    White



Primer    Red    Pink    Flat Black    Ivory    Light Almond    Blue

To order custom metal wall plates, see Pages P-41 – P-45.

**For additional colors consult factory.**

All devices listed on this page conform to NEMA WD-1 and WD-6.