

# SWITCHES

## PlugTail™ Specification Grade Switches


### HP CONVERSION TABLE – SWITCHES

<b>15 Amp</b>	1/2 Horsepower at 120VAC; 2 Horsepower at 240VAC
<b>20 Amp</b>	1 Horsepower at 120VAC; 2 Horsepower at 240VAC
<b>30 Amp</b>	2 Horsepower at 120VAC; 2 Horsepower at 240VAC

### PT20AC1W



#### PlugTail™ Specification Grade Switches

- A. Auto-ground clip** assures positive ground.
  - B. One-piece nickel-plated mounting strap** for superior corrosion resistance.
  - C. No exposed terminals** create a finger-safe application before, during and after installation.
  - D. Built-in connector** features large brass terminal blades to ensure consistent, reliable electrical connections.
  - E. Large brass contacts** snugly terminate on device blade terminals. Audible snapping latch assures connection, allows release.
  - F. Polycarbonate connector housing** secures terminations and conductors in a UL Listed, finger-safe housing.
  - G. Pre-stripped connector leads** fasten to conductors, easier than standard pigtails.
  - H. Glass-reinforced nylon back body** for durability and strength.
- Heavy-duty bumpers** for quiet, smooth operation.  
**Shallow design** for easier installation.

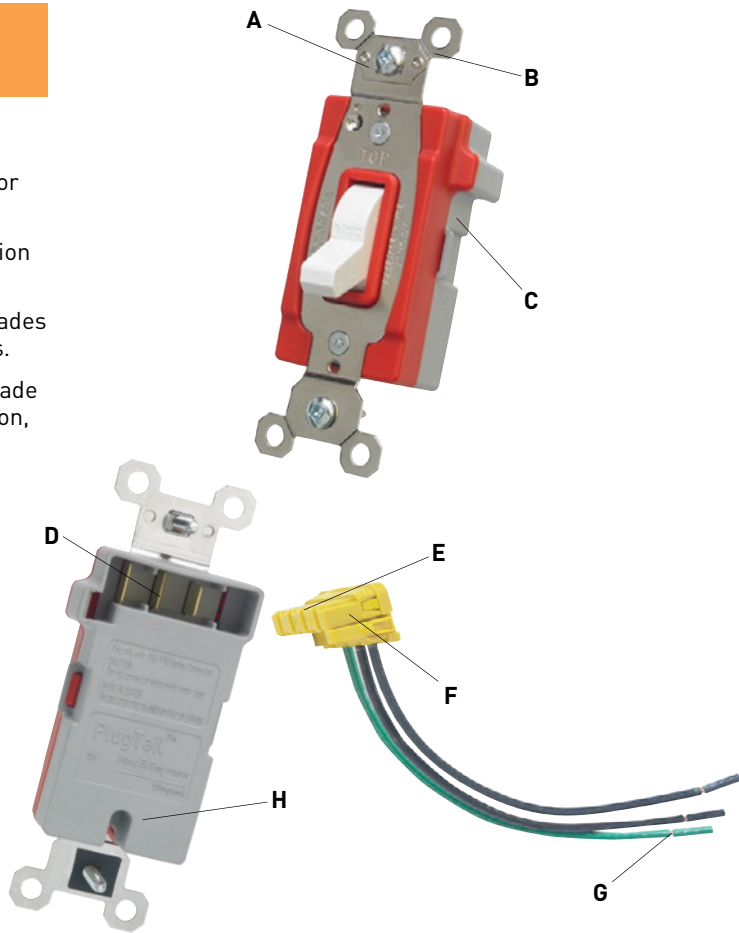

# SWITCHES

## PlugTail™ Specification Grade Switches 15 & 20A, 120/277VAC

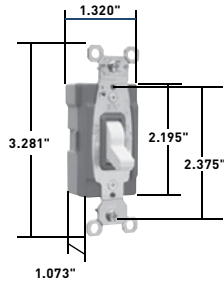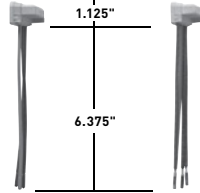
**PT20AC1W**

**PTS6STR3 PTS6STR4**

**PTJ**

CATALOG NUMBER		RATING		COLOR	3rd PARTY COMPLIANCE		
SINGLE POLE	THREE-WAY	A.	VAC			FSUL WS896	
<b>TOGGLE SWITCHES</b>							
PT15AC1I	PT15AC3I	15	120/277	Ivory	•	•	•
PT15AC1W	PT15AC3W	15	120/277	White	•	•	•
PT15AC1	PT15AC3	15	120/277	Brown	•	•	•
PT15AC1BK	PT15AC3BK	15	120/277	Black	•	•	•
PT15AC1GRY	PT15AC3GRY	15	120/277	Gray	•	•	•
PT15AC1RED	PT15AC3RED	15	120/277	Red	•	•	•
PT15AC1LA	PT15AC3LA	15	120/277	Light Almond	•	•	•
PT20AC1I	PT20AC3I	20	120/277	Ivory	•	•	•
PT20AC1W	PT20AC3W	20	120/277	White	•	•	•
PT20AC1	PT20AC3	20	120/277	Brown	•	•	•
PT20AC1BK	PT20AC3BK	20	120/277	Black	•	•	•
PT20AC1GRY	PT20AC3GRY	20	120/277	Gray	•	•	•
PT20AC1RED	PT20AC3RED	20	120/277	Red	•	•	•
PT20AC1LA	PT20AC3LA	20	120/277	Light Almond	•	•	•
<b>ILLUMINATED TOGGLE SWITCHES</b>							
PT15AC1CSL	PT15AC3CSL	15	120/277	Clear	•	•	•
PT15AC1ISL	PT15AC3ISL	15	120/277	Ivory	•	•	•
PT15AC1WSL	PT15AC3WSL	15	120/277	White	•	•	•
PT20AC1CSL	PT20AC3CSL	20	120/277	Clear	•	•	•
PT20AC1ISL	PT20AC3ISL	20	120/277	Ivory	•	•	•
PT20AC1WSL	PT20AC3WSL	20	120/277	White	•	•	•

Available in 347VAC Canadian Catalog Numbers, add 347 to the end of the Catalog Number.  
 Example: PT15AC1W347. All Canadian Products have Combination Slotted/Robertson Head Brass Screws.


CATALOG NUMBER	WIRE TYPE	WIRE LENGTH	WIRE COLORS
<b>PLUGTAIL CONNECTORS FOR SINGLE POLE SWITCHES 120/277VAC</b>			
PTS6STR3	3 Wire Stranded	6"	Green, Black, Black
PTS6SOL3	3 Wire Solid	6"	Green, Black, Black
PTS6STR3277	3 Wire Stranded	6"	Green, Brown, Brown
PTS6SOL3277	3 Wire Solid	6"	Green, Brown, Brown
<b>PLUGTAIL CONNECTORS FOR THREE-WAY SWITCHES 120/277VAC</b>			
PTS6STR4	4 Wire Stranded	6"	Green, Red, Red, Black
PTS6SOL4	4 Wire Solid	6"	Green, Red, Red, Black
PTS6STR4277	4 Wire Stranded	6"	Green, Brown, Yellow, Yellow
PTS6SOL4277	4 Wire Solid	6"	Green, Brown, Yellow, Yellow
<b>PLUGTAIL CONNECTORS FOR SINGLE POLE SWITCHES WITH WAGO CONNECTORS</b>			
PTS6STR3BP	3 Wire Stranded	6"	Green, Black, Black
PTS6SOL3BP	3 Wire Solid	6"	Green, Black, Black
PTS6STR3277BP	3 Wire Stranded	6"	Green, Brown, Brown
PTS6SOL3277BP	3 Wire Solid	6"	Green, Brown, Brown
<b>PLUGTAIL CONNECTORS FOR THREE-WAY SWITCHES WITH WAGO CONNECTORS</b>			
PTS6STR4BP	4 Wire Stranded	6"	Green, Red, Red, Black
PTS6SOL4BP	4 Wire Solid	6"	Green, Red, Red, Black
PTS6STR4277BP	4 Wire Stranded	6"	Green, Brown, Yellow, Yellow
PTS6SOL4277BP	4 Wire Solid	6"	Green, Brown, Yellow, Yellow

CATALOG NUMBER	DESCRIPTION
<b>PLUGTAIL JUMPERS</b>	
PTJ	PlugTail Cover for Rough In
PTJ5	PlugTail Cover for Rough In, 5-pack


# DEVICES & WALL PLATES

## Color Selection Chart

### Devices & Plastic Wall Plate Colors

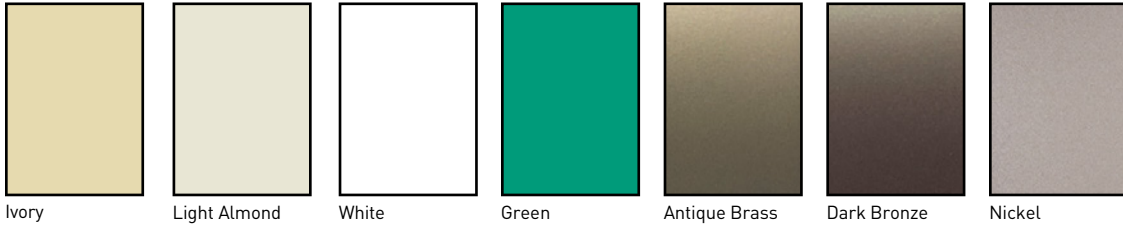

Ivory    Light Almond    White    Green    Antique Brass    Dark Bronze    Nickel

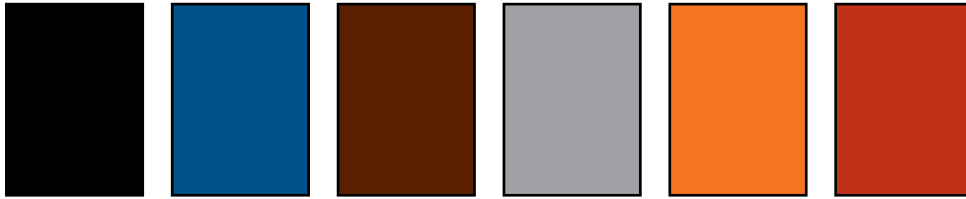


Black    Blue    Brown    Gray    Orange    Red

See specific device and wall plate catalog charts for particular color availabilities.

### Metal Wall Plates


Metal Finish

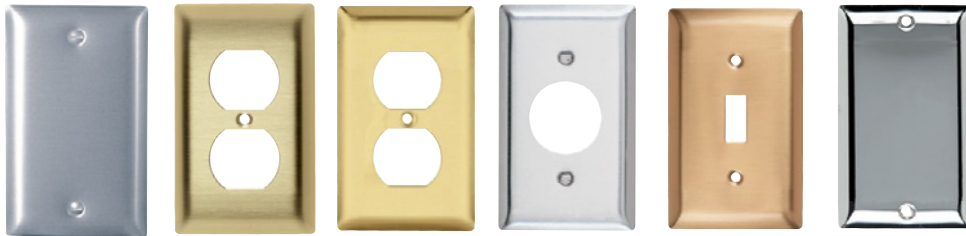

Aluminum    Brass (Brushed)    Polished Brass    Stainless Steel    Brushed Bronze    Chrome

### Custom Metal Wall Plates Paint Finish Colors

Paint Color

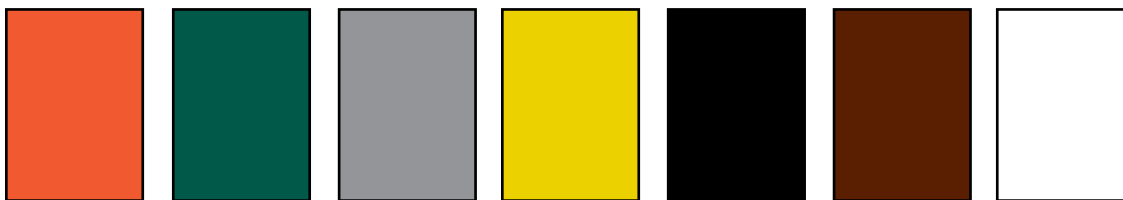

Orange    Green    Gray    Yellow    Glossy Black    Brown    White



Primer    Red    Pink    Flat Black    Ivory    Light Almond    Blue

To order custom metal wall plates, see Pages P-41 – P-45.

**For additional colors consult factory.**

All devices listed on this page conform to NEMA WD-1 and WD-6.